




Box with Hinged Vented Door

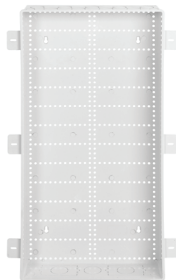

Box Only



Hinged Vented Door



Hinged Vented Door Open

## 14-Inch Network Enclosure

Description	Height Inches (mm)	Width Inches (mm)	Depth Inches (mm)	Module Unit Capacity	Catalog No.
With hinged vented door	16.2" (412)	17.5" (445)	4.35" (111)	5	<b>NSOBXP14</b>
14" height box only	13.5" (343)	17.1" (434)	3.95" (100)	5	<b>NSOBXP14B</b>
Hinged vented door	16.2" (412)	17.5" (445)	0.4" (10)	-	<b>NSOBXP14D</b>



## 28-Inch Network Enclosure

Description	Height Inches (mm)	Width Inches (mm)	Depth Inches (mm)	Module Unit Capacity	Catalog No.
With hinged vented door	30" (762)	17.5" (445)	4.35" (111)	11	<b>NSOBXP28</b>
28" height box only	27.7" (704)	17.1" (434)	3.95" (100)	11	<b>NSOBXP28B</b>
Hinged vented door	30" (762)	17.5" (445)	0.4" (10)	-	<b>NSOBXP28D</b>



## 42-Inch Network Enclosure

Description	Height Inches (mm)	Width Inches (mm)	Depth Inches (mm)	Module Unit Capacity	Catalog No.
With hinged, vented, 2-piece door	45.1" (1146)	17.5" (445)	4.35" (111)	16	<b>NSOBXP42</b>
42" height box only	42.6" (1082)	17.1" (434)	3.95" (100)	16	<b>NSOBXP42B</b>
Hinged vented door (2-piece)	45.1" (1146)	17.5" (445)	0.4" (10)	-	<b>NSOBXP42D</b>

