

## SystemOne Recessed 10" Core Hole Kits, for Use In Concrete Floors



### 10" Fire-Rated Poke-Through

#### Description

Hubbell SystemOne 10" Recessed Floor Fitting with Installation Cover; approved for use in the City of Chicago with EMT and full blank bottom feed plates

#### Catalog Number

**S1R10PTFIT**



### 10" Fire-Rated Poke-Through Kits

Kits include:

 
- (1) Hubbell SystemOne 10" recessed floor fitting (S1R10PTFIT)
- (2) Hubbell SystemOne 10" perimeter device mounting brackets (S1R10PSPREPBRKT)
- (4) Hubbell SystemOne 10" bottom center pass through plate (S1R10CBFPT)
- (3) Hubbell SystemOne 10" bottom perimeter blank plate (S1R10PBFBLANK)
- (1) Hubbell SystemOne 10" bottom perimeter 3/4 inch plate (S1R10PBF075)
- (1) Hubbell SystemOne 10" perimeter divider (S1R10PERIMDIV)
- (1) Hubbell SystemOne 10" center divider (S1R10CENTERDIV)
- (1) Hubbell SystemOne 10" flange and universal cover assembly (S1R10CVRxx)

#### Cover Finish

Brushed Aluminum  
Black Powder Coat  
Brushed Brass Plated  
Antique Bronze Plated  
Gray Powder Coat  
Satin Nickel Plated

#### Catalog Number

**S1R10PTALU**  
**S1R10PTBLK**  
**S1R10PTBRS**  
**S1R10PTBRZ**  
**S1R10PTGRY**  
**S1R10PTNKL**



### Pre-Wired 10" Fire-Rated Poke-Through Kits

Kits include:


- (1) Hubbell SystemOne 10" recessed floor fitting (S1R10PTFIT)
- (2) 20A pre-wired receptacle sub-plates with 24 inch wire leads (S1R10PSPZ)
- (2) Hubbell SystemOne 10" perimeter device mounting brackets (S1R10PSPREPBRKT)
- (4) Hubbell SystemOne 10" bottom center pass through plate (S1R10CBFPT)
- (3) Hubbell SystemOne 10" bottom perimeter blank plate (S1R10PBFBLANK)
- (1) Hubbell SystemOne 10" bottom perimeter 3/4 inch plate (S1R10PBF075)
- (1) Hubbell SystemOne 10" perimeter divider (S1R10PERIMDIV)
- (1) Hubbell SystemOne 10" center divider (S1R10CENTERDIV)
- (1) Hubbell SystemOne 10" flange and universal cover assembly (S1R10CVRxx)
- Receptacles feature single circuit wiring

#### Cover Finish

Brushed Aluminum  
Black Powder Coat  
Brushed Brass Plated  
Antique Bronze Plated  
Gray Powder Coat  
Satin Nickel Plated

#### Catalog Number


**S1R10PTZALU**  
**S1R10PTZBLK**  
**S1R10PTZBRS**  
**S1R10PTZBRZ**  
**S1R10PTZGRY**  
**S1R10PTZNKL**

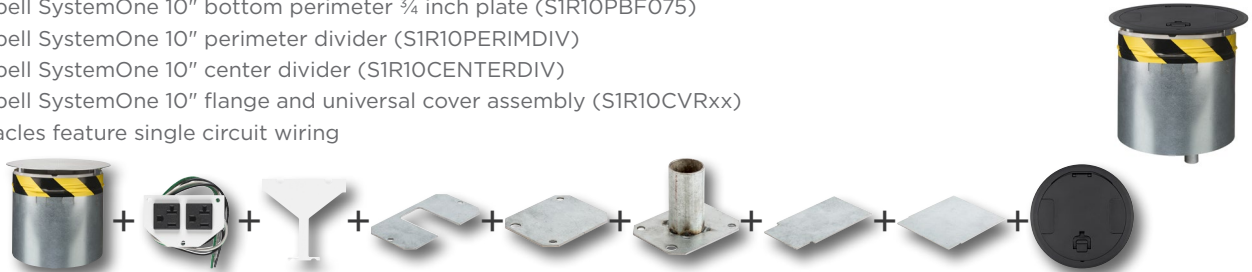

Note: xx indicates finish options.

### Recessed 10" Covers

The 10" FRPT cover assembly unit includes solid cast aluminum construction and mounting hardware. Covers are recessed and available in a number of durable, yet beautiful finishes to match any décor. The flange height of 0.16 inch exceeds ADA requirement and suitable for use on any floor finish. All covers are UL514A, scrubwater compliant.

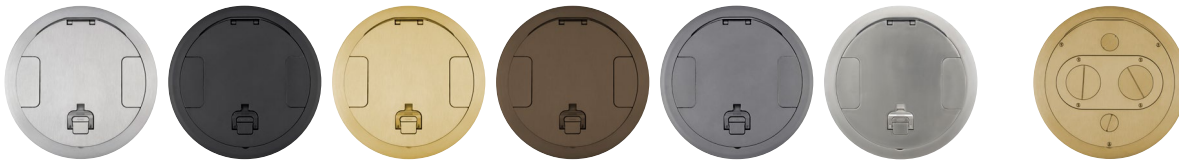

### 10" Fire-Rated Poke-Through Covers

Finish	Recessed Cover Catalog Number	TR Recessed Cover* Catalog Number	Furniture Feed Cover** Catalog Number
Brushed Aluminum	<b>S1R10CVRALU</b>	<b>S1R10CVRTRALU</b>	<b>S1R10FFCVRALU</b>
Black Powder Coat	<b>S1R10CVRBLK</b>	<b>S1R10CVRTRBLK</b>	<b>S1R10FFCVRBLK</b>
Brushed Brass Plated	<b>S1R10CVRBRS</b>	<b>S1R10CVRTRBRS</b>	<b>S1R10FFCVRBRS</b>
Antique Bronze Plated	<b>S1R10CVRBRZ</b>	<b>S1R10CVRTRBRZ</b>	<b>S1R10FFCVRBRZ</b>
Gray Powder Coat	<b>S1R10CVRGRY</b>	<b>S1R10CVRTRGRY</b>	<b>S1R10FFCVRGRY</b>
Satin Nickel Plated	<b>S1R10CVRNKL</b>	<b>S1R10CVRTRNKL</b>	<b>S1R10FFCVRNKL</b>

\*Tamper-resistant covers ship with (1) S1RTR10BIT Torx-T10 bit.

\*\* (2) 1" NPT plugs for power with (2) 1" to 3/4" reducers and (2) 2" NPT plugs for Low Voltage.

Note: Cover Load Rating: 1,000lb with 2x safety factor; load applied through a 3" (76mm) diameter mandrel at the center of cover; rated for static loads only



Complies with UL514 A & C