 
 
 
 
 
 
 
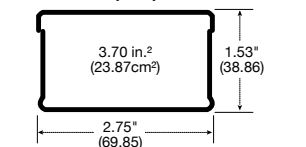
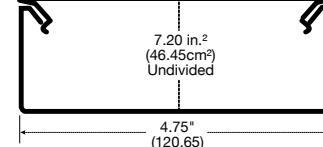
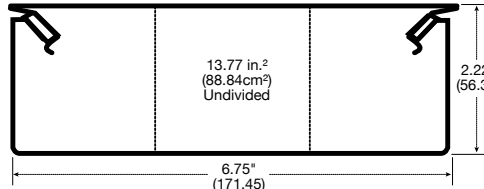


 
 
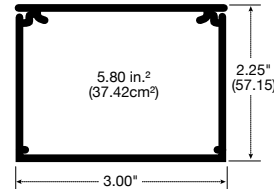
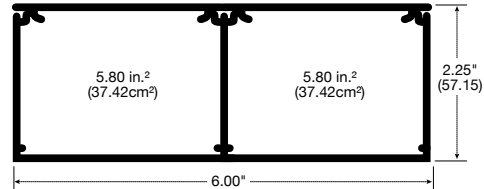
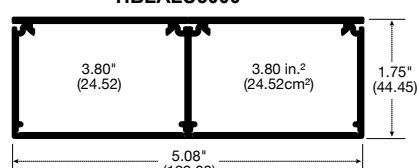
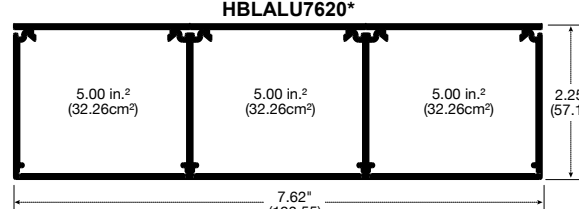
Quick Reference Guide Inches (mm)

Delivery Raceway - Section U

 
 
 
 
 
 
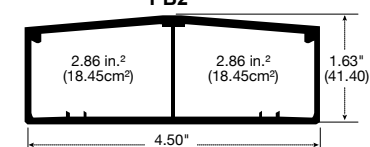
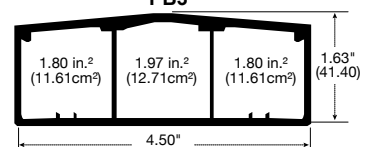
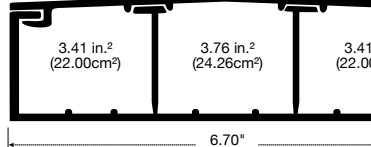
Color: Ivory, Gray or White

<p>HBL500 Ivory/White</p>  <p>.53" (13.46) .76" (19.30) → .22 in.² (1.41cm²)</p> <p>Page S5</p>	<p>HBL700 Ivory/White</p>  <p>.67" (16.90) .76" (19.30) → .26 in.² (1.67cm²)</p> <p>Page S5</p>	<p>HBL750 Ivory/White</p>  <p>.85" (21.59) .76" (19.30) → .40 in.² (2.58cm²)</p> <p>Page S5</p>	<p>HBL2000/A Ivory/Gray</p>  <p>.89 in.² (5.74cm²) .83" (21.08) 1.31" (33.27)</p> <p>Page S11</p>	<p>Metal PlugTrak® Ivory/Gray</p>  <p>.83" (21.08) 1.31" (33.27)</p> <p>Page S13</p>	<p>HBL2400 Ivory</p>  <p>1.39 in.² (8.97cm²) .88" (22.40) 1.91" (48.51)</p> <p>Page S15</p>	<p>HBL2400D Ivory</p>  <p>.86 in.² (5.55cm²) .88" (22.40) 1.91" (48.51) → .37 in.² (2.39cm²)</p> <p>Page S15</p>
<p>HBL3000* Ivory/Gray</p>  <p>3.70 in.² (23.87cm²) 1.53" (38.86) 2.75" (69.85)</p> <p>Page S19</p>	<p>HBL4750* Ivory/Gray</p>  <p>7.20 in.² (46.45cm²) Undivided 1.75" (44.45) 4.75" (120.65)</p> <p>Page S23</p>	<p>HBL6750* Ivory/Gray</p>  <p>13.77 in.² (88.84cm²) Undivided 2.22" (56.39) 6.75" (171.45)</p> <p>Page S29</p>				

Color: Satin Anodized Finish

<p>HBLALU2000</p>  <p>1.20 in.² (7.74cm²) .91" (23.11) 1.84" (46.74)</p> <p>Page S35</p>	<p>Aluminum PlugTrak®</p>  <p>.91" (23.11) 1.84" (46.74)</p> <p>Page S37</p>	<p>HBLALU3800*</p>  <p>5.80 in.² (37.42cm²) 2.25" (57.15) 3.00" (76.20)</p> <p>S39</p>	<p>HBLALU4800*</p>  <p>5.80 in.² (37.42cm²) 5.80 in.² (37.42cm²) 2.25" (57.15) 6.00" (152.40)</p> <p>Page S40</p>
<p>HBLALU5000*</p>  <p>3.80 in.² (24.52) 3.80 in.² (24.52cm²) 1.75" (44.45) 5.08" (129.03)</p> <p>Page S43</p>	<p>HBLALU7620*</p>  <p>5.00 in.² (32.26cm²) 5.00 in.² (32.26cm²) 5.00 in.² (32.26cm²) 2.25" (57.15) 7.62" (193.55)</p> <p>Page S44</p>		

Color: Office White, White and Black

<p>PT1</p>  <p>.68" (17.27) .75" (19.05) → .29 in.² (1.87cm²)</p> <p>Page S55</p>	<p>PP1</p>  <p>.77" (19.56) .84" (21.34) → .38 in.² (2.45cm²)</p> <p>Page S56</p>	<p>PL1</p>  <p>1.03 in.² (6.65cm²) 1.04" (26.42) 1.38" (35.05)</p> <p>Page S57</p>	<p>Non-Metallic PlugTrak®</p>  <p>1.04" (26.42) 1.38" (35.05)</p> <p>Page S63</p>	<p>PW1</p>  <p>.50" (12.70) 1.19" (30.23) → .30 in.² (1.94cm²)</p> <p>Page S58</p>	<p>PW2</p>  <p>.81 in.² (5.23cm²) .79 in.² (5.10cm²) 1.04" (26.42) 2.12" (53.85)</p> <p>Page S59</p>
<p>PB2*</p>  <p>2.86 in.² (18.45cm²) 2.86 in.² (18.45cm²) 1.63" (41.40) 4.50" (114.30)</p> <p>Page S60</p>	<p>PB3</p>  <p>1.80 in.² (11.61cm²) 1.97 in.² (12.71cm²) 1.80 in.² (11.61cm²) 1.63" (41.40) 4.50" (114.30)</p> <p>Page S61</p>	<p>PS3*</p>  <p>3.41 in.² (22.00cm²) 3.76 in.² (24.26cm²) 3.41 in.² (22.00cm²) 1.97" (50.04) 6.70" (170.18)</p> <p>Page S62</p>			

*Available PRE-WIRED