

Adley

Fundamentally modern but with a traditional twist, Adley combines opal glass shades with curved arms and simple, straight bars.

FINISHES

009 Brushed Nickel

012 Satin Brass

31M Matte Black



P400350-31M

Adley


P400351-31M Matte Black
28" dia., 26.12" ht.
9 medium base, 60w max.



P400350-31M Matte Black
22.87" dia., 17.25" ht.
5 medium base, 60w max.



P400349-31M Matte Black
18.12" dia., 16.12" ht.
3 medium base, 60w max.

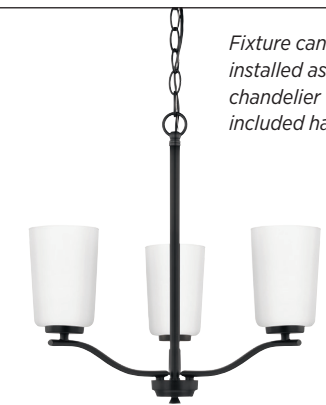

Fixture can be installed as a chandelier using included hardware.

P400348-31M Matte Black
26" L., 17" ht., 4" D.
3 medium base, 60w max.



ALSO IN



Bath



Close-to-Ceiling

Search the product number on progresslighting.com for full product details

Adley

P400351-009 Brushed Nickel
28" dia., 26.12" ht.
9 medium base, 60w max.



P400350-009 Brushed Nickel
22.87" dia., 17.25" ht.
5 medium base, 60w max.



P400349-009 Brushed Nickel
18.12" dia., 16.12" ht.
3 medium base, 60w max.



Fixture can be installed as a chandelier using included hardware.

P400348-009 Brushed Nickel
26" L., 17" ht., 4" D.
3 medium base, 60w max.



ALSO IN



Search the product number on progresslighting.com for full product details

Adley

P400351-012 Satin Brass
28" dia., 26.12" ht.
9 medium base, 60w max.



P400350-012 Satin Brass
22.87" dia., 17.25" ht.
5 medium base, 60w max.



P400349-012 Satin Brass
18.12" dia., 16.12" ht.
3 medium base, 60w max.



Fixture can be installed as a chandelier using included hardware.

P400348-012 Satin Brass
26" L., 17" ht., 4" D.
3 medium base, 60w max.



ALSO IN



Search the product number on progresslighting.com for full product details

Adley

Clear or etched opal glass.

009 Brushed Nickel

104 Polished Nickel

012 Satin Brass

31M Matte Black

P350213-009 Brushed Nickel
8.62" dia., 7.37" ht.
1 medium base, 60w max.



P350260-009 Brushed Nickel
8.62" dia., 7.37" ht.
1 medium base, 60w max.



P350213-012 Satin Brass
8.62" dia., 7.37" ht.
1 medium base, 60w max.



P350260-012 Satin Brass
8.62" dia., 7.37" ht.
1 medium base, 60w max.



P350213-31M Matte Black
8.62" dia., 7.37" ht.
1 medium base, 60w max.



P350260-31M Matte Black
8.62" dia., 7.37" ht.
1 medium base, 60w max.



P350213-104 Polished Nickel
8.62" dia., 7.37" ht.
1 medium base, 60w max.



Adley

Adley combines a clear glass shade with a curved rectangular backplate. Adley is a universal choice for New Traditional and Transitional settings.

FINISHES

- 009 Brushed Nickel
- 012 Satin Brass
- 031 Matte Black
- 104 Polished Nickel



P300155-031

- P300372-009** Brushed Nickel
 - P300372-012** Satin Brass
 - P300372-031** Matte Black
- 48.5" W., 7.62" ht.
6 medium base, 60w max.



All fixtures:



Search the product number on progresslighting.com for full product details

Adley

- P300157-009** Brushed Nickel
- P300157-012** Satin Brass
- P300157-031** Matte Black
- P300157-104** Polished Nickel

32" W., 7.62" ht.
4 medium base,
60w max.



- P300155-009** Brushed Nickel
- P300155-012** Satin Brass
- P300155-031** Matte Black
- P300155-104** Polished Nickel

13.87" W., 7.62" ht.
2 medium base,
60w max.



All fixtures:



- P300156-009** Brushed Nickel
- P300156-012** Satin Brass
- P300156-031** Matte Black
- P300156-104** Polished Nickel

23" W., 7.62" ht.
3 medium base,
60w max.



- P300154-009** Brushed Nickel
- P300154-012** Satin Brass
- P300154-031** Matte Black
- P300154-104** Polished Nickel

4.5" W., 7.75" ht., 6" D.
1 medium base,
60w max.



Search the product number on progresslighting.com for full product details

Adley

Adley combines an etched opal glass shade with a curved rectangular backplate. Adley is a universal choice for New Traditional and Transitional settings.

FINISHES

009 Brushed Nickel

012 Satin Brass

31M Matte Black



P300466-012

P300468-009 Brushed Nickel
P300468-012 Satin Brass
P300468-31M Matte Black
 32" W., 7.62" ht.
 4 medium base, 60w max.



All fixtures:



Search the product number on progresslighting.com for full product details

Adley

P300467-009 Brushed Nickel
P300467-012 Satin Brass
P300467-31M Matte Black
 23" W., 7.62" ht.
 3 medium base, 60w max.



P300466-009 Brushed Nickel
P300466-012 Satin Brass
P300466-31M Matte Black
 13.87" W., 7.62" ht.
 2 medium base, 60w max.



P300465-009 Brushed Nickel
P300465-012 Satin Brass
P300465-31M Matte Black
 4.5" W., 7.75" ht., 6" D.
 1 medium base, 60w max.



All fixtures:



Search the product number on progresslighting.com for full product details