

# Seneca

**FINISHES**

- Black - 031
- Polished Nickel - 104

**PAIR WITH**

- Galley
- Equinox
- Bay Court

Sophisticated simplicity is personified in the Seneca collection. Within its open cage design the candelabra lights seem to float in midair, brought down to earth only by its simple base. Graceful lines radiate downwards for an unexpected, upside-down twist on traditional lighting design, making Seneca ideal for luxurious Transitional settings, while the overall, clean and modern look adds polished flair to Modern Farmhouse interiors.

P400115-104



*Open Cage Design*

*Airy & Light*


*Sophisticated*



P400115-104



P500121-104

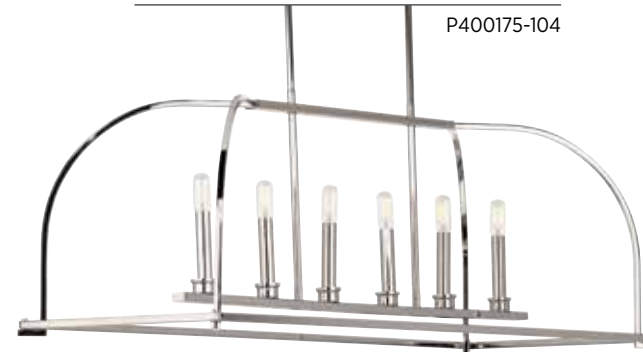

P400175-104



P400187-104



P500122-104

## Seneca

**FIVE-LIGHT CHANDELIER**

**P400115-104** Polished Nickel  
25-1/2" dia., 15-7/8" ht.,  
Overall ht. w/stem 81-1/2"; wire 15'.  
Five candelabra base lamps,  
each 60w max.

**SIX-LIGHT LINEAR CHANDELIER**

**P400175-104** Polished Nickel  
38-1/4" W., 15-3/8" D., 14-1/8" ht.,  
Overall ht. w/stem 80-1/2"; wire 15'.  
Six candelabra base lamps,  
each 60w max.

**NINE-LIGHT CHANDELIER**

**P400187-104** Polished Nickel  
30" dia., 20-7/8" ht.,  
Overall ht. w/stem 86-1/2"; wire 15'.  
Nine candelabra base lamps,  
each 60w max.

**FOUR-LIGHT FOYER**

**P500121-104** Polished Nickel  
15" dia., 17-1/4" ht.,  
Overall ht. w/stem 83-1/2"; wire 15'.  
Four candelabra base lamps,  
each 60w max.

**EIGHT-LIGHT FOYER**

**P500122-104** Polished Nickel  
19-5/8" dia., 32" ht.,  
Overall ht. w/stem 98"; wire 15'.  
Eight candelabra base lamps,  
each 60w max.

*All fixtures shown with EF4T8D927/JA8 LED lamps, not included.*



## Seneca

### FIVE-LIGHT CHANDELIER

**P400115-031** Black  
25-1/2" dia., 15-7/8" ht.,  
Overall ht. w/stem 81-1/2"; wire 15'.  
Five candelabra base lamps,  
each 60w max.

### SIX-LIGHT LINEAR CHANDELIER

**P400175-031** Black  
38-1/4" W., 15-3/8" D., 14-1/8" ht.,  
Overall ht. w/stem 80-1/2"; wire 15'.  
Six candelabra base lamps,  
each 60w max.

### NINE-LIGHT CHANDELIER

**P400187-031** Black  
30" dia., 20-7/8" ht.,  
Overall ht. w/stem 86-1/2"; wire 15'.  
Nine candelabra base lamps,  
each 60w max.

### FOUR-LIGHT FOYER

**P500121-031** Black  
15" dia., 17-1/4" ht.,  
Overall ht. w/stem 83-1/2"; wire 15'.  
Four candelabra base lamps,  
each 60w max.

### EIGHT-LIGHT FOYER

**P500122-031** Black  
19-5/8" dia., 32" ht.,  
Overall ht. w/stem 98"; wire 15'.  
Eight candelabra base lamps,  
each 60w max.

*All fixtures shown with EF4T8D927/JA8  
LED lamps, not included.*

