

Equinox

FINISHES

- Satin Brass - 12
- Antique Bronze - 20
- Matte Black - 31
- Polished Nickel - 104
- Burnished Silver - 126

PAIR WITH

- Litchfield
- Seneca
- Kene

P3841-104

Interlocking rings form the perfect sphere as they pivot in a variety of adjustable positions around a center stem. Inside the orb, sleek candelabra bases command center stage as they radiate alluring light from every imaginable angle.

Movable Rings

Spherical Design



Polished Nickel



P3889-104

Equinox

FOUR-LIGHT PENDANT

P3827-104 Polished Nickel
16" dia., 18-3/8" ht.,
Overall ht. w/chain 94"; wire 15'.
Four candelabra base lamps,
each 60w max.

FIVE-LIGHT CHANDELIER

P3841-104 Polished Nickel
22" dia., 24-3/8" ht.,
Overall ht. w/chain 99-1/2"; wire 15'.
Five candelabra base lamps,
each 60w max.

SIX-LIGHT CHANDELIER

P3889-104 Polished Nickel
27-3/4" dia., 30" ht.,
Overall ht. w/chain 105"; wire 15'.
Six candelabra base lamps,
each 60w max.

ONE-LIGHT PENDANT

P7077-104 Polished Nickel
11-3/8" dia., 12-1/16" ht.,
Overall ht. w/chain 78"; wire 10'.
One medium base lamp,
100w max.

ONE-LIGHT PENDANT

P7078-104 Polished Nickel
16" dia., 16-3/4" ht.,
Overall ht. w/chain 83"; wire 10'.
One medium base lamp,
100w max.



P3827-104



P3841-104



P7078-104



P7077-104



Warm Wood Adds Comfort & Style

Reclaimed wood takes center stage in an open concept space. Wood acts as a warming element and this rustic kitchen vent hood melds together industrial metals, neutral wall color and a gray-blue undertone of the Shaker-style cabinets into a natural, organic look.

Choose lighting that delivers a punch, but doesn't overwhelm the space. The large Equinox chandelier brings a crisp and clean, yet industrial feel that gives overall balance to the area. A trio of round Chronicle pendants over the island provides contrast to the sea of rectangular shapes furnished by the cabinets, subway tile, paneled kitchen island detail and the oven hood.

Equinox



EIGHT-LIGHT OVAL CHANDELIER

P3791-20 Antique Bronze
39" L., 14-1/4" W., 26-3/8" ht.,
Overall ht. w/chain 150"; wire 15'.
Eight candelabra base lamps,
each 60w max.

FOUR-LIGHT PENDANT

P3827-20 Antique Bronze
16" dia., 18-3/8" ht.,
Overall ht. w/chain 94"; wire 15'.
Four candelabra base lamps,
each 60w max.

FIVE-LIGHT CHANDELIER

P3841-20 Antique Bronze
22" dia., 24-3/8" ht.,
Overall ht. w/chain 99-1/2"; wire 15'.
Five candelabra base lamps,
each 60w max.

SIX-LIGHT CHANDELIER

P3889-20 Antique Bronze
27-3/4" dia., 30" ht.,
Overall ht. w/chain 105"; wire 15'.
Six candelabra base lamps,
each 60w max.

MINI-PENDANT

P5142-20 Antique Bronze
10-1/8" dia., 12-1/2" ht.,
Overall ht. w/chain 87"; wire 15'.
Three candelabra base lamps,
each 60w max.



Equinox

FOUR-LIGHT PENDANT

P3827-12 Satin Brass
P3827-31 Matte Black
 16" dia., 18-3/8" ht.,
 Overall ht. w/chain 94", wire 15'.
 Four candelabra base lamps,
 each 60w max.

FIVE-LIGHT CHANDELIER

P3841-12 Satin Brass
P3841-31 Matte Black
 22" dia., 24-3/8" ht.,
 Overall ht. w/chain 99-1/2", wire 15'.
 Five candelabra base lamps,
 each 60w max.

SIX-LIGHT CHANDELIER


P3889-12 Satin Brass
P3889-31 Matte Black
 27-3/4" dia., 30" ht.,
 Overall ht. w/chain 105", wire 15'.
 Six candelabra base lamps,
 each 60w max.



P3841-12



P3841-31

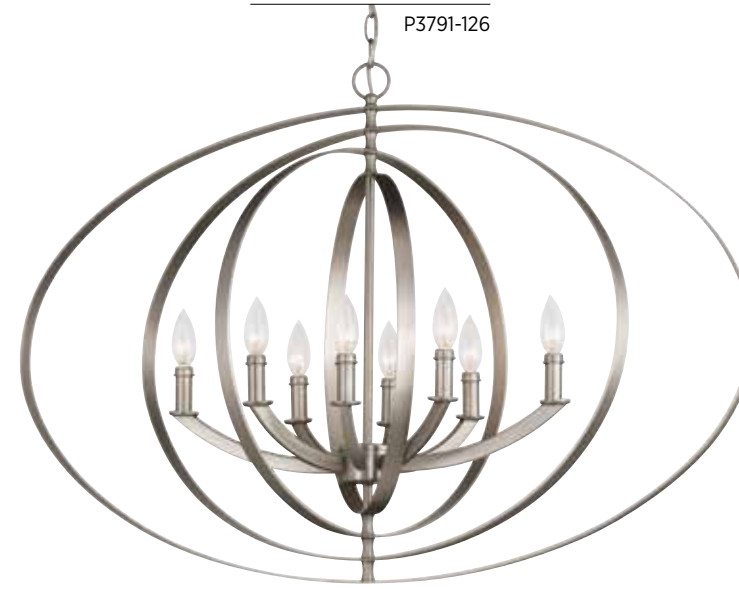

P3791-126




P3889-12



P3889-31



P3889-126

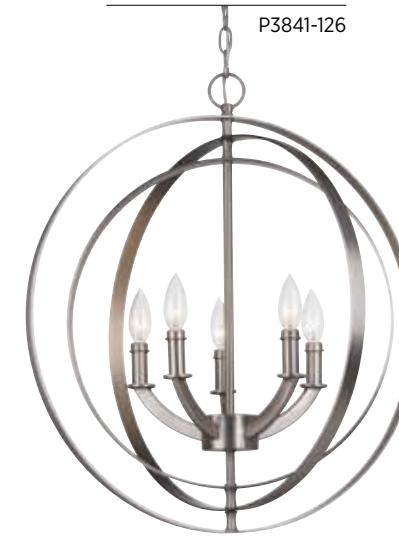

P3841-126



P3827-12



P3827-31



P5142-126



P3827-126

Equinox

EIGHT-LIGHT OVAL CHANDELIER

P3791-126 Burnished Silver
 39" L., 14-1/4" W., 26-3/8" ht.,
 Overall ht. w/chain 150"; wire 15'.
 Eight candelabra base lamps,
 each 60w max.

FOUR-LIGHT PENDANT

P3827-126 Burnished Silver
 16" dia., 18-3/8" ht.,
 Overall ht. w/chain 94"; wire 15'.
 Four candelabra base lamps,
 each 60w max.

FIVE-LIGHT CHANDELIER

P3841-126 Burnished Silver
 22" dia., 24-3/8" ht.,
 Overall ht. w/chain 99-1/2"; wire 15'.
 Five candelabra base lamps,
 each 60w max.

SIX-LIGHT CHANDELIER

P3889-126 Burnished Silver
 27-3/4" dia., 30" ht.,
 Overall ht. w/chain 105"; wire 15'.
 Six candelabra base lamps,
 each 60w max.

MINI-PENDANT

P5142-126 Burnished Silver
 10-1/8" dia., 12-1/2" ht.,
 Overall ht. w/chain 87"; wire 15'.
 Three candelabra base lamps,
 each 60w max.