

Hemsworth

FINISHES

- Textured Black - 031
- Galvanized - 141

ALSO IN

- Sconces
- Close-to-Ceiling

PAIR WITH

- Gulliver
- Bonn
- Briarwood

P500277-031

A rustic flair is the cornerstone look of this family with both aged and bleached oak faux wood finishes.

Rustic Charm


Barn Inspired Metal Details



Textured Black



P400229-031

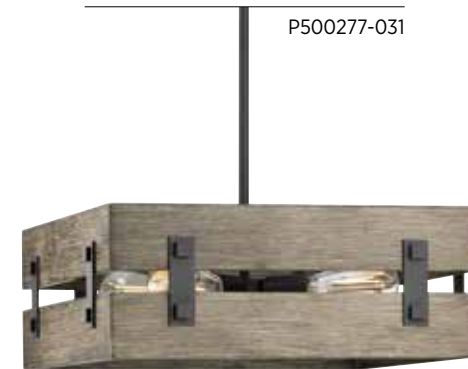

P500277-031



P710093-031



P350172-031



P350172-031
shown as semi-flush

Hemsworth

TWO-LIGHT SEMI-FLUSH

P350172-031 Textured Black
Hanging and ceiling mount hardware included.
13-1/2" sq., 10-1/8" ht.,
Overall ht. w/chain 51", wire 10'.
Two medium base lamps,
each 60w max.

FOUR-LIGHT LINEAR CHANDELIER

P400229-031 Textured Black
36" W., 9-14" D., 7-7/8" ht.,
Overall ht. w/chain 78-1/2", wire 15'.
Four medium base lamps,
each 60w max.

FOUR-LIGHT PENDANT

P500277-031 Textured Black
18" sq., 7" ht.,
Overall ht. w/chain 73", wire 15'.
Four medium base lamps,
each 60w max.

WALL BRACKET

P710093-031 Textured Black
4-3/4" W., 16-3/4" ht.,
Extends 3-7/8". H/CTR 10-3/4".
One medium base lamp,
60w max.

*All fixtures shown with
F7ST19DLED927/JA8 LED lamps,
not included.*



Bring the Outdoors In

Follow today's trend of forging a deep connection with outdoor life while entertaining in sleek style. Bring the outside in with greenery, wooden accents and terracotta pots placed against a clean black and beige color palette. Add a showstopper chandelier like the clean-lined Hemsworth, whose warm wooden frame and metal hardware bring together the best of rustic and modern design.

Hemsworth

P400229-141



TWO-LIGHT SEMI-FLUSH
P350172-141 Galvanized
 Hanging and ceiling mount hardware included.
 13-1/2" sq., 10-1/8" ht.,
 Overall ht. w/chain 51", wire 10'.
 Two medium base lamps,
 each 60w max.

FOUR-LIGHT LINEAR CHANDELIER
P400229-141 Galvanized
 36" W., 9-14" D., 7-7/8" ht.,
 Overall ht. w/chain 78-1/2", wire 15'.
 Four medium base lamps,
 each 60w max.

FOUR-LIGHT PENDANT
P500277-141 Galvanized
 18" sq., 7" ht.,
 Overall ht. w/chain 73", wire 15'.
 Four medium base lamps,
 each 60w max.

P500277-141



WALL BRACKET
P710093-141 Galvanized
 4-3/4" W., 16-3/4" ht.,
 Extends 3-7/8". H/CTR 10-3/4".
 One medium base lamp,
 60w max.

P710093-141

*All fixtures shown with
 F7ST19DLED927/JA8 LED lamps,
 not included.*

P350172-141



P350172-141
 shown as semi-flush

Hemsworth

Barn-inspired metal detailing on either aged or bleached oak fixtures.

SEMI-FLUSH CONVERTIBLE

P350172-031 Black

P350172-141 Galvanized

Hanging and ceiling mount hardware included.

13-1/2" sq., 10-1/8" ht.,

Overall ht. w/chain 51", wire 10'

Two medium base lamps, each 60w max.



P350172-031



P350172-141

Hemsworth

Barn-inspired metal detailing punctuates either aged or bleached oak backplates.

P710093-031 Black

P710093-141 Galvanized

4-3/4" W., 16-3/4" ht.

Extends 3-7/8". H/CTR 10-3/4".

One medium base lamp, 60w max.

Fixture shown with P7825-01 vintage lamp.



P710093-141



P710093-031