

Calhoun

FINISHES

- Brushed Nickel - 009
- Antique Bronze - 020

ALSO IN

Bath

PAIR WITH

Seneca
Mast

P400133-020
spanner with long stem



Vintage Style


Adjustable Spanner

A trend in home décor is the repurposing of antique pieces. Calhoun playfully follows this trend with an apothecary style clear glass diffuser held in place with a mechanical latch from a spice container. A glass shade showcases a thickened profile to create a vintage-style surface for a classic handmade appearance. The vintage design is a perfect complement to several décor styles including the popular Farmhouse trend.

Glass Shades



P400132-020

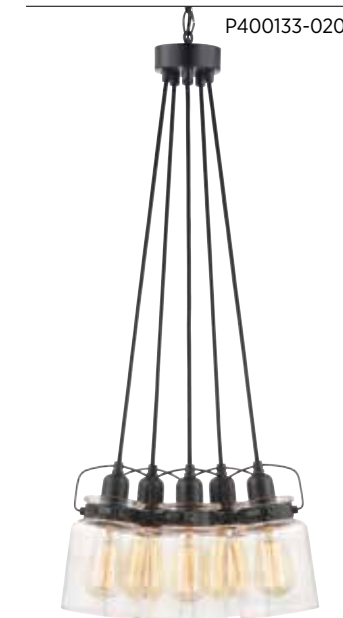

P400133-020



P400132-020
spanner with
short stem



P400133-020
spanner with
short stem



P400132-020
spanner with
long stem



P500152-020



P500055-020

Calhoun

THREE-LIGHT CHANDELIER

P400132-020 Antique Bronze
22-5/8" dia., 29-1/8" ht.,
Overall ht. w/chain 103", wire 10'.
Three medium base lamps,
each 60w max.

FIVE-LIGHT CHANDELIER

P400133-020 Antique Bronze
28-5/8" dia., 29-1/8" ht.,
Overall ht. w/chain 103", wire 10'.
Five medium base lamps,
each 60w max.

MINI-PENDANT

P500055-020 Antique Bronze
4-3/4" dia., 9" ht.,
Overall ht. w/stem 75", wire 10'.
One medium base lamp,
100w max.

ONE-LIGHT PENDANT

P500152-020 Antique Bronze
12" dia., 9-3/8" ht.,
Overall ht. w/stem 75-1/2", wire 10'.
One medium base lamp,
60w max.

All fixtures shown with P7825-01 vintage lamps, not included.


Calhoun is a versatile style that can be displayed in three different ways for both three-light and five-light chandeliers: assemble with the included optional spanner and long or short stems for a unique cord-hung style chandelier, or let the lights hang in a more casual cluster.



Be Ingeniously Industrial

A canvas of exposed brick walls and dark metal-paned windows brings interesting visual and textural elements to the clean Industrial space. Use metal and wood elements throughout to play up the minimal yet rugged vibe. Since utility and function are cornerstones of the warehouse look, place an ultra-functional pendant like Calhoun center stage. With its unique, adjustable design, Calhoun can be installed several ways for three different, personalized custom looks.

Calhoun

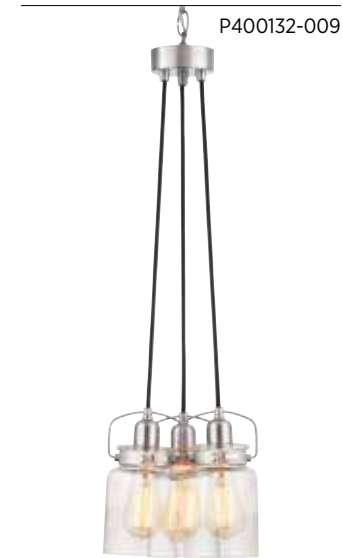

P400132-009



P400133-009

THREE-LIGHT CHANDELIER
P400132-009 Brushed Nickel
 22-5/8" dia., 29-1/8" ht.,
 Overall ht. w/chain 103", wire 10'.
 Three medium base lamps,
 each 60w max.

FIVE-LIGHT CHANDELIER
P400133-009 Brushed Nickel
 28-5/8" dia., 29-1/8" ht.,
 Overall ht. w/chain 103", wire 10'.
 Five medium base lamps,
 each 60w max.

MINI-PENDANT
P500055-009 Brushed Nickel
 4-3/4" dia., 9" ht.,
 Overall ht. w/stem 75", wire 10'.
 One medium base lamp,
 100w max.

ONE-LIGHT PENDANT
P500152-009 Brushed Nickel
 12" dia., 9-3/8" ht.,
 Overall ht. w/stem 75-1/2", wire 10'.
 One medium base lamp,
 60w max.

All fixtures shown with P7825-01 vintage lamps, not included.

Calhoun is a versatile style that can be displayed in three different ways for both three-light and five-light chandeliers: assemble with the included optional spanner and long or short stems for a unique cord-hung style chandelier, or let the lights hang in a more casual cluster.



P400132-009
 spanner with
 short stem



P400133-009
 spanner with
 short stem



P400132-009
 spanner with
 long stem



P500152-009



P500055-009

Calhoun

FINISHES

- Brushed Nickel - 009
- Antique Bronze - 020

ALSO IN

- Collections
- Close-to-Ceiling
- Pendants

P300047-009

A delightful trend in home décor is the repurposing of antique parts into new, functional furniture and accessories. Calhoun playfully follows this lead with an apothecary style and features a clear glass diffuser held in place with a mechanical latch from a spice container. The glass shade showcases a thickened profile to create a vintage-style surface for a classic handmade appearance.

Apothecary Style



Vintage Style

Classic Handmade Feel

ONE-LIGHT BATH

P300045-009 Brushed Nickel
5" W., 8-5/8" ht.
Extends 6-7/8". H/CTR 5-1/8".
One medium base lamp,
100w max.



P300045-009

TWO-LIGHT BATH

P300046-009 Brushed Nickel
13-1/4" W., 8-5/8" ht.
Extends 6-7/8". H/CTR 6-3/8".
Two medium base lamps,
each 100w max.



P300048-009

THREE-LIGHT BATH

P300047-009 Brushed Nickel
21-5/8" W., 8-5/8" ht.
Extends 6-7/8". H/CTR 6-3/8".
Three medium base lamps,
each 100w max.



P300046-009



P300047-009

*All fixtures mount up or down.
Shown with P7825-01 vintage lamps,
not included.*

Calhoun



P300046-020



P300045-020



P300047-020



P300048-020

ONE-LIGHT BATH

P300045-020 Antique Bronze
5" W., 8-5/8" ht.
Extends 6-7/8". H/CTR 5-1/8".
One medium base lamp,
100w max.

TWO-LIGHT BATH

P300046-020 Antique Bronze
13-1/4" W., 8-5/8" ht.
Extends 6-7/8". H/CTR 6-3/8".
Two medium base lamps,
each 100w max.

THREE-LIGHT BATH

P300047-020 Antique Bronze
21-5/8" W., 8-5/8" ht.
Extends 6-7/8". H/CTR 6-3/8".
Three medium base lamps,
each 100w max.

FOUR-LIGHT BATH

P300048-020 Antique Bronze
30-1/4" W., 8-5/8" ht.
Extends 6-7/8". H/CTR 6-3/8".
Four medium base lamps,
each 100w max.

*All fixtures mount up or down.
Shown with P7825-01 vintage lamps,
not included.*



*Featuring Calhoun
Image: Tresidio Homes*