

Tobin

FINISH

- Brushed Nickel - 009
- Matte Black - 031

ALSO IN

Bath
Sconces

PAIR WITH

Ratio
Haven
Chadwick

WALL BRACKET

P300222-009 Brushed Nickel
5" W., 15-1/2" ht.,
Extends 5-7/8". H/CTR 11".
One medium base lamp,
100w max.

SEMI-FLUSH CONVERTIBLE

P350137-009 Brushed Nickel
Hanging and ceiling mount
hardware included.
12-1/4" dia., 10-1/8" ht.,
Overall ht. w/chain 48-1/2"; wire 10'.
Two medium base lamps,
each 100w max.

THREE-LIGHT CHANDELIER

P400181-009 Brushed Nickel
22-3/8" dia., 9-7/8" ht.,
Overall ht. w/stem 70"; wire 15'.
Three medium base lamps,
each 100w max.

FIVE-LIGHT CHANDELIER

P400182-009 Brushed Nickel
27-5/8" dia., 9-7/8" ht.,
Overall ht. w/stem 70"; wire 15'.
Five medium base lamps,
each 100w max.

NINE-LIGHT CHANDELIER


P400183-009 Brushed Nickel
32" dia., 18-5/8" ht.,
Overall ht. w/stem 78-1/2"; wire 15'.
Nine medium base lamps,
each 100w max.

MINI-PENDANT

P500180-009 Brushed Nickel
5-3/4" dia., 21-5/8" ht.,
Overall ht. w/stem 88"; wire 10'.
One medium base lamp,
100w max.



P350137-009
shown hanging

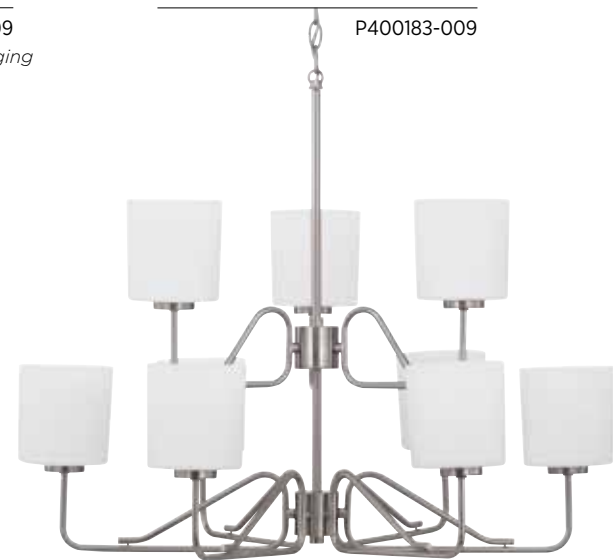

P400183-009



P400183-031



P350137-031
shown hanging



P500180-009



P400182-009



P400182-031



P500180-031



P300222-009



P400181-009



P400181-031



P300222-031

Tobin

WALL BRACKET

P300222-031 Matte Black
5" W., 15-1/2" ht.,
Extends 5-7/8". H/CTR 11".
One medium base lamp,
100w max.

SEMI-FLUSH CONVERTIBLE

P350137-031 Matte Black
Hanging and ceiling mount
hardware included.
12-1/4" dia., 10-1/8" ht.,
Overall ht. w/chain 48-1/2"; wire 10'.
Two medium base lamps,
each 100w max.

THREE-LIGHT CHANDELIER

P400181-031 Matte Black
22-3/8" dia., 9-7/8" ht.,
Overall ht. w/stem 70"; wire 15'.
Three medium base lamps,
each 100w max.

FIVE-LIGHT CHANDELIER

P400182-031 Matte Black
27-5/8" dia., 9-7/8" ht.,
Overall ht. w/stem 70"; wire 15'.
Five medium base lamps,
each 100w max.

NINE-LIGHT CHANDELIER

P400183-031 Matte Black
32" dia., 18-5/8" ht.,
Overall ht. w/stem 78-1/2"; wire 15'.
Nine medium base lamps,
each 100w max.

MINI-PENDANT

P500180-031 Matte Black
5-3/4" dia., 21-5/8" ht.,
Overall ht. w/stem 88"; wire 10'.
One medium base lamp,
100w max.

Tobin

A modern take on a classic form. Tobin's tubular arms extend outward and are made to form a gentle curve that showcase etched white glass shades. The Tobin collection is ideal for those who appreciate Modern design styles.

FINISHES

- Brushed Nickel - 009
- Matte Black - 031

ALSO IN

Collections
Close-to-Ceiling



P300219-009



P300220-009



P300222-009



P300221-009



P300219-031



P300220-031



P300222-031



P300221-031

ONE-LIGHT BATH

P300222-009 Brushed Nickel

P300222-031 Matte Black

5" W., 15-1/2" ht.

Extends 5-7/8". H/CTR 11".

One medium base lamp,
100w max.

TWO-LIGHT BATH

P300219-009 Brushed Nickel

P300219-031 Matte Black

15-1/4" W., 7-7/8" ht.

Extends 7-5/8". H/CTR 5-5/8".

Two medium base lamps,
each 100w max.

THREE-LIGHT BATH

P300220-009 Brushed Nickel

P300220-031 Matte Black

25-1/2" W., 7-7/8" ht.

Extends 7-5/8". H/CTR 5-5/8".

Three medium base lamps,
each 100w max.

FOUR-LIGHT BATH

P300221-009 Brushed Nickel

P300221-031 Matte Black

35-3/4" W., 7-7/8" ht.

Extends 7-5/8". H/CTR 5-5/8".

Four medium base lamps,
each 100w max.

All fixtures mount up or down.

Tobin

Tubular arms form a gentle curve showcasing an etched glass shade.



P300222-009



P300222-031

P300222-009 Brushed Nickel

P300222-031 Black

5" W., 15-1/2" ht.

Extends 5-7/8". H/CTR 11".

One medium base lamp,

100w max.