


Springer

P250000-081
shown with White Barnwood blades

FINISHES

- Antique Nickel - 081
- Architectural Bronze - 129

Springer is a statement-making ceiling fan with a rustic flair. The 12-blade, 60" ceiling fan was inspired by the form and function of a windmill and is ideal for Farmhouse, Industrial and Transitional interior settings. A full function remote control with batteries is included along with a dual mount canopy that accommodates flat or sloped ceilings.

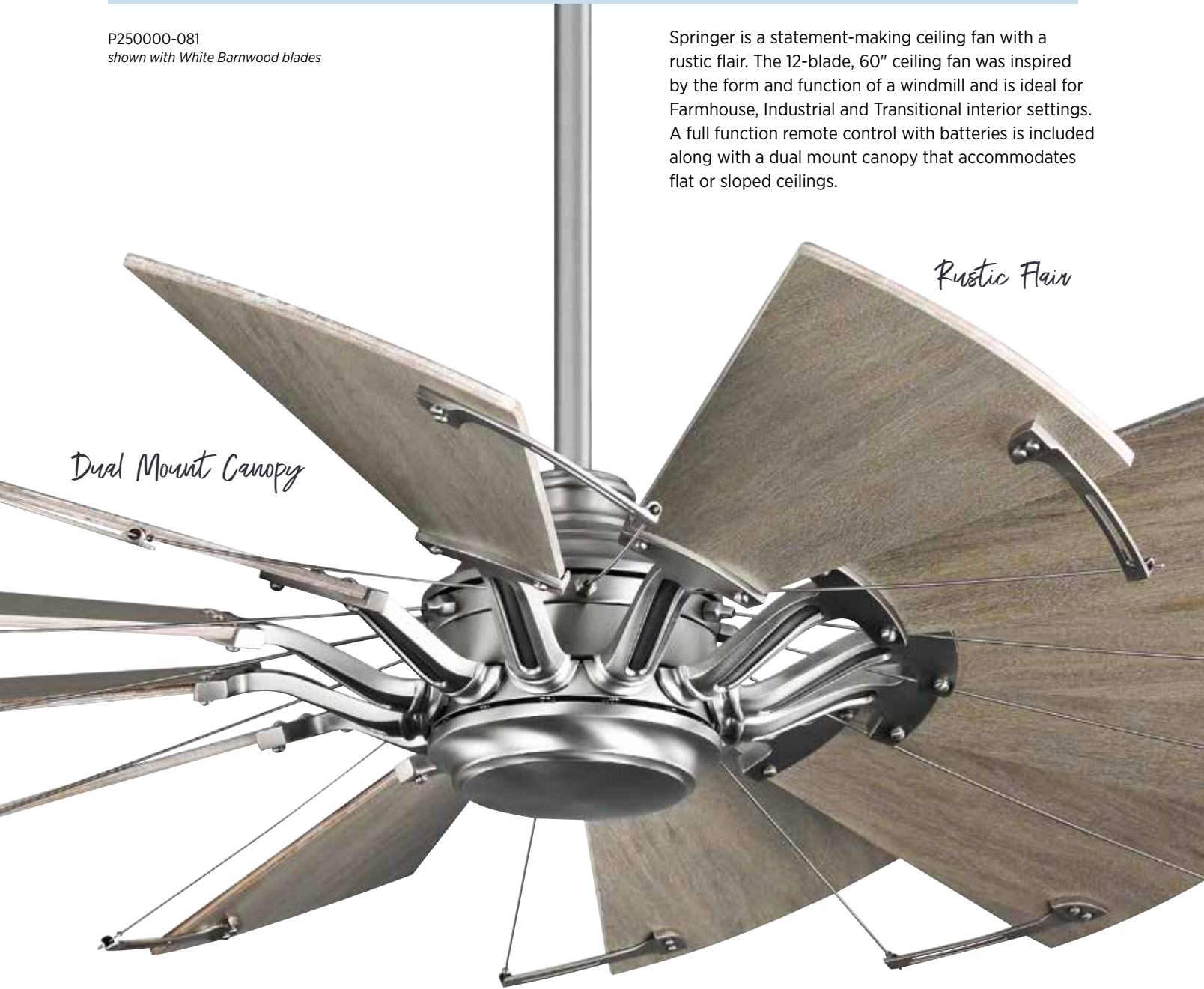


Dual Mount Canopy

Rustic Flair

Windmill Inspired

Springer

 P250000-081 Antique Nickel



P250000-129 Architectural Bronze



P250000-081
shown with White Barnwood blades



P250000-129
shown with Distressed Walnut blades

ENERGY INFORMATION AT HIGH SPEED

Airflow	6,377 cubic feet per minute
Electricity Use	33 watts (excludes lights)
DOE Weighted CFM/W	206 CFM/W

FEATURES

- Limited Lifetime Warranty
- Dual Mount (flat or sloped ceiling-22°)
- DC Motor
- Plywood blades
- Full function remote control with batteries is included

SIZE

60" dia., 17-3/8" ht.
80" lead wires.



Full Function Remote Control Included
Six-speed fan operation
Reverse direction control