


Beam LED

FINISHES

- Brushed Nickel - 009
- Polished Chrome - 015
- Architectural Bronze - 129

P300182-129-30

Beam LED vanity and sconces feature a squared, tubular opal glass diffuser paired with a simple, modern metal canopy. An integrated LED source provides a variety of energy and cost savings benefits. Suitable for residential and commercial applications.

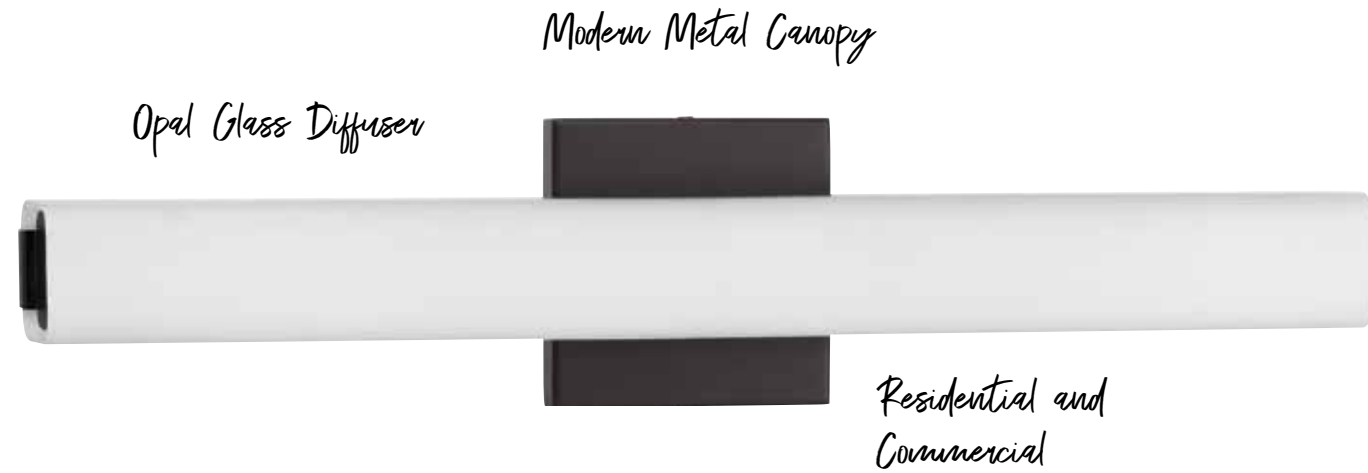

22" LINEAR LED BATH
P300182-129-30 Architectural Bronze
 Installs horizontal or vertical.
 22-1/4" W., 4-3/4" ht.
 Extends 3". H/CTR 2-3/8".
 36w integrated LED, 3000K,
 90CRI, 2200 delivered lumens.

LED WALL BRACKET
P710049-129-30 Architectural Bronze
 4-3/4" W., 10-1/2" ht.
 Extends 3-1/4". H/CTR 8-3/8".
 16w integrated LED, 3000K,
 90CRI, 1000 delivered lumens.

All fixtures:



P300182-129-30



P710049-129-30



P300182-129-30
 mounted vertical



P300182-009-30
 mounted vertical



P300182-015-30
 mounted vertical



P300182-009-30



P710049-009-30



P300182-015-30



P710049-015-30

Beam LED

22" LINEAR LED BATH
P300182-009-30 Brushed Nickel
P300182-015-30 Polished Chrome
 Installs horizontal or vertical.
 22-1/4" W., 4-3/4" ht.
 Extends 3". H/CTR 2-3/8".
 36w integrated LED, 3000K,
 90CRI, 2200 delivered lumens.

LED WALL BRACKET
P710049-009-30 Brushed Nickel
P710049-015-30 Polished Chrome
 4-3/4" W., 10-1/2" ht.
 Extends 3-1/4". H/CTR 8-3/8".
 16w integrated LED, 3000K,
 90CRI, 1000 delivered lumens.

All fixtures:



Beam LED

A clean, contemporary metal backplate holds a square tubular opal glass diffuser.

P710049-009-30 Brushed Nickel
P710049-015-30 Polished Chrome
P710049-129-30 Architectural Bronze
4-3/4" W., 10-1/2" ht., wire 6".
Extends 3-1/4". H/CTR 8-3/8".
16w integrated LED, 3000K,
90CRI, 1000 delivered lumens.



P710049-009-30



P710049-015-30



P710049-129-30