

Parallel LED

FINISHES

- Brushed Nickel - 009
- Satin Brass - 012

- Polished Chrome - 015
- Architectural Bronze - 129

P300183-009-30

The sophisticated, modern style of the Parallel Collection features crisp, tubular, opal glass diffusers, each paired with a simple modern metal backplate for an understated, elegant design.

Opal Glass Diffuser

Tubular Design



Simple and Modern

22" LINEAR LED BATH


P300183-009-30 Brushed Nickel
Installs horizontal or vertical.
22-3/8" W., 4-3/4" ht.
Extends 2-3/4". H/CTR 2-3/8".
36w integrated LED, 3000K,
90CRI, 2166 delivered lumens.

32" LINEAR LED BATH

P300184-009-30 Brushed Nickel
Installs horizontal or vertical.
32" W., 4-3/4" ht.
Extends 2-3/4". H/CTR 2-3/8".
53w integrated LED, 3000K,
90CRI, 2872 delivered lumens.

LED WALL BRACKET

P710050-009-30 Brushed Nickel
4-3/4" W., 11" ht.
Extends 2-3/4". H/CTR 7-1/2".
16w integrated LED, 3000K,
90CRI, 930 delivered lumens.

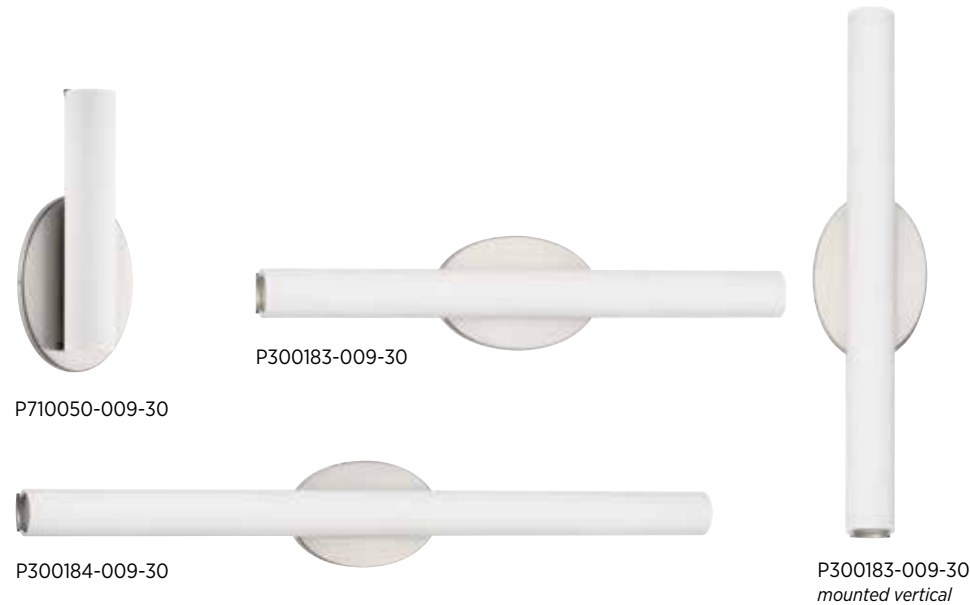

P710050-009-30

P300183-009-30

P300184-009-30

P300183-009-30
mounted vertical

All fixtures:



Parallel LED

22" LINEAR LED BATH

P300183-012-30 Satin Brass
P300183-015-30 Polished Chrome
P300183-129-30 Architectural Bronze
Installs horizontal or vertical.
22-3/8" W., 4-3/4" ht.
Extends 2-3/4". H/CTR 2-3/8".
36w integrated LED, 3000K,
90CRI, 2166 delivered lumens.


32" LINEAR LED BATH

P300184-012-30 Satin Brass
P300184-015-30 Polished Chrome
P300184-129-30 Architectural Bronze
Installs horizontal or vertical.
32" W., 4-3/4" ht.
Extends 2-3/4". H/CTR 2-3/8".
53w integrated LED, 3000K,
90CRI, 2872 delivered lumens.

LED WALL BRACKET

P710050-012-30 Satin Brass
P710050-015-30 Polished Chrome
P710050-129-30 Architectural Bronze
4-3/4" W., 11" ht.
Extends 2-3/4". H/CTR 7-1/2".
16w integrated LED, 3000K,
90CRI, 930 delivered lumens.

All fixtures:

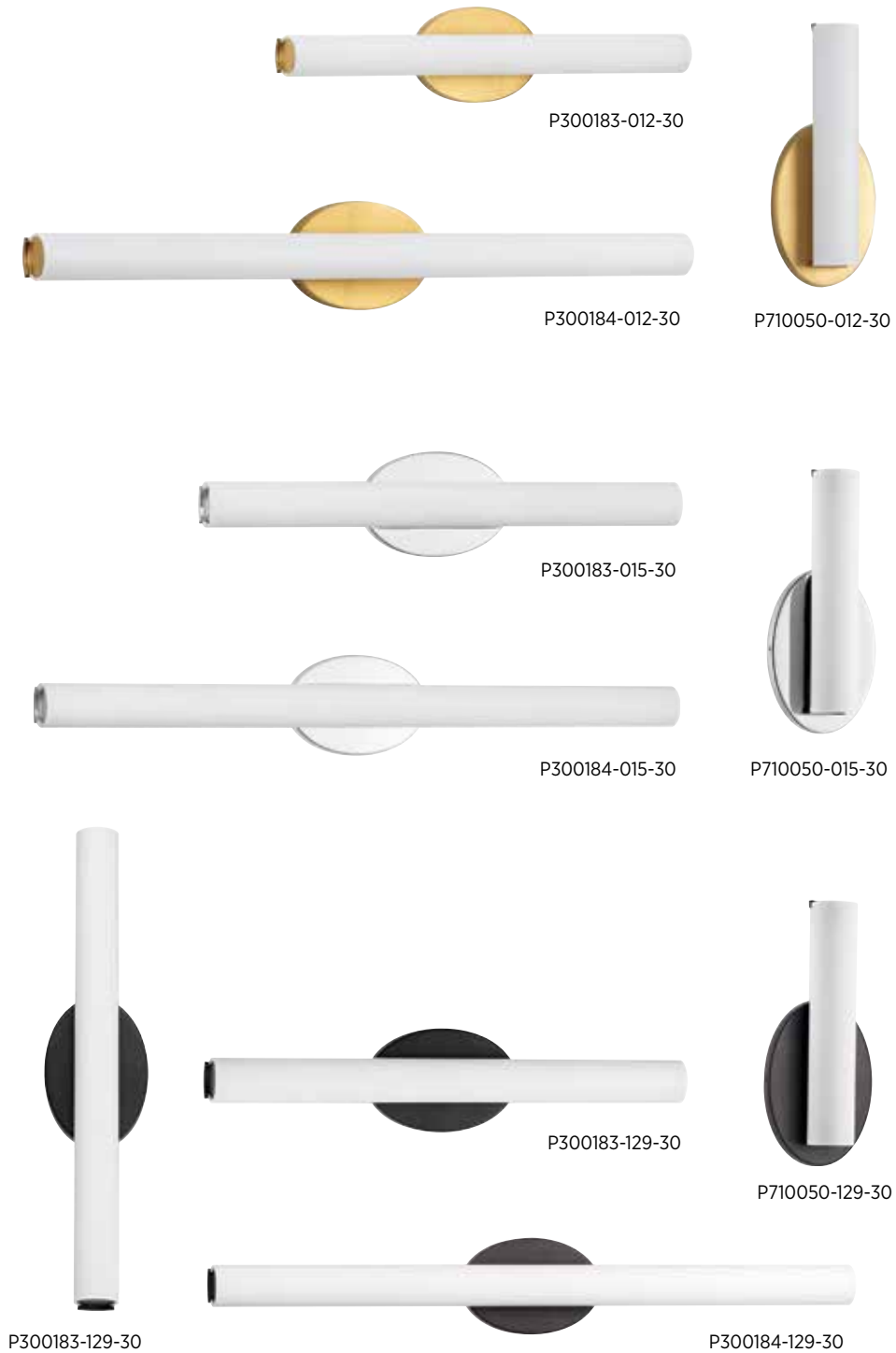

P300183-012-30

P300184-012-30

P710050-012-30

P300183-015-30

P300184-015-30

P710050-015-30

P300183-129-30

P710050-129-30

P300184-129-30

Parallel LED

A tubular opal glass diffuser is paired with a simple, modern metal backplate.

P710050-009-30 Brushed Nickel

P710050-012-30 Satin Brass

P710050-015-30 Polished Chrome

P710050-129-30 Architectural Bronze

4-3/4" W., 11" ht., wire 6".

Extends 2-3/4". H/CTR 7-1/2".

16w integrated LED, 3000K,

90CRI, 930 delivered lumens.



P710050-009-30



P710050-012-30



P710050-015-30



P710050-129-30