

# Truss LED


## FINISHES

- Brushed Nickel - 09
- Architectural Bronze - 129

P2834-0930K9

Circular etched opal glass contains an integrated LED source to provide a variety of energy and cost savings benefits for the homeowner. Modern style and even illumination are ideal for a variety of bath settings.

*Modern Style*

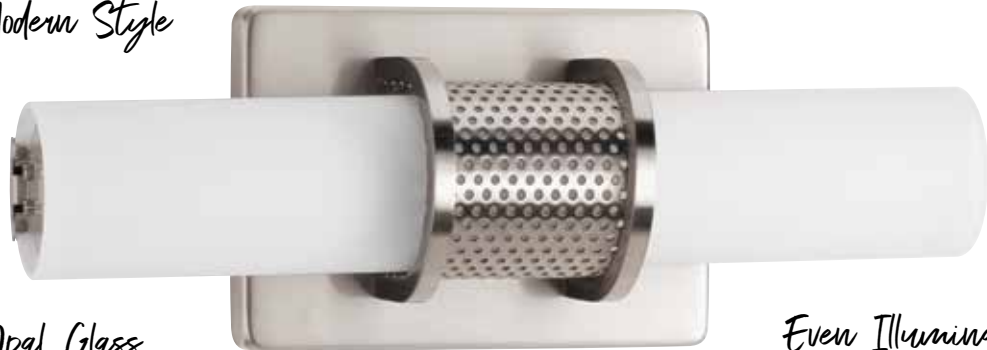

*Etched Opal Glass*

*Even Illumination*



P2839-0930K9



P2834-0930K9



P2839-12930K9  
*mounted vertical*



P2839-12930K9



P2834-12930K9

### 13" LINEAR VANITY

**P2834-0930K9** Brushed Nickel  
**P2834-12930K9** Architectural Bronze  
 13" W., 4-3/4" ht.  
 Extends 3-7/8". H/CTR 2-3/8".  
 32w integrated LED, 3000K,  
 90 CRI, 737 delivered lumens.

### 22" LINEAR VANITY

**P2839-0930K9** Brushed Nickel  
**P2839-12930K9** Architectural Bronze  
 22-1/2" W., 4-3/4" ht.  
 Extends 3-7/8". H/CTR 2-3/8".  
 37w integrated LED, 3000K,  
 90 CRI, 1222 delivered lumens.

*All fixtures can be installed horizontally or vertically.*

## Truss LED

---

A unique mesh accent holds an etched glass cylinder against a simple square backplate.



P2834-0930K9



P2834-12930K9

**P2834-0930K9** Brushed Nickel  
**P2834-12930K9** Architectural Bronze  
4-3/4" W., 13" ht.  
Extends 3-7/8". H/CTR 2-3/8".  
20w integrated LED, 3000K,  
90 CRI, 665 delivered lumens.

