


4" Recessed

Housings

For complete fixture, order housing with trim.

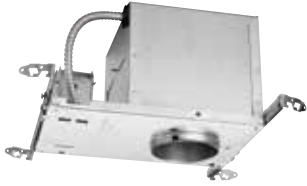

New Construction Air-Tight IC with E26 socket

P831-AT

Ceiling opening: 4-1/2"
Plaster frame: 8-3/8" x 13"
Recessed depth: 7-1/2"

P831-AT HOUSING FEATURES

- UL and CUL listed for damp locations and feed through wiring.
- Meets WSEC code requirements.
- Adjustable from 1/2" to 2-1/2" ceiling thickness.
- Notched plaster frame for easy alignment.
- Locking feature to secure housing.
- Integral T-bar clamps.
- Nail grip bar hangers accommodate up to 24" on center ceiling joists.
- Rated for 8 #12 90° conductors (4 in/4 out).
- Integral Romex clamp.
- Trim mounted socket snaps into trim for consistent lamp positioning.
- Shipped in air-tight configuration.



New Construction Non-IC with E26 socket

P830-TG

Ceiling opening: 4-1/2"
Plaster frame: 7-7/8" x 10-3/4"
Recessed depth: 5-1/2"
Pryouts: 1/2" and 3/4"

P830-AT HOUSING FEATURES

- UL and CUL listed for damp locations and feed through wiring.
- Adjustable from 1/2" to 2-1/2" ceiling thickness.
- Notched plaster frame for easy alignment.
- Locking feature to secure housing.
- Integral T-bar clamps.
- Nail grip bar hangers accommodate up to 24" on center ceiling joists.
- Rated for 8 #12 90° conductors (4 in/4 out).
- Integral Romex clamp.
- Trim mounted socket snaps into trim for consistent lamp positioning.



Remodel Non-IC with E26 socket

P832-TG

Ceiling opening: 4-1/4"
Recessed depth: 5-1/2"
Pryouts: 1/2"

P832-AT HOUSING FEATURES

- Retrofit version of P830-TG for use in existing ceilings.
- UL and CUL listed for damp locations and through wiring.
- Integral flange on housing and exclusive locking bars permits quick mounting in ceilings from 1/2" to 1" thick.
- Attached junction box with removable sides.

IC Trims & Non-IC Trims

5" outside diameter. Lamps tilt 20°.



OPEN
P8041-28 White
IC & Non-IC:
50w PAR20, R20



OPEN SHOWER TRIM
P8041WL-28 White
Wet location listed.
IC & Non-IC:
50w PAR20*

*WL trims require use with outdoor rated PAR lamps.



PINHOLE
P8042-28 White
IC & Non-IC:
40w PAR16, 30w R20



STEP BAFFLE
P8044-31 Black Baffle
P8044-09 Brushed Nickel
P8044-20 Antique Bronze
P8044-28 White Baffle
IC & Non-IC:
55w PAR16, 50w PAR20, R20



WALL WASHER
P8047-31 White w/Black Baffle
IC & Non-IC:
40w PAR16, 35w R 20



EYEBALL
P8046-28 White
P8046-09 Brushed Nickel
P8046-20 Antique Bronze
IC & Non-IC:
40w PAR16, 30w R 20

LED IC Trims



LED EYEBALL
P8046-09-30K Brushed Nickel
P8046-20-30K Antique Bronze
P8046-28-30K White
P8046-31-30K Black
9.5w integrated LED, 3000K, 90CRI, 630 lumens.



LED ROUND
P8080-09-30K Brushed Nickel
P8080-20-30K Antique Bronze
P8080-28-30K White
P8080-31-30K Black
9.5w integrated LED, 3000K, 90CRI, 630 lumens.




4" Recessed

Fire Rated Housing



For complete fixture, order housing with trim.

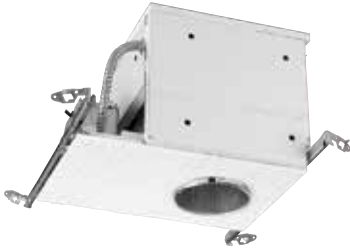

New Construction Fire Rated Ceilings with E26 socket

P831-FB

Ceiling Opening: 4-1/2"
Recessed Depth: 9-1/8"
Plaster Frame: 9-9/16" x 13-1/4"
Pryouts: 1/2" and 3/4"

P831-FB HOUSING FEATURES

- UL Classified to maintain fire ratings of 1 hour or less for L500 and G531 series roof/ceiling designs.
- UL Classified to maintain fire ratings of 2 hours or less for UL D200, D500, G200, G500, L200 and L500 series floor/ceiling designs.
- UL-CUL listed for damp location and feed through wiring.
- Non-IC rated*.
- Fits Into 2" x 10" construction.



U.S. Patent #: 5758959, 6004011, 6357891, 6254527

Trims - Non-IC

5" outside diameter. All trims have 360° positioning. Lamps tilt 20°.



OPEN
P8041-28 White
55w PAR16,
50w PAR20, R20



STEP BAFFLE
P8044-09 Brushed Nickel
P8044-31 Black
P8044-28 White
55w PAR16,
50w PAR20, R20



STEP BAFFLE
P8044-20 Antique Bronze
55w PAR16,
50w PAR20, R20



OPEN SHOWER
P8041WL-28 White
Wet location listed.
50w PAR20

Wet Location trims require use with outdoor rated PAR lamps



EYEBALL
P8046-09 Brushed Nickel
P8046-20 Antique Bronze
P8046-28 White
40w PAR16, 30w R20



WALL WASHER
P8047-31 Black Baffle
40w PAR16, 35w R20



PINHOLE SPOT
P8042-28 White
40w PAR16, 30w R20

4" Recessed LED

LED Housings

For complete fixture, order housing with trim.



New Construction Non-IC with LED Quick Connect

P830-LED

Ceiling opening: 4-1/2"
Plaster frame: 7-7/8" x 10-3/4"
Recessed depth: 5-1/2"
Pryouts: 1/2" and 3/4"

P830-LED HOUSING FEATURES

- Integral quick link connector mates with P8080 and P8046 series LED trims.



New Construction Air-Tight IC with LED Quick Connect

P831-LED

Ceiling opening: 4-1/2"
Plaster frame: 8-3/8" x 13"
Recessed depth: 7-1/2"

P831-LED HOUSING FEATURES

- Integral quick link connector mates with P8080 and P8046 series LED trims.



Remodel Non-IC with LED Quick Connect

P832-LED

Ceiling opening: 4-1/4"
Recessed depth: 5-1/2"
Pryouts: 1/2"

P832-LED HOUSING FEATURES

- Retrofit version of P830-LED for use in existing ceilings.

4" LED Round Trim

Flicker free dimming down to 10% with many Triac or forward phase dimmers. Flicker rate less than 30%.

P8080-09-30K Brushed Nickel

P8080-20-30K Antique Bronze

P8080-28-30K White

P8080-31-30K Black

9.5w integrated LED, 3000K, 90CRI, 630 lumens.



P8080-09-30K



P8080-20-30K



P8080-28-30K



P8080-31-30K

P8080 & P8046 TRIM FEATURES

- Frosted polycarbonate lens controls direct glare from LEDs.
- cULus listed for wet locations.
- Lumen output and distribution comparable to 50w R20 incandescent lamp.
- CRI is 90+.
- Suitable for use in IC or NON-IC applications.
- 50,000 hours life based on 70% lumen maintenance (TM-21).

4" LED Eyeball Trim

Flicker free dimming down to 10% with many Triac or forward phase dimmers. Flicker rate less than 30%.

P8046-09-30K Brushed Nickel

P8046-20-30K Antique Bronze

P8046-28-30K White

P8046-31-30K Black

9.5w integrated LED, 3000K, 90CRI, 630 lumens.



P8046-09-30K



P8046-20-30K



P8046-28-30K



P8046-31-30K