


Edgefield

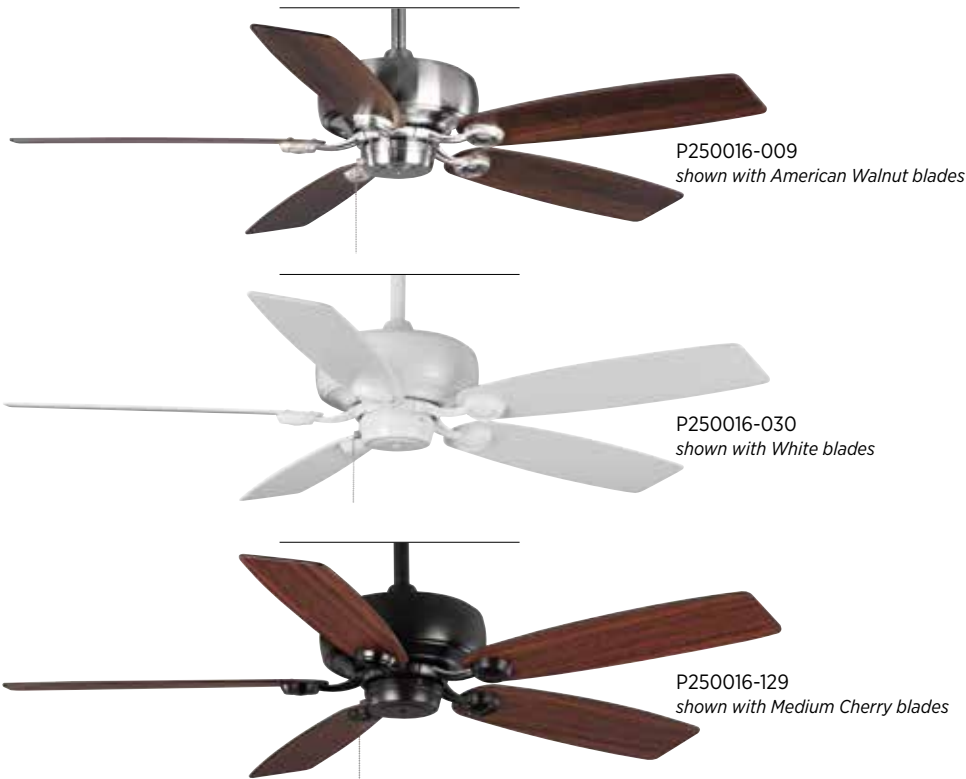

P250016-009
shown with American Walnut blades

 
P250016-030
shown with White blades

P250016-129
shown with Medium Cherry blades


FINISHES

- Brushed Nickel - 009
- White - 030
- Architectural Bronze - 129


P250016-009 Brushed Nickel



P250016-030 White

 

P250016-129 Antique Bronze

 

ENERGY INFORMATION AT HIGH SPEED

Airflow	5,741 cubic feet per minute
Electricity Use	34 watts (excludes lights)
DOE Weighted CFM/W	179 CFM/W

FEATURES

- Limited lifetime warranty
- Dual Mount (flat or sloped ceiling-18.5°)
- DC motor
- MDF blades
- Compatible with universal light kits
- Three speed pull-chain switch
- Will not accept a wall or remote control


SIZE

52" dia., 14-9/16" ht.
80" lead wires

All fixtures:



Clifton Heights

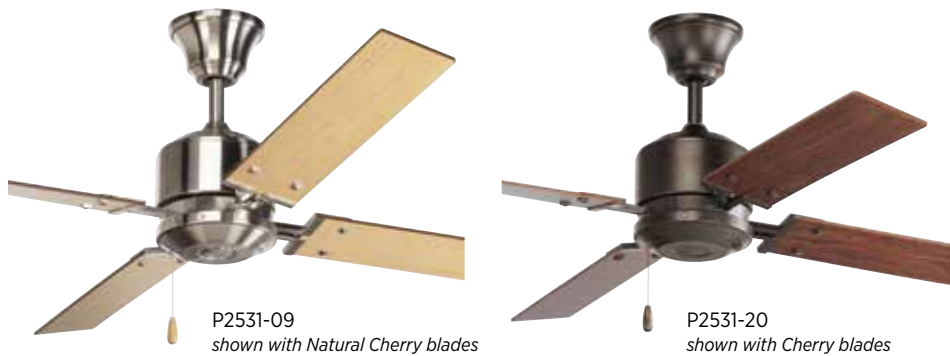


P2531-09
shown with Natural Cherry blades

P2531-20
shown with Cherry blades


FINISHES

- Brushed Nickel - 09
- Antique Bronze - 20

 P2531-09 Brushed Nickel



P2531-20 Antique Bronze

 

ENERGY INFORMATION AT HIGH SPEED

Airflow	4,373 cubic feet per minute
Electricity Use	55 watts (excludes lights)
DOE Weighted CFM/W	89 CFM/W

FEATURES

- 30-year limited warranty
- 45° Canopy
- Close-to-ceiling installation
- SureConnect System
- AC Motor
- Compatible with universal light kits
- Three speed pull-chain switch
- Add a P2630-30 or P2630-95 wall control or P2662-01 hand-held remote control

SIZE

52" dia., 15-3/4" ht.
CTC 11" ht.
80" lead wires.

CTC INSTALLATION

