

Indoor/Outdoor

Universal-style with quick-connect wiring.

SCHOOLHOUSE

P2601-20WB Antique Bronze

P2601-30WB White

P2601-80WB Forged Black

P2601-141WB Galvanized
with opal glass.

8-1/2" dia., 7" ht.

One medium base, 3000K,
LED lamp included.

800 lumens/lamp, 90 CRI.
(dimmable)



P2601-20WB



P2601-30WB



P2601-80WB



P2601-141WB



JA8



LOW PROFILE

P2611-20WB Antique Bronze

P2611-30WB White

P2611-80WB Forged Black
with opal glass.

10-1/2" dia., 4-1/2" ht.

Two medium base, 3000K,
LED lamp included.

800 lumens/lamp, 90 CRI.
(dimmable)



P2611-20WB



P2611-30WB



P2611-80WB



JA8



ASHMORE

P2636-20WB Antique Bronze
with frosted seeded glass.

11" dia., 8-1/4" ht.

Two medium base, 3000K,
LED lamp included.

800 lumens/lamp, 90 CRI.
(dimmable)



P2636-20WB



JA8



Torino

Universal-style light kit with quick-connect wiring.

P2645-77WB Forged Bronze
with tea-stained glass.

P2645-01WB

with etched glass.

Included Finials:

-09 Brushed Nickel

-20 Antique Bronze

-80 Forged Black

12" dia., 5-3/4" ht.

Two medium base, 3000K,

LED lamps included.

800 lumens/lamp, 90 CRI.

Indoor use only. (dimnable)



P2645-77WB



P2645-01WB
shown with
-09 finial



P2645-01WB
shown with
-20 finial



P2645-01WB
shown with
-80 finial

Gather, Bravo & Joy

Universal-style light kit with quick-connect wiring.

P2650-20TWB Antique Bronze
with tea-stained glass.

P2650-01WB

with etched glass.

Included Finials:

-09 Brushed Nickel

-20 Antique Bronze

11" dia., 5-1/2" ht.

Two medium base, 3000K,

LED lamps included.

800 lumens/lamp, 90 CRI.

Indoor use only. (dimnable)



P2650-20TWB



P2650-01WB
shown with
-09 finial



P2650-01WB
shown with
-20 finial

Madison

Universal-style with quick-connect wiring.

P2623-09WB Brushed Nickel

P2623-20WB Antique Bronze
with etched glass.

19" dia., 8" ht.

Three medium base, 3000K,

LED lamps included.

800 lumens/lamp, 90 CRI.

Indoor use only. (dimnable)



P2623-09WB



P2623-20WB

Universal Bowl

Universal-style with quick-connect wiring.

P2612-20TWB Antique Bronze
with tea-stained glass.

P2612-01WB

with alabaster glass.

Included Finials:

-09 Brushed Nickel

-20 Antique Bronze

-30 White

-15 Polished Chrome

-143 Graphite

10-3/4" dia., 5-1/2" ht.

Two medium base, 3000K,

LED lamps included.

800 lumens/lamp, 90 CRI.

Indoor use only. (dimmable)



P2612-20TWB



P2612-01WB
shown with
-09 finial



P2612-01WB
shown with
-15 finial



P2612-01WB
shown with
-20 finial



P2612-01WB
shown with
-30 finial



P2612-01WB
shown with
-143 finial

Wisten

Universal-style light kit with quick-connect wiring.

P2649-01WB

with etched glass.

Included Finials:

-09 Brushed Nickel

-20 Antique Bronze

11" dia., 6-1/4" ht.

Two medium base, 3000K,

LED lamps included.

800 lumens/lamp, 90 CRI.

Indoor use only. (dimmable)



P2649-01WB
shown with
-09 finial



P2649-01WB
shown with
-20 finial

Clifton Heights

Universal-style with quick-connect wiring.

P2654-01WB

with etched glass.

Included Finials:

-09 Brushed Nickel

-20 Antique Bronze

12-1/2" sq., 6-1/4" ht.

Two medium base, 3000K,

LED lamps included.

800 lumens/lamp, 90 CRI.

Indoor use only. (dimmable)



P2654-01WB
shown with
-09 finial



P2654-01WB
shown with
-20 finial

LED Light Kits

Universal-style light kits with quick connect wiring.

P2659-09 Brushed Nickel
P2659-20 Antique Bronze
P2659-30 White
 with etched white glass.
 12-1/4" dia., 4" ht.
 One 16w, 3000K
 LED module included.
 1265 source lumens,
 960 delivered lumens,
 90 CRI. Indoor use only.
 (dimmable)



P2659-09



P2659-20



P2659-30

P2660-01
 with etched alabaster glass.
 Included Finials:
 -09 Brushed Nickel
 -20 Antique Bronze
 -30 White
 11-1/4" dia., 5-3/8" ht.
 One 16w, 3000K
 LED module included.
 1241 source lumens,
 1150 delivered lumens,
 90 CRI. Indoor use only.
 (dimmable)



P2660-01
 shown with
 -09 finial



P2660-01
 shown with
 -20 finial



P2660-01
 shown with
 -30 finial

Trinity

Universal-style with quick-connect wiring.

P2628-01WB
 with etched glass.
 Included Finials:
 -09 Brushed Nickel
 -20 Antique Bronze
 -30 White
 -77 Forged Bronze
 13-3/8" dia., 6-3/8" ht.
 Two medium base, 3000K,
 LED lamps included.
 800 lumens/lamp, 90 CRI.
 Indoor use only. (dimmable)



P2628-01WB
 shown with
 -09 finial



P2628-01WB
 shown with
 -20 finial



P2628-01WB
 shown with
 -30 finial



P2628-01WB
 shown with
 -77 finial

Four Light Universal

Universal-style with quick-connect wiring.

P2643-09WB Brushed Nickel

P2643-20WB Antique Bronze

P2643-30WB White

with alabaster glass.

P2643-20TWB Antique Bronze

with tea stained alabaster glass.

13-5/8" dia., 7-3/4" ht.

Four medium base, 3000K,

LED lamps included.

800 lumens/lamp, 90 CRI.

Indoor use only. (dimnable)



P2643-09WB



P2643-20WB



P2643-30WB



P2643-20TWB

Three Light Universal

Universal-style with quick-connect wiring.

P2642-09WB Brushed Nickel

P2642-30WB White

with alabaster glass.

13-5/8" dia., 7-3/4" ht.

Three medium base, 3000K,


LED lamps included.

800 lumens/lamp, 90 CRI.

Indoor use only. (dimnable)



P2642-09WB

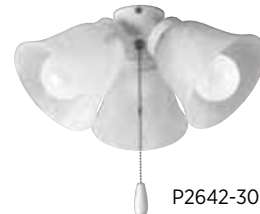

P2642-30WB

Low Profile

Universal-style with quick-connect wiring.

P2602-09WB Brushed Nickel

P2602-15WB Polished Chrome

P2602-20WB Antique Bronze

P2602-30WB White

P2602-143WB Graphite

with white opal glass.

10-1/2" dia., 4-1/2" ht.

Two medium base, 3000K,

LED lamps included.

800 lumens/lamp, 90 CRI.

Indoor use only. (dimnable)



P2602-09WB



P2602-15WB



P2602-20WB



P2602-30WB



P2602-143WB

Four Light Alabaster

Spring clip glass attachment. For use with P2500, P2501, P2502, P2524 and P2525.

P2610-09WB Brushed Nickel
P2610-15WB Polished Chrome
P2610-20WB Antique Bronze
P2610-30WB White
P2610-143WB Graphite
with alabaster glass.
14-1/2" dia., 6-1/4" ht.
Four medium base, 3000K,
LED lamps included.
800 lumens/lamp, 90 CRI.
Indoor use only. (dimnable)



Three Light Alabaster

Spring clip glass attachment. For use with P2500, P2501, P2502, P2524 and P2525.

P2600-09WB Brushed Nickel
P2600-20WB Antique Bronze
P2600-30WB White
with alabaster glass.
15" dia., 6-5/8" ht.
Three medium base, 3000K,
LED lamps included.
800 lumens/lamp, 90 CRI.
Indoor use only. (dimnable)



Schoolhouse

Universal-style with quick-connect wiring.

P2644-09WB Brushed Nickel
P2644-30WB White
with white opal glass.
8-1/2" dia., 6-1/2" ht.
One medium base, 3000K,
LED lamp included.
800 lumens/lamp, 90 CRI.
Indoor use only. (dimnable)

