

DECORATIVE MINI-FLUSH MOUNT

Round LED decorative surface mount with etched glass.



LED FEATURES

- Wet location listed
- 90+ CRI
- 50,000 hour life
- Includes mounting hardware for recessed installation in 4", 5", and 6" housings

7-1/4" ROUND TRIAC DIMMING

Flicker free dimming down to 10% with many Triac or forward phase dimmers. Flicker rate less than 30%.

P8147-09-30K Brushed Nickel
P8147-20-30K Antique Bronze
P8147-28-30K White
P8147-31-30K Black
 7-1/4" dia., 2-3/4" ht.
 One 17w LED module included
 1050 lumens, 63 lumens per watt.



7-1/4" ROUND ELV DIMMING

Flicker free dimming down to 10% with many ELV dimmers.

P8147-0930K9 Brushed Nickel
P8147-2030K9 Antique Bronze
P8147-2830K9 White
P8147-3130K9 Black
 7-1/4" dia., 2-3/4" ht.
 One 17w LED module included.
 1050 lumens, 63 lumens per watt.



5-1/2" ROUND TRIAC DIMMING

Flicker free dimming down to 10% with many Triac or forward phase dimmers. Flicker rate less than 30%.


P8247-09-30K Brushed Nickel
P8247-20-30K Antique Bronze
P8247-28-30K White
P8247-31-30K Black
 5-1/2" round, 1-1/2" ht.
 One 10.5w LED module included.
 690 lumens, 66 lumens per watt.



5-1/2" ROUND ELV DIMMING

Flicker free dimming down to 10% with many ELV dimmers.

P8247-09/30K9-AC1-L06 Brushed Nickel
P8247-20/30K9-AC1-L06 Antique Bronze
P8247-28/30K9-AC1-L06 White
P8247-31/30K9-AC1-L06 Black
 5-1/2" round, 1-1/2" ht.
 One 12w LED module included.
 630 lumens, 52 lumens per watt.

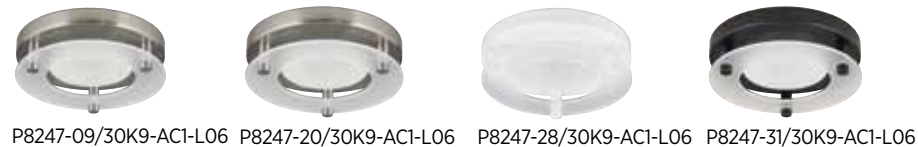

Shown: P8247-09/30K9-AC1-L06 mini flush mounts