


# MINI-FLUSH MOUNT

The LED flush mount series uses an intuitive snap-in system that makes flush mount installation easier than ever. Simply install adapter onto junction box, then snap into place using the flush mount clip.



## LED FEATURES

- Wet location listed
- 90+ CRI
- 120v input voltage AC
- 42,000 hour life
- 64 Lumens per watt
- Includes recessed mount hardware unless otherwise specified

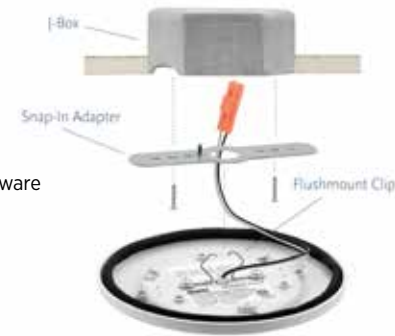

## 7-1/4" ROUND TRIAC DIMMING

Flicker free dimming down to 10% with many Triac or forward phase dimmers. Flicker rate less than 30%.

**P8022-20-30K** Antique Bronze  
**P8022-28-30K** White  
**P8022-31-30K** Black  
**P8022-82-30K** Metallic Gray  
 7-1/4" dia., 1-1/4" ht.  
 One 17w LED module included.  
 1050 lumens, 63 lumens per watt.




**P8222-28-30K** White  
 Does not include recessed mount hardware.  
 7-1/4" dia., 1-1/4" ht.  
 One 17w LED module included.  
 1050 lumens, 63 lumens per watt.



## 7-1/4" ROUND ELV DIMMING

Flicker free dimming down to 10% with many ELV dimmers.

**P8022-20/30K9-AC1-L10** Antique Bronze  
**P8022-28/30K9-AC1-L10** White  
**P8022-31/30K9-AC1-L10** Black  
**P8022-82/30K9-AC1-L10** Metallic Gray  
 7-1/4" dia., 1-1/4" ht.  
 One 17w LED module included.  
 1050 lumens, 63 lumens per watt.

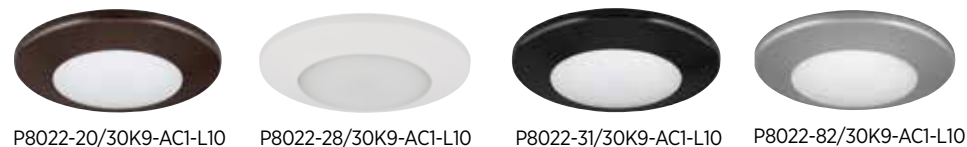


**P8222-28/30K9-AC1-L10** White  
 Does not include recessed mount hardware.  
 7-1/4" dia., 1-1/4" ht.  
 One 17w LED module included.  
 1050 lumens, 63 lumens per watt.



## 7-1/4" SQUARE ELV DIMMING

Flicker free dimming down to 10% with many ELV dimmers.

**P8027-2030K9-AC1-L10** Antique Bronze  
**P8027-2830K9-AC1-L10** White  
**P8027-3130K9-AC1-L10** Black  
**P8027-8230K9-AC1-L10** Metallic Gray  
 7-1/4" sq., 1-1/4" ht.  
 One 17w LED module included.  
 1050 lumens, 63 lumens per watt.

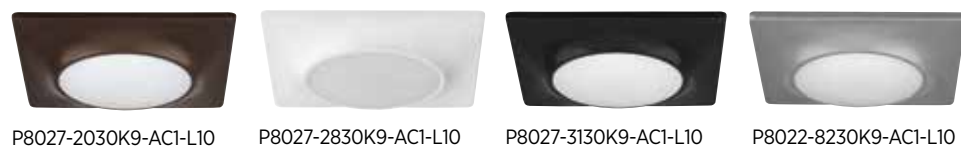

# 5-1/2" ROUND TRIAC DIMMING

Flicker free dimming with Triac or forward phase dimmers. Flicker rate less than 30%.


**P8240-20-30K** Antique Bronze  
**P8240-28-30K** White  
**P8240-31-30K** Black  
**P8240-82-30K** Metallic Gray  
 5-1/2" dia., 1-1/8" ht.  
 One 10.5w LED module included.  
 660 lumens, 62 lumens per watt.



## 5-1/2" ROUND ELV DIMMING

Flicker free dimming with many ELV dimmers.

**P8240-20/30K9-AC1-L06** Antique Bronze  
**P8240-28/30K9-AC1-L06** White  
**P8240-31/30K9-AC1-L06** Black  
**P8240-82/30K9-AC1-L06** Metallic Gray  
 5-1/2" dia., 1-1/8" ht.  
 One 12w LED module included.  
 623 lumens, 51 lumens per watt.

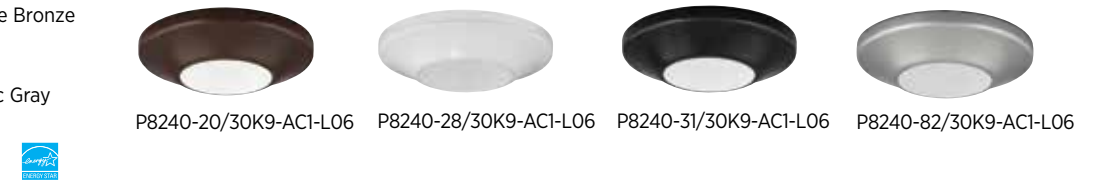

## 5-1/4" SQUARE TRIAC DIMMING

Flicker free dimming down to 10% with many Triac or forward phase dimmers. Flicker rate less than 30%.

**P8241-20-30K** Antique Bronze  
**P8241-28-30K** White  
**P8241-31-30K** Black  
**P8241-82-30K** Metallic Gray  
 5-1/4" sq., 1-1/8" ht.  
 One 10.5w LED module included.  
 645 lumens, 61 lumens per watt.



## 5-1/2" SQUARE ELV DIMMING

Flicker free dimming down to 10% with many ELV dimmers.

**P8241-20/30K9-AC1-L06** Antique Bronze  
**P8241-28/30K9-AC1-L06** White  
**P8241-31/30K9-AC1-L06** Black  
**P8241-82/30K9-AC1-L06** Metallic Gray  
 5-1/4" sq., 1-1/8" ht.  
 One 10.5w LED module included.  
 680 lumens, 64 lumens per watt.



# LED SLIM-LINE SURFACE MOUNT

Flush mount that can mount into a minimum 2" box. See progresslighting.com for compatible J boxes.

## LED SLIM-LINE SURFACE MOUNT

**P8107-2030K** Antique Bronze  
**P8107-2830K** White  
**P8107-3130K** Black  
**P8107-8230K** Metallic Gray  
 5-1/2" dia., 2-3/4" ht.  
 One 12w LED module included.  
 630 lumens, 52.5 lumens per watt.



Bracket for P8107-2830K9 shown mounted into JBox. JBox not included.