

TRIMBLE

Angular metal shades suspended from an expansive frame create a signature design statement in the Trimble Collection. Its mid-century modern inspiration incorporates a streamlined approach and rich visual details that bring iconic style to open spaces.



P400309-31M



P710113-31M



P400309-31M



P400310-31M

FINISHES

- Matte Black - 31M
- Brushed Bronze - 109

THREE-LIGHT CHANDELIER

P400309-31M Matte Black
44-1/8" dia., 11-1/8" ht.
Overall ht. w/stem 77", wire 15'.
Three medium base lamps,
each 60w max.

FOUR-LIGHT CHANDELIER

P400310-31M Matte Black
54-1/8" dia., 11-1/8" ht.
Overall ht. w/stem 77", wire 15'.
Four medium base lamps,
each 60w max.

ONE-LIGHT WALL BRACKET

P710113-31M Matte Black
10" W., 10" ht.
Extends 21-7/8", H/CTR 7".
One medium base lamp,
60w max.

TRIMBLE

THREE-LIGHT CHANDELIER

P400309-109 Brushed Bronze
44-1/8" dia., 11-1/8" ht.
Overall ht. w/stem 77", wire 15'.
Three medium base lamps,
each 60w max.



P710113-109

FOUR-LIGHT CHANDELIER

P400310-109 Brushed Bronze
54-1/8" dia., 11-1/8" ht.
Overall ht. w/stem 77", wire 15'.
Four medium base lamps,
each 60w max.



P400309-109

ONE-LIGHT WALL BRACKET

P710113-109 Brushed Bronze
10" W., 10" ht.
Extends 21-7/8", H/CTR 7".
One medium base lamp,
60w max.



P400310-109

TRIMBLE

An intriguing flat disc shade forms the basis of the Trimble Collection, whose mid-century modern inspiration is perfect for open spaces. A two-toned finish and knurled metal detailing provide rich visual interest and luxe industrial appeal.

FINISHES

- Brushed Nickel - 009
- Brushed Bronze - 109


THREE-LIGHT FLUSH MOUNT

P350248-009 Brushed Nickel
P350248-109 Brushed Bronze
18" dia., 4-1/4" ht.
Three medium base lamps,
each 60w max.

*FOUR-LIGHT CHANDELIER

P400337-009 Brushed Nickel
P400337-109 Brushed Bronze
22-3/8" dia., 7" ht.
Overall ht. w/stem 62", wire 10'.
Four medium base lamps,
each 60w max.

Fixture dimension does not include lamps.

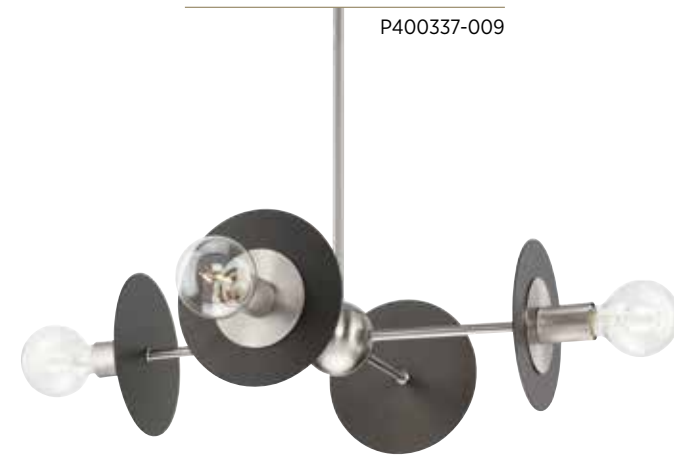

P400337-009



P400337-109



P350248-009



P350248-109

TRIMBLE



TRIMBLE

Simply curved lines form the basis of the Trimble Collection, whose mid-century modern inspiration is perfect for open spaces. A two-toned finish and graceful glass dome shade present rich visual interest while delivering pleasing diffuse illumination.



FINISHES

- Brushed Nickel - 009
- Brushed Bronze - 109

SEMI-FLUSH

P350233-009 Brushed Nickel
P350233-109 Brushed Bronze
 12" dia., 7-1/4" ht.
 One medium base lamp,
 60w max.

*ONE-LIGHT FLUSH MOUNT

P350247-009 Brushed Nickel
P350247-109 Brushed Bronze
 8" dia., 3-1/4" ht.
 One medium base lamp,
 60w max.

TWO-LIGHT ISLAND

P400336-009 Brushed Nickel
P400336-109 Brushed Bronze
 44" W., 5-3/4" ht., 8" D.
 Overall ht. w/stem 62-1/2", wire 10'.
 Two medium base lamps,
 each 60w max.

*ONE-LIGHT PENDANT

P500392-009 Brushed Nickel
P500392-109 Brushed Bronze
 8" dia., 2-1/2" ht.
 Overall ht. w/stem 59", wire 10'.
 One medium base lamp,
 60w max.

ONE-LIGHT PENDANT

P500394-009 Brushed Nickel
P500394-109 Brushed Bronze
 18" dia., 7-1/4" ht.
 Overall ht. w/stem 72", wire 10'.
 One medium base lamp,
 100w max.

*ONE-LIGHT WALL BRACKET

P710112-009 Brushed Nickel
P710112-109 Brushed Bronze
 8" W., 6" ht.
 Extends 9-7/8", H/CTR 2-5/8".
 One medium base lamp,
 60w max.

**Fixture dimension does not include lamps.*