


# 16,000 lb. Series Guy Strains - Thimble / Thimble

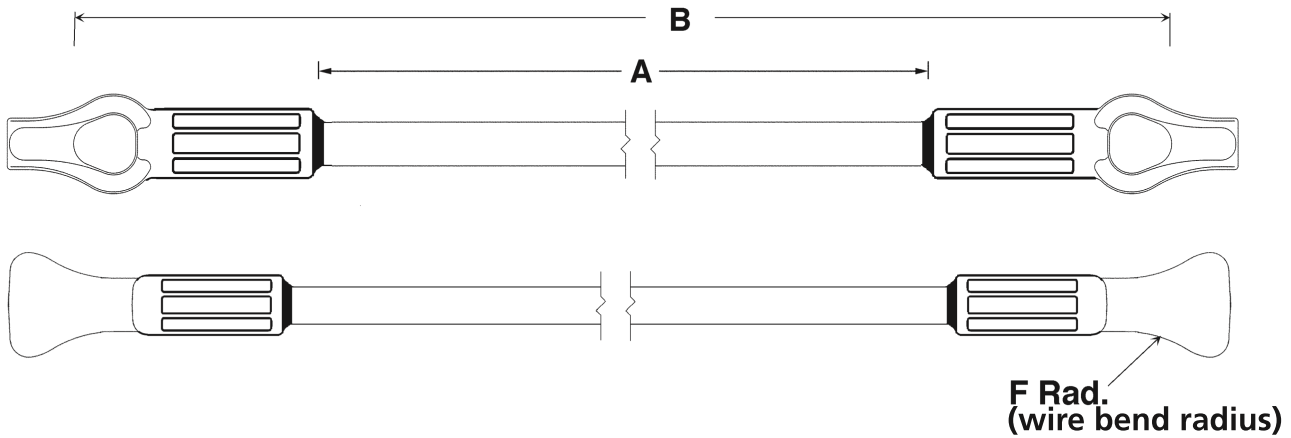

5/8" dia. Fiberglass rod.  
Castings are hot-dip galvanized ductile iron.

**RUS Accepted.**

Catalog Number	Length A	Length B	Radius F	Weight (Each)
<b>16,000 lbs. (7258 kg) Minimum Ultimate Strength*</b>				
GS16012TT	12" (30.5 cm)	19.2" (48.8 cm)	0.75" (19 mm)	2.8 lbs. (1.3 kg)
GS16018TT	18" (45.7 cm)	25.2" (64.0 cm)	0.75" (19 mm)	2.9 lbs. (1.3 kg)
GS16036TT	36" (91.4 cm)	43.2" (109.7 cm)	0.75" (19 mm)	3.3 lbs. (1.5 kg)
GS16042TT	42" (106.7 cm)	49.2" (125.0 cm)	0.75" (19 mm)	3.4 lbs. (1.5 kg)
GS16054TT	54" (137.2 cm)	61.2" (155.4 cm)	0.75" (19 mm)	3.7 lbs. (1.7 kg)
GS16078TT	78" (198.1 cm)	85.2" (216.4 cm)	0.75" (19 mm)	4.2 lbs. (1.9 kg)

*Consult factory for additional lengths.*

*Add "SC" suffix to the end of the catalog number to denote Silicone Coated rod*

**\*Recommended maximum working load is 50% of minimum ultimate ratings listed.**

