


## 21,000 lb. Series Guy Strains - Clevis / Thimble-Eye

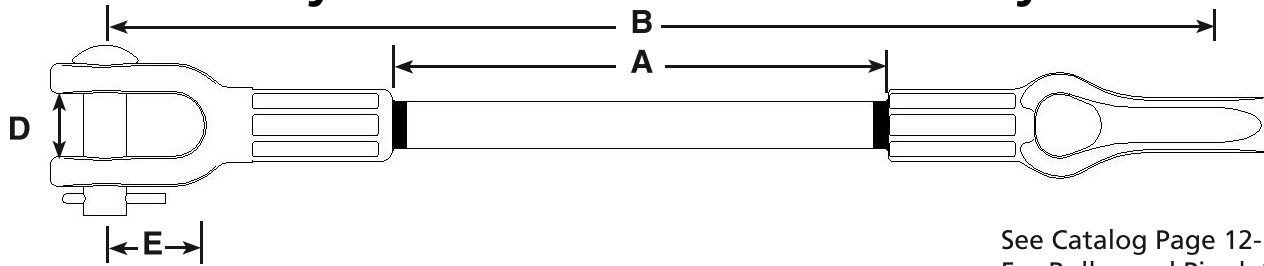

See Catalog Page 12-17  
For Roller and Pin details



See Note For Roller Configurations

C Dimension is 5/8" (16 mm) for 21,000 lbs. series  
D Dimension is 0.9" (23 mm) for 21,000 lbs. series  
E Dimension is 1.4" (36 mm) for 21,000 lbs. series

5/8" dia. Fiberglass rod.  
Castings are hot-dip galvanized ductile iron.

**RUS Accepted.**

Catalog Number	Length A	Length B	Radius F	Weight (Each)
<b>21,000 lbs. (9525 kg) Minimum Ultimate Strength*</b>				
GS21012CP	12" (30.5 cm)	22" (55.9 cm)	0.78" (20 mm)	4.5 lbs. (2.0 kg)
GS21018CP	18" (45.7 cm)	28" (71.1 cm)	0.78" (20 mm)	4.6 lbs. (2.1 kg)
GS21024CP	24" (61.0 cm)	34" (86.4 cm)	0.78" (20 mm)	4.8 lbs. (2.2 kg)
GS21036CP	36" (91.4 cm)	46" (116.8 cm)	0.78" (20 mm)	5.1 lbs. (2.3 kg)
GS21054CP	54" (137.2 cm)	64" (162.6 cm)	0.78" (20 mm)	5.7 lbs. (2.6 kg)
GS21060CP	60" (152.4 cm)	70" (177.8 cm)	0.78" (20 mm)	5.8 lbs. (2.6 kg)
GS21078CP	78" (198.1 cm)	88" (223.5 cm)	0.78" (20 mm)	6.4 lbs. (2.9 kg)
GS21096CP	96" (243.8 cm)	106" (269.2 cm)	0.78" (20 mm)	6.9 lbs. (3.1 kg)
GS21120CP	120" (304.8 cm)	130" (330.2 cm)	0.78" (20 mm)	7.6 lbs. (3.4 kg)
GS21144CP	144" (365.8 cm)	154" (391.2 cm)	0.78" (20 mm)	8.3 lbs. (3.7 kg)

GS—CP series has No Roller as detailed in drawing  
For 1 Roller, replace "CP" in number with "CP1"  
Add "SC" suffix to the end of the catalog number to denote Silicone Coated rod

\*Recommended maximum working load is 50% of minimum ultimate ratings listed.

