


30,000 lb. SERIES Guy Strains - Clevis / Thimble-Eye

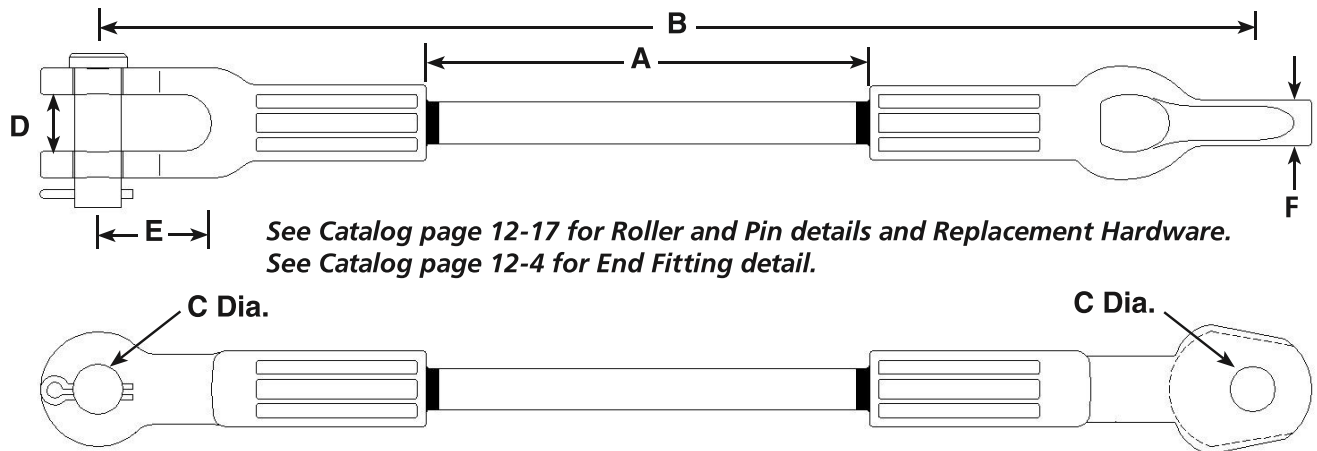

See Note For Roller Configurations

- C Dimension is 3/4" for 30,000 lbs. series
- D Dimension is 1" for 30,000 lbs. series
- E Dimension is 2.04" for 30,000 lbs. series
- F Dimension is 0.83" for 30,000 lbs. series

3/4" dia. Fiberglass rod.

Castings are hot-dip galvanized ductile iron.

Catalog Number	Length A	Length B	Weight (Each)
30,000 lbs. (13,608 kg) Minimum Ultimate Strength*			
GS30012CP	12" (30.5 cm)	25" (63.5 cm)	5.4 lbs. (2.4 kg)
GS30018CP	18" (45.8 cm)	31" (78.7 cm)	5.6 lbs. (2.5 kg)
GS30024CP	24" (61.0 cm)	37" (94.0 cm)	5.8 lbs. (2.6 kg)
GS30030CP	30" (76.2 cm)	43" (109.2 cm)	6.0 lbs. (2.7 kg)
GS30036CP	36" (91.4 cm)	49" (124.5 cm)	6.2 lbs. (2.8 kg)
GS30042CP	42" (106.7 cm)	55" (139.7 cm)	6.4 lbs. (2.9 kg)
GS30048CP	48" (121.9 cm)	61" (154.9 cm)	6.6 lbs. (3.0 kg)
GS30054CP	54" (137.2 cm)	67" (170.2 cm)	6.7 lbs. (3.0 kg)
GS30060CP	60" (152.4 cm)	73" (185.4 cm)	6.9 lbs. (3.1 kg)
GS30072CP	72" (182.9 cm)	85" (215.9 cm)	7.3 lbs. (3.3 kg)
GS30078CP	78" (198.1 cm)	91" (231.1 cm)	7.5 lbs. (3.4 kg)
GS30084CP	84" (213.4 cm)	97" (246.4 cm)	7.7 lbs. (3.5 kg)
GS30090CP	90" (228.6 cm)	103" (261.6 cm)	7.9 lbs. (3.6 kg)
GS30096CP	96" (243.8 cm)	109" (276.9 cm)	8.1 lbs. (3.7 kg)
GS30108CP	108" (274.3 cm)	121" (307.3 cm)	8.5 lbs. (3.9 kg)
GS30120CP	120" (304.8 cm)	133" (337.8 cm)	8.8 lbs. (4.0 kg)
GS30144CP	144" (365.8 cm)	157" (398.8 cm)	9.6 lbs. (4.4 kg)

GS—CP series has No Roller as detailed in drawing

For 1 Roller, replace "CP" in number with "CP1"

Add "SC" suffix to the end of the catalog number to denote Silicone Coated Rod

*Recommended maximum working load is 50% of minimum ultimate ratings listed.