
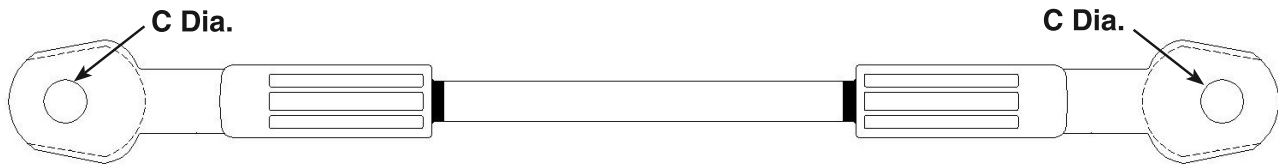


30,000 lb. SERIES Guy Strains - Thimble-Eye / Thimble-Eye

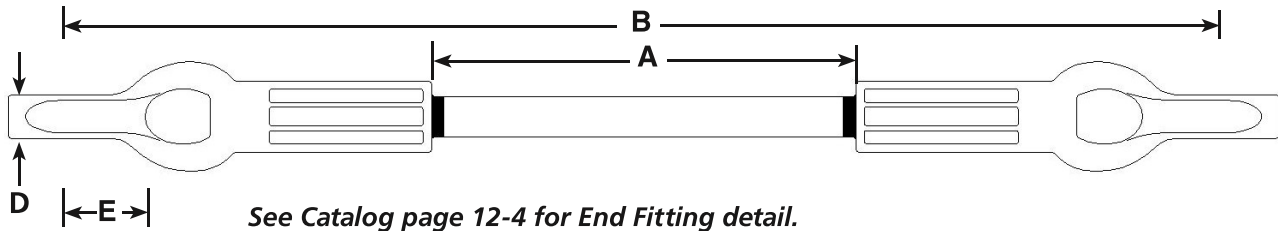

- C Dimension is 3/4" for 30,000 lbs. series
- D Dimension is 0.83" for 30,000 lbs. series
- E Dimension is 1.44" for 30,000 lbs. series

3/4" dia. Fiberglass rod.
Castings are hot-dip galvanized ductile iron.

Catalog Number	Length A	Length B	Weight (Each)
30,000 lbs. (13,608 kg) Minimum Ultimate Strength*			
GS30012PP	12" (30.5 cm)	26" (66.0 cm)	5.4 lbs. (2.4 kg)
GS30018PP	18" (45.8 cm)	32" (81.3 cm)	5.6 lbs. (2.5 kg)
GS30024PP	24" (61.0 cm)	38" (96.5 cm)	5.8 lbs. (2.6 kg)
GS30030PP	30" (76.2 cm)	44" (111.8 cm)	6.0 lbs. (2.7 kg)
GS30036PP	36" (91.4 cm)	50" (127.0 cm)	6.2 lbs. (2.8 kg)
GS30042PP	42" (106.7 cm)	56" (142.2 cm)	6.4 lbs. (2.9 kg)
GS30048PP	48" (121.9 cm)	62" (157.5 cm)	6.6 lbs. (3.0 kg)
GS30054PP	54" (137.2 cm)	68" (172.7 cm)	6.7 lbs. (3.0 kg)
GS30060PP	60" (152.4 cm)	74" (188.0 cm)	6.9 lbs. (3.1 kg)
GS30072PP	72" (182.9 cm)	86" (218.4 cm)	7.3 lbs. (3.3 kg)
GS30078PP	78" (198.1 cm)	92" (233.7 cm)	7.5 lbs. (3.4 kg)
GS30084PP	84" (213.4 cm)	98" (248.9 cm)	7.7 lbs. (3.5 kg)
GS30090PP	90" (228.6 cm)	104" (264.2 cm)	7.9 lbs. (3.6 kg)
GS30096PP	96" (243.8 cm)	110" (279.4 cm)	8.1 lbs. (3.7 kg)
GS30108PP	108" (274.3 cm)	122" (309.9 cm)	8.5 lbs. (3.9 kg)
GS30120PP	120" (304.8 cm)	134" (340.4 cm)	8.8 lbs. (4.0 kg)
GS30144PP	144" (365.8 cm)	158" (401.3 cm)	9.6 lbs. (4.4 kg)

Add "SC" suffix to the end of the catalog number to denote Silicone Coated Rod

*Recommended maximum working load is 50% of minimum ultimate ratings listed.

