

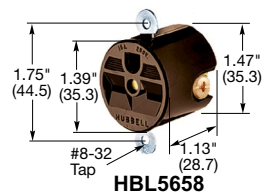
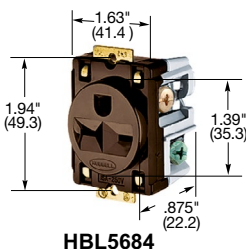
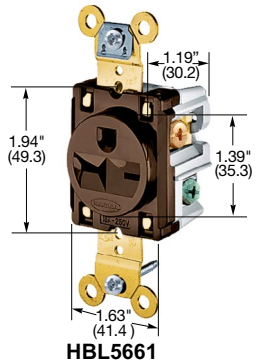
 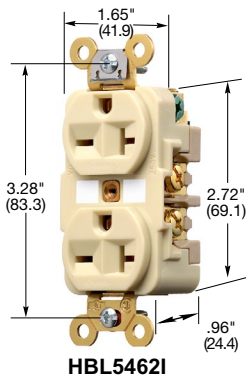


15 and 20 Ampere, 250 Volts

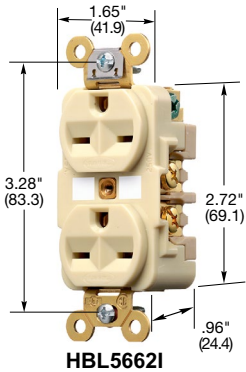

Dimensions in Inches (mm)

HBL® Extra Heavy Duty Max Specification Grade Receptacles



Duplex	Color	Catalog Number	
Flush, nylon face, back and side wired, multiple drive screws.	Black	—	HBL5462BK
	Brown	HBL5662	HBL5462
	Gray	—	HBL5462GY
	Ivory	HBL5662I	HBL5462I
	Red	—	HBL5462R
Isolated ground ^A .	Orange	IG5662	IG5462

Single	Color	Catalog Number	
Flush, nylon face, back and side wired.	Brown	HBL5661	HBL5461
	Gray	—	HBL5461GY
	Ivory	HBL5661I	HBL5461I
	Red	—	HBL5461R
	White	—	HBL5461W
Isolated ground ^A .	Orange	IG5661	IG5461
Panel mount 1.94 in. (49.3) centers.	Brown	HBL5684	—
Ring terminal connection.	Brown	HBL5661RT	—

Duplex and Single Panel Mount	Color	Catalog Number	
Flush, nylon duplex face, side wired only.	Brown	HBL5662	—
	Ivory	HBL5662I	—
Panel mount 1.75 in. (44.5) centers.	Brown	HBL5658	—

Note: ^ASee section N for additional information on isolated ground devices.
HP ratings are AC only.
See page A-47 for accessories.
See section O for wallplates.