



# Straight Blade Devices




15 and 20 Ampere, 125 Volts

## SNAPConnect® Extra Heavy Duty Hospital Grade Receptacles

  
**IP20**  
SUITABILITY




Duplex	Color	Catalog Number	Catalog Number	
Hospital grade, finder groove, nylon face, modular receptacle which requires pigtailed connector on page A-15.	Black	<b>SNAP8200BKA</b>	<b>SNAP8300BKA</b>	
	Brown	<b>SNAP8200A</b>	<b>SNAP8300A</b>	
	Gray	<b>SNAP8200GYA</b>	<b>SNAP8300GYA</b>	
	Ivory	<b>SNAP8200IA</b>	<b>SNAP8300IA</b>	
	Light Almond	<b>SNAP8200LAA</b>	<b>SNAP8300LAA</b>	
	Red	<b>SNAP8200RA</b>	<b>SNAP8300RA</b>	
Hospital grade, smooth nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.	Black	<b>SNAP8200BKNA</b>	<b>SNAP8300BKNA</b>	
	Brown	<b>SNAP8200NA</b>	<b>SNAP8300NA</b>	
	Gray	<b>SNAP8200GYNA</b>	<b>SNAP8300GYNA</b>	
	Ivory	<b>SNAP8200INA</b>	<b>SNAP8300INA</b>	
	Light Almond	<b>SNAP8200LANA</b>	<b>SNAP8300LANA</b>	
	Red	<b>SNAP8200RNA</b>	<b>SNAP8300RNA</b>	
Hospital grade, Tamper-Resistant, smooth nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.	Black	<b>SNAP8200BKTRA</b>	<b>SNAP8300BKTRA</b>	
	Brown	<b>SNAP8200TRA</b>	<b>SNAP8300TRA</b>	
	Gray	<b>SNAP8200GYTRA</b>	<b>SNAP8300GYTRA</b>	
	Ivory	<b>SNAP8200ITRA</b>	<b>SNAP8300ITRA</b>	
	Light Almond	<b>SNAP8200LATRA</b>	<b>SNAP8300LATRA</b>	
	Red	<b>SNAP8200RTRA</b>	<b>SNAP8300RTRA</b>	
Hospital grade, Tamper-Resistant, Split Circuit, smooth nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.	Black	<b>SNAP8200BKSCTRA</b>	<b>SNAP8300BKSCTRA</b>	
	Brown	<b>SNAP8200SCTRA</b>	<b>SNAP8300SCTRA</b>	
	Gray	<b>SNAP8200GYSCTRA</b>	<b>SNAP8300GYSCTRA</b>	
	Ivory	<b>SNAP8200ISCTRA</b>	<b>SNAP8300ISCTRA</b>	
	Light Almond	<b>SNAP8200LASCTRA</b>	<b>SNAP8300LASCTRA</b>	
	Red	<b>SNAP8200RSCTRA</b>	<b>SNAP8300RSCTRA</b>	
Isolated ground <sup>A</sup> , Hospital grade, Tamper-Resistant.	Orange	<b>SNAP8200IGTRA</b>	<b>SNAP8300IGTRA</b>	
	Red	<b>SNAP8200RIGTRA</b>	<b>SNAP8300RIGTRA</b>	
	Hospital grade, with Power Indicating LED, smooth nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.	Black	<b>SNAP8200BKL</b>	<b>SNAP8300BKL</b>
		Brown	<b>SNAP8200L</b>	<b>SNAP8300L</b>
		Gray	<b>SNAP8200GYL</b>	<b>SNAP8300GYL</b>
		Ivory	<b>SNAP8200IL</b>	<b>SNAP8300IL</b>
Light Almond		<b>SNAP8200LAL</b>	<b>SNAP8300LAL</b>	
Red		<b>SNAP8200RL</b>	<b>SNAP8300RL</b>	
Isolated ground <sup>A</sup> , Hospital grade, with Power Indicating LED.	Orange	<b>SNAP8200IGL</b>	<b>SNAP8300IGL</b>	
	Red	<b>SNAP8200RIGL</b>	<b>SNAP8300RIGL</b>	
	Hospital grade, Tamper-Resistant, with Power Indicating LED, smooth nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.	Black	<b>SNAP8200BKLTR</b>	<b>SNAP8300BKLTR</b>
		Brown	<b>SNAP8200LTR</b>	<b>SNAP8300LTR</b>
		Gray	<b>SNAP8200GYLTR</b>	<b>SNAP8300GYLTR</b>
		Ivory	<b>SNAP8200ILTR</b>	<b>SNAP8300ILTR</b>
Light Almond		<b>SNAP8200LALTR</b>	<b>SNAP8300LALTR</b>	
Red		<b>SNAP8200RLTR</b>	<b>SNAP8300RLTR</b>	
Hospital grade, Tamper-Resistant, with Power Indicating Face, smooth face, modular receptacle which requires pigtailed connector on page A-15.	White	<b>SNAP8200WLTR</b>	<b>SNAP8300WLTR</b>	
	Gray	<b>SNAP8200GYLTR</b>	<b>SNAP8300GYLTR</b>	
	Ivory	<b>SNAP8200ILTR</b>	<b>SNAP8300ILTR</b>	
	Red	<b>SNAP8200RLTR</b>	<b>SNAP8300RLTR</b>	
	White	<b>SNAP8200WLTR</b>	<b>SNAP8300WLTR</b>	
	Isolated ground <sup>A</sup> , Hospital grade, TR with Power Indicating LED.	Orange	<b>SNAP8200IGLTRA</b>	<b>SNAP8300IGLTRA</b>
Red		<b>SNAP8200RIGLTRA</b>	<b>SNAP8300RIGLTRA</b>	

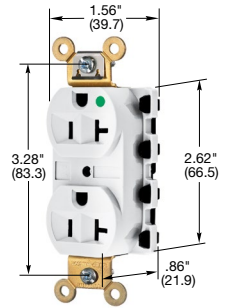


SNAP8300WA

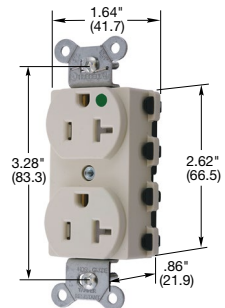


SNAP8300LATRA

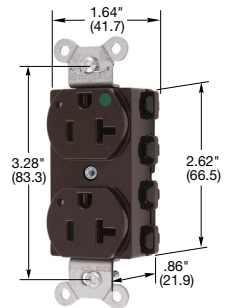

SNAP8300L

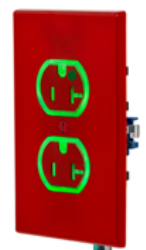

SNAP8300RLTR

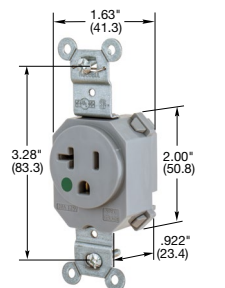

SNAP8310GY

Dimensions in Inches (mm)

## SNAPConnect® Extra Heavy Duty Hospital Grade Single Receptacles

Color	Hospital Grade		Hospital Grade Tamper-Resistant	
	15A 125V	20A 125V	15A 125V	20A 125V
Black	<b>SNAP8210BK</b>	<b>SNAP8310BK</b>	<b>SNAP8210BKTR</b>	<b>SNAP8310BKTR</b>
Blue	<b>SNAP8210BL</b>	<b>SNAP8310BL</b>	<b>SNAP8210BLTR</b>	<b>SNAP8310BLTR</b>
Brown	<b>SNAP8210</b>	<b>SNAP8310</b>	<b>SNAP8210TR</b>	<b>SNAP8310TR</b>
Gray	<b>SNAP8210GY</b>	<b>SNAP8310GY</b>	<b>SNAP8210GYTR</b>	<b>SNAP8310GYTR</b>
Ivory	<b>SNAP8210I</b>	<b>SNAP8310I</b>	<b>SNAP8210ITR</b>	<b>SNAP8310ITR</b>
Light Almond	<b>SNAP8210LA</b>	<b>SNAP8310LA</b>	<b>SNAP8210LATR</b>	<b>SNAP8310LATR</b>
Red	<b>SNAP8210R</b>	<b>SNAP8310R</b>	<b>SNAP8210RTR</b>	<b>SNAP8310RTR</b>
White	<b>SNAP8210W</b>	<b>SNAP8310W</b>	<b>SNAP8210WTR</b>	<b>SNAP8310WTR</b>