




15 and 20 Ampere, 125 Volts

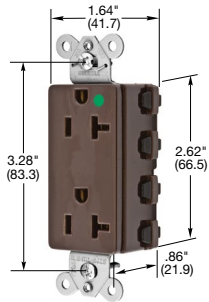


SNAP2182A

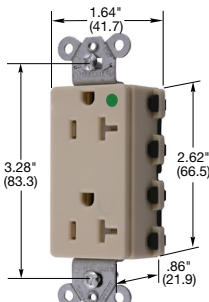


SNAP2182ITRA

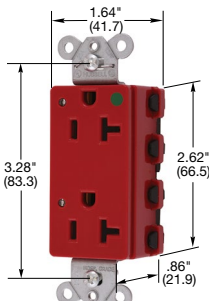

SNAP2182RL

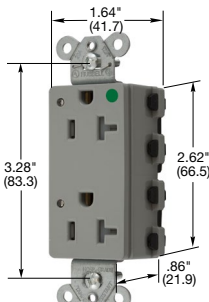

SNAP2182GYLTRA

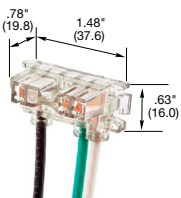

SNAP1RA

Dimensions in Inches (mm)

IP20
SUITABILITY



15A 125V
NEMA 5-15R
UL CSA
0.5 HP



20A 125V
NEMA 5-20R
UL CSA
1 HP

SNAPConnect® Extra Heavy Duty Hospital Grade Receptacles

Style Line® Decorator

Hospital grade, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector on page A-15.

Hospital grade, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.



Hospital grade, Tamper-Resistant, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.



Hospital grade, Tamper-Resistant, Split Circuit, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.



Isolated ground^A, Hospital grade, Tamper-Resistant.

Hospital grade, with Power Indicating LED, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.



Isolated ground^A, Hospital grade, with Power Indicating LED.



Hospital grade, Tamper-Resistant, with Power Indicating LED, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.

Isolated ground^A, Hospital grade, TR with Power Indicating LED.

Note: See section N additional information on isolated ground devices and section O for wallplates. See page A-5 for additional information on SNAPConnect features. See page Tech-10 for Tamper-Resistant and LED Power Indicators descriptions. See pages A-47 and A-48 for accessories.

SNAPConnect® Right Angle Pigtailed Connector

Description	Wire Type	General Use	Assembled in USA
Clear right angle terminal with 6 inch leads #12 AWG THHN/THWN-2; Polycarbonate housing material.	Solid	SNAP1RA	SNAP1RNA
	Stranded	SNAP2RA	SNAP2RNA
Clear right angle terminal with 6 inch leads #12 AWG THHN/THWN-2; Polycarbonate housing material with WAGO terminals.	Solid	SNAP1RAM2	SNAP1RNAM2
	Stranded	SNAP2RAM2	SNAP2RNAM2

Note: For Assembled in USA products, must order connector with NA suffix.