

# Straight Blade Devices



15 and 20 Ampere, 125 Volts



15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP




20A 125V  
NEMA 5-20R  
UL CSA  
1 HP


## SNAPConnect®

### Extra Heavy Duty Receptacles


Duplex	Color	Catalog Number	Catalog Number
Specification grade, finder groove, nylon face, modular receptacle which requires pigtailed connector on page A-13.	Black	<b>SNAP5262BKBA</b>	<b>SNAP5362BKBA</b>
	Brown	<b>SNAP5262A</b>	<b>SNAP5362A</b>
	Gray	<b>SNAP5262GYA</b>	<b>SNAP5362GYA</b>
	Ivory	<b>SNAP5262IA</b>	<b>SNAP5362IA</b>
	Light Almond	<b>SNAP5262LAA</b>	<b>SNAP5362LAA</b>
	Red	<b>SNAP5262RA</b>	<b>SNAP5362RA</b>
	White	<b>SNAP5262WA</b>	<b>SNAP5362WA</b>
Specification grade, smooth, nylon face, modular receptacle which requires pigtailed connector on page A-13. Assembled in USA.	Black	<b>SNAP5262BKNA</b>	<b>SNAP5362BKNA</b>
	Brown	<b>SNAP5262NA</b>	<b>SNAP5362NA</b>
	Gray	<b>SNAP5262GYNA</b>	<b>SNAP5362GYNA</b>
	Ivory	<b>SNAP5262INA</b>	<b>SNAP5362INA</b>
	Light Almond	<b>SNAP5262LANA</b>	<b>SNAP5362LANA</b>
	Red	<b>SNAP5262RNA</b>	<b>SNAP5362RNA</b>
	White	<b>SNAP5262WNA</b>	<b>SNAP5362WNA</b>
Specification grade, Tamper-Resistant, smooth nylon face, modular receptacle which requires pigtailed connector on page A-13. Assembled in USA.	Black	<b>SNAP5262BKTR</b>	<b>SNAP5362BKTR</b>
	Blue	<b>SNAP5262BLTR</b>	<b>SNAP5362BLTR</b>
	Brown	<b>SNAP5262TRA</b>	<b>SNAP5362TRA</b>
	Gray	<b>SNAP5262GYTRA</b>	<b>SNAP5362GYTRA</b>
	Ivory	<b>SNAP5262ITRA</b>	<b>SNAP5362ITRA</b>
	Light Almond	<b>SNAP5262LATRA</b>	<b>SNAP5362LATRA</b>
	Red	<b>SNAP5262RTRA</b>	<b>SNAP5362RTRA</b>
White	<b>SNAP5262WTRA</b>	<b>SNAP5362WTRA</b>	
Specification grade, Tamper-Resistant, Split Circuit, smooth nylon face, modular receptacle which requires pigtailed connector on page A-13. Assembled in USA.	Black	<b>SNAP5262BKSCTRA</b>	<b>SNAP5362BKSCTRA</b>
	Blue	<b>SNAP5262BLSCTRA</b>	<b>SNAP5362BLSCTRA</b>
	Brown	<b>SNAP5262SCTRA</b>	<b>SNAP5362SCTRA</b>
	Gray	<b>SNAP5262GYSCTRA</b>	<b>SNAP5362GYSCTRA</b>
	Ivory	<b>SNAP5262ISCTRA</b>	<b>SNAP5362ISCTRA</b>
	Light Almond	<b>SNAP5262LASCTRA</b>	<b>SNAP5362LASCTRA</b>
	Red	<b>SNAP5262RSCTRA</b>	<b>SNAP5362RSCTRA</b>
White	<b>SNAP5262WSCTRA</b>	<b>SNAP5362WSCTRA</b>	
Isolated ground <sup>4</sup> , Specification grade, Tamper-Resistant.	Orange	<b>SNAP5262IGTRA</b>	<b>SNAP5362IGTRA</b>
Spec. grade, with Power Indicating LED, smooth nylon face, modular receptacle which requires pigtailed connector on page A-13. Assembled in USA.	Black	<b>SNAP5262BKL</b>	<b>SNAP5362BKL</b>
	Blue	<b>SNAP5262BLL</b>	<b>SNAP5362BLL</b>
	Brown	<b>SNAP5262L</b>	<b>SNAP5362L</b>
	Gray	<b>SNAP5262GYL</b>	<b>SNAP5362GYL</b>
	Ivory	<b>SNAP5262IL</b>	<b>SNAP5362IL</b>
	Light Almond	<b>SNAP5262LAL</b>	<b>SNAP5362LAL</b>
	Red	<b>SNAP5262RL</b>	<b>SNAP5362RL</b>
White	<b>SNAP5262WL</b>	<b>SNAP5362WL</b>	
Isolated ground <sup>4</sup> , Specification grade, with Power Indicating LED.	Orange	<b>SNAP5262IGL</b>	<b>SNAP5362IGL</b>
Specification grade, Tamper-Resistant, with Power Indicating LED, smooth nylon face, modular receptacle which requires pigtailed connector on page A-13. Assembled in USA.	Black	<b>SNAP5262BKLTR</b>	<b>SNAP5362BKLTR</b>
	Blue	<b>SNAP5262BLLTR</b>	<b>SNAP5362BLLTR</b>
	Brown	<b>SNAP5262LTR</b>	<b>SNAP5362LTR</b>
	Gray	<b>SNAP5262GYLTR</b>	<b>SNAP5362GYLTR</b>
	Ivory	<b>SNAP5262ILTR</b>	<b>SNAP5362ILTR</b>
	Light Almond	<b>SNAP5262LALTR</b>	<b>SNAP5362LALTR</b>
	Red	<b>SNAP5262RLTR</b>	<b>SNAP5362RLTR</b>
White	<b>SNAP5262WLTR</b>	<b>SNAP5362WLTR</b>	
Isolated ground <sup>4</sup> , Specification grade, TR with Power Indicating LED.	Orange	<b>SNAP5262IGLTR</b>	<b>SNAP5362IGLTR</b>

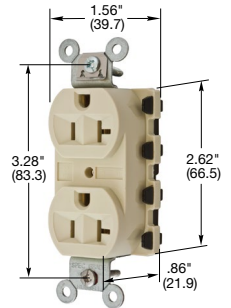


SNAP5362IA

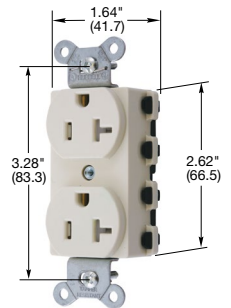


SNAP5362LA-

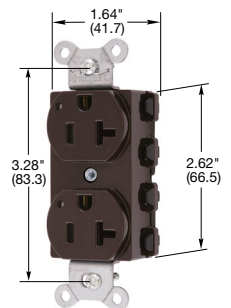

SNAP5362L

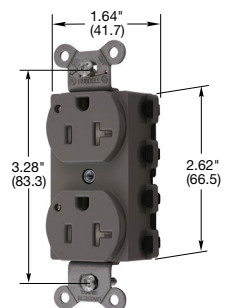

SNAP5362IGLTRA

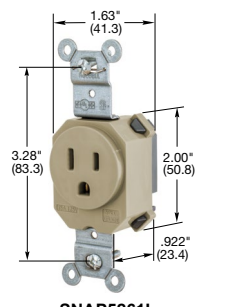

SNAP5261I

Dimensions in Inches (mm)

## SNAPConnect® Extra Heavy Duty Standard Single Receptacles

Color	Standard Duplex		Standard Duplex Tamper-Resistant	
	15A 125V	20A 125V	15A 125V	20A 125V
Black	<b>SNAP5261BK</b>	<b>SNAP5361BK</b>	<b>SNAP5261BKTR</b>	<b>SNAP5361BKTR</b>
Blue	<b>SNAP5261BL</b>	<b>SNAP5361BL</b>	<b>SNAP5261BLTR</b>	<b>SNAP5361BLTR</b>
Brown	<b>SNAP5261</b>	<b>SNAP5361</b>	<b>SNAP5261TR</b>	<b>SNAP5361TR</b>
Gray	<b>SNAP5261GY</b>	<b>SNAP5361GY</b>	<b>SNAP5261GYTR</b>	<b>SNAP5361GYTR</b>
Ivory	<b>SNAP5261I</b>	<b>SNAP5361I</b>	<b>SNAP5261ITR</b>	<b>SNAP5361ITR</b>
Light Almond	<b>SNAP5261LA</b>	<b>SNAP5361LA</b>	<b>SNAP5261LATR</b>	<b>SNAP5361LATR</b>
Red	<b>SNAP5261R</b>	<b>SNAP5361R</b>	<b>SNAP5261RTR</b>	<b>SNAP5361RTR</b>
White	<b>SNAP5261W</b>	<b>SNAP5361W</b>	<b>SNAP5261WTR</b>	<b>SNAP5361WTR</b>