



# Straight Blade Devices




15 and 20 Ampere, 125 and 250 Volts

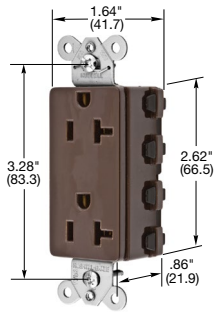


**SNAP2162A**

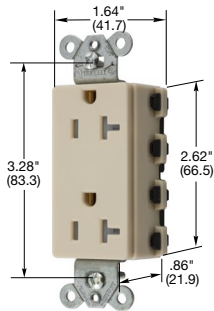


**SNAP2162ITRA**

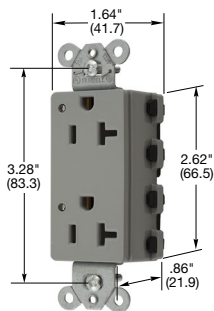

**SNAP2162GYL**

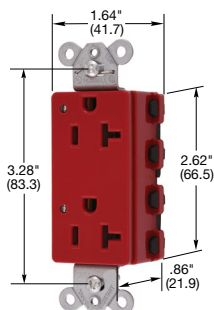

**SNAP2162RLTRA**

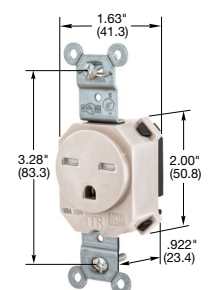

**SNAP5661LATR**

Dimensions in Inches (mm)

## SNAPConnect® Extra Heavy Duty Receptacles



### Style Line® Decorator

Specification grade, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below.

Specification grade, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.

Specification grade, Tamper-Resistant, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.

Specification grade, Tamper-Resistant, Split Circuit, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.

Isolated ground<sup>A</sup>, Spec. grade, TR. Spec. grade, with Power Indicating LED, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.

Isolated ground<sup>A</sup>, Spec. grade, with LED. Specification grade, Tamper-Resistant, with Power Indicating LED, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.

Isolated ground<sup>A</sup>, Spec. grade, TR with LED.

Note: <sup>A</sup>See section N additional information on isolated ground devices.  
See page Tech-10 for Tamper-Resistant and LED Power Indicators descriptions.  
See pages A-47 and A-48 for accessories.  
See section O for wallplates.

## SNAPConnect® 250V Extra Heavy Duty Standard Single Receptacles

Description	Color	15A 250V	20A 250V
Spec. grade, single modular receptacle Tamper-Resistant, smooth nylon face. Requires pigtailed connector on page A-13.	Black	<b>SNAP5661BKTR</b>	<b>SNAP5461BKTR</b>
	Brown	<b>SNAP5661BTR</b>	<b>SNAP5461BTR</b>
	Gray	<b>SNAP5661GYTR</b>	<b>SNAP5461GYTR</b>
	Ivory	<b>SNAP5661ITR</b>	<b>SNAP5461ITR</b>
	Light Almond	<b>SNAP5661LATR</b>	<b>SNAP5461LATR</b>
	White	<b>SNAP5661WTR</b>	<b>SNAP5461WTR</b>

Color	Catalog Number	Catalog Number
Black	<b>SNAP2152BKA</b>	<b>SNAP2162BKA</b>
Brown	<b>SNAP2152A</b>	<b>SNAP2162A</b>
Gray	<b>SNAP2152GYA</b>	<b>SNAP2162GYA</b>
Ivory	<b>SNAP2152IA</b>	<b>SNAP2162IA</b>
Light Almond	<b>SNAP2152LAA</b>	<b>SNAP2162LAA</b>
Red	<b>SNAP2152RA</b>	<b>SNAP2162RA</b>
White	<b>SNAP2152WA</b>	<b>SNAP2162WA</b>

Color	Catalog Number	Catalog Number
Black	<b>SNAP2152BKNA</b>	<b>SNAP2162BKNA</b>
Brown	<b>SNAP2152NA</b>	<b>SNAP2162NA</b>
Gray	<b>SNAP2152GYNA</b>	<b>SNAP2162GYNA</b>
Ivory	<b>SNAP2152INA</b>	<b>SNAP2162INA</b>
Light Almond	<b>SNAP2152LANA</b>	<b>SNAP2162LANA</b>
Red	<b>SNAP2152RNA</b>	<b>SNAP2162RNA</b>
White	<b>SNAP2152WNA</b>	<b>SNAP2162WNA</b>

Color	Catalog Number	Catalog Number
Black	<b>SNAP2152BKTRA</b>	<b>SNAP2162BKTRA</b>
Blue	<b>SNAP2152BLTRA</b>	<b>SNAP2162BLTRA</b>
Brown	<b>SNAP2152TRA</b>	<b>SNAP2162TRA</b>
Gray	<b>SNAP2152GYTRA</b>	<b>SNAP2162GYTRA</b>
Ivory	<b>SNAP2152ITRA</b>	<b>SNAP2162ITRA</b>
Light Almond	<b>SNAP2152LATRA</b>	<b>SNAP2162LATRA</b>
Red	<b>SNAP2152RTRA</b>	<b>SNAP2162RTRA</b>
White	<b>SNAP2152WTRA</b>	<b>SNAP2162WTRA</b>

Color	Catalog Number	Catalog Number
Black	<b>SNAP2152BKSCTRA</b>	<b>SNAP2162BKSCTRA</b>
Blue	<b>SNAP2152BLSCTRA</b>	<b>SNAP2162BLSCTRA</b>
Brown	<b>SNAP2152SCTRA</b>	<b>SNAP2162SCTRA</b>
Gray	<b>SNAP2152GYSCTRA</b>	<b>SNAP2162GYSCTRA</b>
Ivory	<b>SNAP2152ISCTRA</b>	<b>SNAP2162ISCTRA</b>
Light Almond	<b>SNAP2152LASCTRA</b>	<b>SNAP2162LASCTRA</b>
Red	<b>SNAP2152RSCTRA</b>	<b>SNAP2162RSCTRA</b>
White	<b>SNAP2152WSCTRA</b>	<b>SNAP2162WSCTRA</b>

Color	Catalog Number	Catalog Number
Black	<b>SNAP2152BKL</b>	<b>SNAP2162BKL</b>
Blue	<b>SNAP2152BLL</b>	<b>SNAP2162BLL</b>
Brown	<b>SNAP2152L</b>	<b>SNAP2162L</b>
Gray	<b>SNAP2152GYL</b>	<b>SNAP2162GYL</b>
Ivory	<b>SNAP2152IL</b>	<b>SNAP2162IL</b>
Light Almond	<b>SNAP2152LAL</b>	<b>SNAP2162LAL</b>
Red	<b>SNAP2152RL</b>	<b>SNAP2162RL</b>
White	<b>SNAP2152WL</b>	<b>SNAP2162WL</b>

Color	Catalog Number	Catalog Number
Black	<b>SNAP2152BKLTR</b>	<b>SNAP2162BKLTR</b>
Blue	<b>SNAP2152BLLTR</b>	<b>SNAP2162BLLTR</b>
Brown	<b>SNAP2152LTR</b>	<b>SNAP2162LTR</b>
Gray	<b>SNAP2152GYLTR</b>	<b>SNAP2162GYLTR</b>
Ivory	<b>SNAP2152ILTR</b>	<b>SNAP2162ILTR</b>
Light Almond	<b>SNAP2152LALTR</b>	<b>SNAP2162LALTR</b>
Red	<b>SNAP2152RLTR</b>	<b>SNAP2162RLTR</b>
White	<b>SNAP2152WLTR</b>	<b>SNAP2162WLTR</b>

Color	Catalog Number	Catalog Number
Orange	<b>SNAP2152IGLTRA</b>	<b>SNAP2162IGLTRA</b>