

# Straight Blade Devices

15 and 20 Ampere, 125 Volts



15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP



20A 125V  
NEMA 5-20R  
UL CSA  
1 HP



Meets UL  
Standard 943  
Class A GFCI



## SNAPConnect® GFCI LED Hospital Grade ●

Description	Color	Catalog Number	
Hospital Grade SNAPConnect GFCI LED, self-grounding staple, requires connector below, sold separately.	Black	-	<b>SNAPGF83BLK</b>
	Brown	-	<b>SNAPGF83</b>
	Gray	-	<b>SNAPGF83GRY</b>
	Ivory	<b>SNAPGF82I</b>	<b>SNAPGF83I</b>
	Light Almond	<b>SNAPGF82LA</b>	<b>SNAPGF83LA</b>
	Red	<b>SNAPGF82R</b>	<b>SNAPGF83R</b>
	White	<b>SNAPGF82W</b>	<b>SNAPGF83W</b>



SNAPGF83R

## SNAPConnect® GFCI LED Hospital Grade ● Tamper and Weather Resistant

Description	Color	Catalog Number	
Hospital Grade SNAPConnect GFCI TR/WR, self-grounding staple, requires connector below, sold separately.	Black	-	<b>SNAPGFTW83BLK</b>
	Brown	-	<b>SNAPGFTW83</b>
	Gray	<b>SNAPGFTW82GRY</b>	<b>SNAPGFTW83GRY</b>
	Ivory	<b>SNAPGFTW82I</b>	<b>SNAPGFTW83I</b>
	Light Almond	<b>SNAPGFTW82LA</b>	<b>SNAPGFTW83LA</b>
	Red	<b>SNAPGFTW82R</b>	<b>SNAPGFTW83R</b>
	White	<b>SNAPGFTW82W</b>	<b>SNAPGFTW83W</b>



SNAPGFTW83I

Note: GFCI type receptacles should not be used in critical care patient areas or for electrical life support equipment applications because of the possibility of power interruption. All GFCI receptacles are furnished with a matching color thermoplastic wallplate, 20 amp feed-through capability.



15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP




20A 125V  
NEMA 5-20R  
UL CSA  
1 HP



## SNAPConnect® USB Charger Hospital Grade ● Duplex Receptacles

Description	Color	Catalog Number	
Hospital Grade SNAPConnect USB Charger, Tamper-Resistant Style Line® decorator duplex receptacle, 15 or 20 Amp, 125 Volt AC with one type A & one type-C USB port, 3 Amp up to 9 Volt USB output.	Black	<b>SNAP8200UACBK</b>	<b>SNAP8300UACBK</b>
	Brown	<b>SNAP8200UAC</b>	<b>SNAP8300UAC</b>
	Gray	<b>SNAP8200UACGY</b>	<b>SNAP8300UACGY</b>
	Ivory	<b>SNAP8200UACI</b>	<b>SNAP8300UACI</b>
	Light Almond	<b>SNAP8200UACLA</b>	<b>SNAP8300UACLA</b>
	Red	<b>SNAP8200UACR</b>	<b>SNAP8300UACR</b>
	White	<b>SNAP8200UACW</b>	<b>SNAP8300UACW</b>

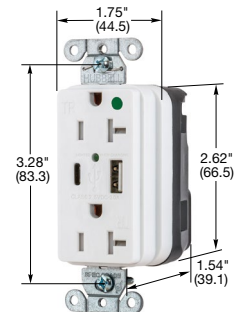

SNAP8300UACW



15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP




20A 125V  
NEMA 5-20R  
UL CSA  
1 HP



## SNAPConnect® Surge Protection Hospital Grade ● Tamper-Resistant Receptacle with Power Indicating LED


Description	Color	Catalog Number	
Hospital Grade SNAPConnect Surge suppression, Tamper-Resistant, smooth face, duplex receptacle.	Blue	<b>SNAP8262S</b>	<b>SNAP8362S</b>
	Gray	<b>SNAP8262GYS</b>	<b>SNAP8362GYS</b>
	Ivory	<b>SNAP8262IS</b>	<b>SNAP8362IS</b>
	Light Almond	<b>SNAP8262LAS</b>	<b>SNAP8362LAS</b>
	Red	<b>SNAP8262RS</b>	<b>SNAP8362RS</b>
	White	<b>SNAP8262WS</b>	<b>SNAP8362WS</b>

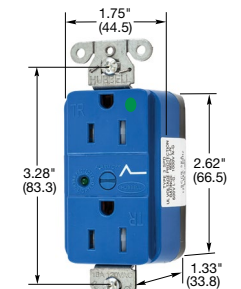

SNAP8262S

## SNAPConnect® Right Angle Pigtailed Connector

Description	Wire Type	General Use	Assembled in USA
Clear right angle terminal with 6 inch leads #12 AWG THHN/THWN-2; Polycarbonate housing material.	Solid	<b>SNAP1RA</b>	<b>SNAP1RNA</b>
	Stranded	<b>SNAP2RA</b>	<b>SNAP2RNA</b>
Clear right angle terminal with 6 inch leads #12 AWG THHN/THWN-2; Polycarbonate housing material with WAGO terminals.	Solid	<b>SNAP1RAM2</b>	<b>SNAP1RNAM2</b>
	Stranded	<b>SNAP2RAM2</b>	<b>SNAP2RNAM2</b>

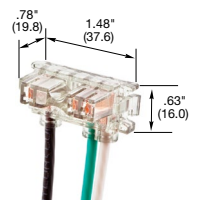

SNAP1RA

Note: See page Tech-10 for Tamper-Resistant, Weather Resistant and LED Power Indicators descriptions.

Dimensions in Inches (mm)