




15 and 20 Ampere, 125 Volts

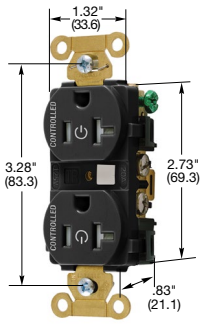


HBL5362C2BLKTR

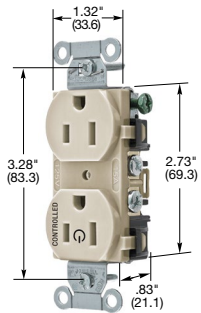


BR15C1LA

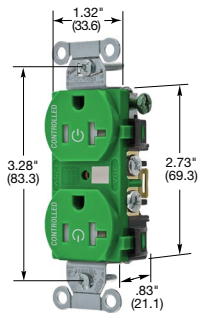

BR20C2GNTR

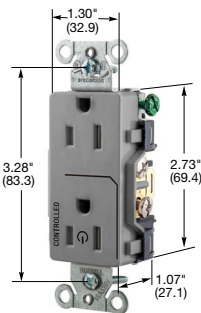

DR15C1GRY

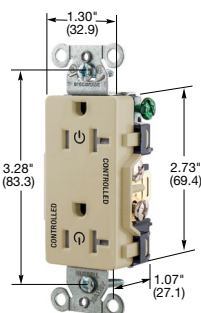

DR20C2ITR

Dimensions in Inches (mm)

Industrial Grade, Permanently Marked Tamper-Resistant Receptacles



Duplex	Color	One Controlled Face Split Circuit Hot Tab		Two Controlled Faces	
		15 Amp	20 Amp	15 Amp	20 Amp
Smooth nylon face, duplex, permanently marked for use with automatic outlet control systems, back and side wired.	Black	HBL5262C1BLKTR	HBL5362C1BLKTR	HBL5262C2BLKTR	HBL5362C2BLKTR
	Blue	HBL5262C1BLTR	HBL5362C1BLTR	HBL5262C2BLTR	HBL5362C2BLTR
	Brown	HBL5262C1TR	HBL5362C1TR	HBL5262C2TR	HBL5362C2TR
	Gray	HBL5262C1GRYTR	HBL5362C1GRYTR	HBL5262C2GRYTR	HBL5362C2GRYTR
	Ivory	HBL5262C1ITR	HBL5362C1ITR	HBL5262C2ITR	HBL5362C2ITR
	Lt. Almond	HBL5262C1LATR	HBL5362C1LATR	HBL5262C2LATR	HBL5362C2LATR
	Red	HBL5262C1RTR	HBL5362C1RTR	HBL5262C2RTR	HBL5362C2RTR
	White	HBL5262C1WHITR	HBL5362C1WHITR	HBL5262C2WHITR	HBL5362C2WHITR

Permanently Marked Receptacles

Duplex	Color	One Controlled Face Split Circuit Hot Tab		Two Controlled Faces		
		15 Amp	20 Amp	15 Amp	20 Amp	
Smooth polycarbonate face, duplex, permanently marked for use with automatic outlet control systems, back and side wired.	Black	BR15C1BLK	BR20C1BLK	BR15C2BLK	BR20C2BLK	
	Blue	BR15C1BL	BR20C1BL	BR15C2BL	BR20C2BL	
	Brown	BR15C1	BR20C1	BR15C2	BR20C2	
	Gray	BR15C1GRY	BR20C1GRY	BR15C2GRY	BR20C2GRY	
	Green	BR15C1GN	BR20C1GN	BR15C2GN	BR20C2GN	
	Ivory	BR15C1I	BR20C1I	BR15C2I	BR20C2I	
	Lt. Almond	BR15C1LA	BR20C1LA	BR15C2LA	BR20C2LA	
	Red	BR15C1R	BR20C1R	BR15C2R	BR20C2R	
	White	BR15C1WHI	BR20C1WHI	BR15C2WHI	BR20C2WHI	
	Smooth polycarbonate face, Tamper-Resistant, duplex, permanently marked for use with automatic outlet control systems, back and side wired.	Black	BR15C1BLKTR	BR20C1BLKTR	BR15C2BLKTR	BR20C2BLKTR
		Blue	BR15C1BLTR	BR20C1BLTR	BR15C2BLTR	BR20C2BLTR
Brown		BR15C1TR	BR20C1TR	BR15C2TR	BR20C2TR	
Gray		BR15C1GRYTR	BR20C1GRYTR	BR15C2GRYTR	BR20C2GRYTR	
Green		BR15C1GNTR	BR20C1GNTR	BR15C2GNTR	BR20C2GNTR	
Ivory		BR15C1ITR	BR20C1ITR	BR15C2ITR	BR20C2ITR	
Lt. Almond		BR15C1LATR	BR20C1LATR	BR15C2LATR	BR20C2LATR	
Red		BR15C1RTR	BR20C1RTR	BR15C2RTR	BR20C2RTR	
White	BR15C1WHITR	BR20C1WHITR	BR15C2WHITR	BR20C2WHITR		



Style Line® Decorator

Smooth polycarbonate face, decorator duplex, permanently marked for use with automatic outlet control systems, back and side wired.	Black	DR15C1BLK	DR20C1BLK	DR15C2BLK	DR20C2BLK	
	Blue	DR15C1BL	DR20C1BL	DR15C2BL	DR20C2BL	
	Brown	DR15C1	DR20C1	DR15C2	DR20C2	
	Gray	DR15C1GRY	DR20C1GRY	DR15C2GRY	DR20C2GRY	
	Green	DR15C1GN	DR20C1GN	DR15C2GN	DR20C2GN	
	Ivory	DR15C1I	DR20C1I	DR15C2I	DR20C2I	
	Lt. Almond	DR15C1LA	DR20C1LA	DR15C2LA	DR20C2LA	
	Red	DR15C1R	DR20C1R	DR15C2R	DR20C2R	
	White	DR15C1WHI	DR20C1WHI	DR15C2WHI	DR20C2WHI	
	Smooth polycarbonate face, Tamper-Resistant, decorator duplex, permanently marked for use with automatic outlet control systems, back and side wired.	Black	DR15C1BLKTR	DR20C1BLKTR	DR15C2BLKTR	DR20C2BLKTR
		Blue	DR15C1BLTR	DR20C1BLTR	DR15C2BLTR	DR20C2BLTR
Brown		DR15C1TR	DR20C1TR	DR15C2TR	DR20C2TR	
Gray		DR15C1GRYTR	DR20C1GRYTR	DR15C2GRYTR	DR20C2GRYTR	
Green		DR15C1GNTR	DR20C1GNTR	DR15C2GNTR	DR20C2GNTR	
Ivory		DR15C1ITR	DR20C1ITR	DR15C2ITR	DR20C2ITR	
Lt. Almond		DR15C1LATR	DR20C1LATR	DR15C2LATR	DR20C2LATR	
Red		DR15C1RTR	DR20C1RTR	DR15C2RTR	DR20C2RTR	
White	DR15C1WHITR	DR20C1WHITR	DR15C2WHITR	DR20C2WHITR		



Permanent Controlled Receptacle Label

Description	Catalog Number
For use in retrofit applications where indication of a controlled receptacle is required. This label is UL approved for marking and labeling. 60 labels of each per pack.	CL60