

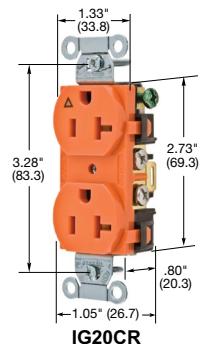
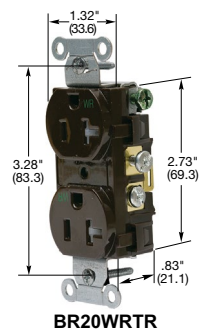
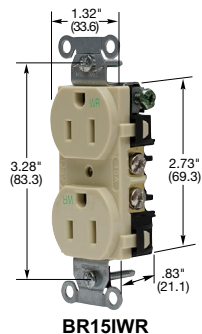


15 and 20 Ampere, 125 Volts

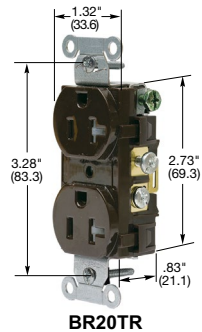

Dimensions in Inches (mm)

Commercial Specification Grade Receptacles

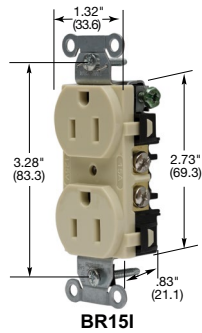

Duplex

Smooth polycarbonate face, duplex, back and side wired.

Color

Catalog Number

<p>Tamper-Resistant, smooth polycarbonate face, duplex, back and side wired.</p>	Black	BR15BLK	BR20BLK
	Blue	BR15BL	BR20BL
	Brown	BR15	BR20
	Gray	BR15GRY	BR20GRY
	Green	BR15GN	BR20GN
	Ivory	BR15I	BR20I
	Light Almond	BR15LA	BR20LA
	Red	BR15R	BR20R
	White	BR15WHI	BR20WHI
	<p>Weather Resistant, smooth polycarbonate face, duplex, back and side wired.</p>	Black	BR15BLKTR
Blue		BR15BLTR	BR20BLTR
Brown		BR15TR	BR20TR
Gray		BR15GRYTR	BR20GRYTR
Green		BR15GNTR	BR20GNTR
Ivory		BR15ITR	BR20ITR
Light Almond		BR15LATR	BR20LATR
Red		BR15RTR	BR20RTR
White		BR15WHITR	BR20WHITR
<p>Weather Resistant, smooth polycarbonate face, duplex, back and side wired.</p>		Black	BR15BLKW
	Brown	BR15W	BR20W
	Gray	BR15GRYW	BR20GRYW
	Ivory	BR15IW	BR20IW
	Light Almond	BR15LAW	BR20LAW
	White	BR15WHIW	BR20WHIW
<p>Weather and Tamper-Resistant, smooth polycarbonate face, duplex, back and side wired.</p>	Black	BR15BLKWTR	BR20BLKWTR
	Brown	BR15WRTR	BR20WRTR
	Gray	BR15GRYWRTR	BR20GRYWRTR
	Ivory	BR15IWRTR	BR20IWRTR
	Light Almond	BR15LAWRTR	BR20LAWRTR
	White	BR15WHIWRTR	BR20WHIWRTR
<p>Isolated ground^A, smooth nylon face, duplex, side wired only.</p>	Gray	IG15CRGRY	IG20CRGRY
	Ivory	IG15CRI	IG20CRI
	Light Almond	IG15CRLA	IG20CRLA
	Orange	IG15CR	IG20CR
	White	IG15CRWHI	IG20CRWHI
<p>Isolated ground^A, Style Line[®] decorator*, smooth nylon face, duplex, back and side wired.</p>	Gray	IG15DRGRY	IG20DRGRY
	Ivory	IG15DRI	IG20DRI
	Light Almond	IG15DRLA	IG20DRLA
	Orange	IG15DR	IG20DR
	White	-	IG20DRWHI

Note: ^ASee section N for additional information on isolated ground devices.

See page A-47 for accessories.

See page Tech-10 for Tamper and Weather Resistant descriptions.

See section O for wallplates.