


USB Charger Receptacles and Outlets



Weather Resistant Receptacle Features

- Meets Section 406.9 of NEC®
- 5 Amp, 5 Volt USB output
- Type A&C USB ports
- Power indicating green LED light

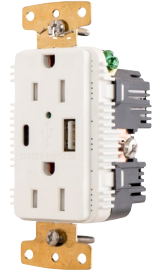


Weather Resistant USB Charger Duplex Receptacles

Description	Color	15A 125V	20A 125V
Type A&C USB Charger Receptacle, One Type A and one Type-C port configurations, high power 5 Amp, 5 Volt USB output, Tamper-Resistant USB ports rated 10,000 cycles; Commercial Grade	Black	USB15AC5BKWR	USB20AC5BKWR
	Brown	USB15AC5WR	USB20AC5WR
	Gray	USB15AC5GYWR	USB20AC5GYWR
	Ivory	USB15AC5IWR	USB20AC5IWR
	Light Almond	USB15AC5LAWR	USB20AC5LAWR
	White	USB15AC5WWR	USB20AC5WWR

Note: Outdoor circuits should be GFCI protected per national and local electric codes.

Commercial and Hospital Grade ● USB-C Power Delivery Charger Tamper-Resistant Duplex Receptacles

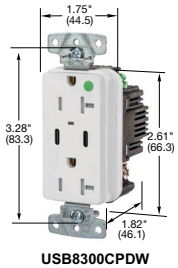


USB8300CPDW

Two Type-C port configurations, one USB-C Power Delivery port with up to 55 Watt output and one USB Type-C convenience port with up to 1.5 Amp, 5 Volt USB output, Tamper Resistant duplex receptacle, USB ports rated 10,000 cycles

Description	Color	Commercial		Hospital Grade	
		15A 125V	20A 125V	15A 125V	20A 125V
One Type-A and one Type-C port configurations, one USB-C Power Delivery port with up to 55 Watt output and one USB-A convenience port with up to 1.5 Amp, 5 Volt USB output, Tamper Resistant duplex receptacles, USB ports rated 10,000 cycles.	Black	USB15ACPDBK	USB20ACPDBK	USB8200ACPDBK	USB8300CPDBK
	Brown	USB15ACPD	USB20ACPD	USB8200ACPD	USB8300CPD
	Gray	USB15ACPDGY	USB20ACPDGY	USB8200ACPDGY	USB8300CPDGY
	Ivory	USB15ACPD I	USB20ACPD I	USB8200ACPD I	USB8300CPD I
	Lt. Almond	USB15ACPD LA	USB20ACPD LA	USB8200ACPD LA	USB8300CPD LA
	Red	-	-	USB8200ACPDR	USB8300CPDR
	White	USB15ACPDW	USB20ACPDW	USB8200ACPDW	USB8300CPDW

Note: See page Tech-10 for Tamper-Resistant description.

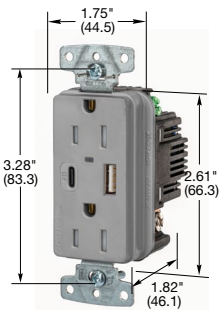

USB15ACPDGY

4 Port USB Charger Outlets




Description	Color	Catalog Number
USB Charger Outlets, 4 USB ports, two Type A & two Type-C ports, 5 Amp up to 9 Volt DC, Style Line® decorator.	Black	USB4ACBK
	Brown	USB4AC
	Gray	USB4ACGY
	Ivory	USB4ACI
	Light Almond	USB4ACLA
	White	USB4ACW

Switch Combo Outlets




Description	Color	Catalog Number
Switch Combo Outlet, two USB type 2.0 ports, 2.1 Amp, 5 Volt DC, Style Line® decorator.	Black	USB102BK
	Brown	USB102
	Gray	USB102GY
	Ivory	USB102I
	Light Almond	USB102LA
	White	USB102W

NEC® is a registered trademark of the National Fire Protection Association (NFPA).

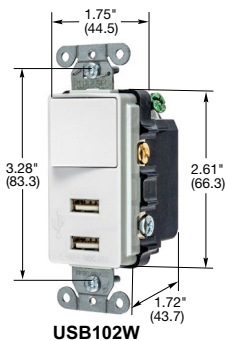

USB102W

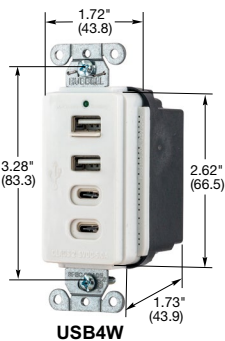

USB4W

Dimensions in Inches (mm)