



HBL8215C



HBL8215CTST




HBL8215CAT



HBL8115V



HBL8219C

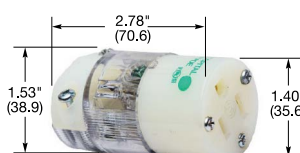

HBL8219CT



HBL8119V



HBL8666V

Dimensions in Inches (mm)

IP20
SUITABILITY



15A 125V
NEMA 5-15P
UL CSA



20A 125V
NEMA 5-20P
UL CSA

Hospital Grade Plugs

Insulgrip®

Description	Cord Diameter	Catalog Number	
Black and white nylon.	.230"-.720" (5.8-18.3)	HBL8215C	HBL8315C
Black and white, spring termination	.230"-.720" (5.8-18.3)	HBL8215CST	HBL8315CST
Transparent housing.	.230"-.720" (5.8-18.3)	HBL8215CT	HBL8315CT
Transparent housing, spring termination	.230"-.720" (5.8-18.3)	HBL8215CTST	HBL8315CTST
8 position angle plug, transparent housing.	.250"-.655" (6.4-16.6)	HBL8215CAT*	HBL8315CAT*

Valise®

Description	Cord Diameter	Catalog Number	
White nylon.	.300"-.660" (7.6-16.8)	HBL8115V	HBL8364V
Insulation displacement, white nylon.	.300"-.360" (7.6-9.1)	HBL8013V*	—

IP20
SUITABILITY



15A 125V
NEMA 5-15R
UL CSA
0.5 HP



20A 125V
NEMA 5-20R
UL CSA
1 HP

Hospital Grade Connector Bodies

Insulgrip®

Description	Cord Diameter	Catalog Number	
Black and white nylon.	.230"-.720" (5.8-18.3)	HBL8219C	HBL8319C
Black and white, spring termination	.230"-.720" (5.8-18.3)	HBL8219CST	HBL8319CST
Transparent housing.	.230"-.720" (5.8-18.3)	HBL8219CT	HBL8319CT
Transparent housing, spring termination	.230"-.720" (5.8-18.3)	HBL8219CTST	HBL8319CTST

Valise®

Description	Cord Diameter	Catalog Number	
White nylon.	.300"-.660" (7.6-16.8)	HBL8119V	—

Note: *Not Fed. Spec. Listed.

See page A-48 for accessories.

IP20
SUITABILITY



15A 250V
NEMA 6-15P
UL CSA
1.5 HP



20A 250V
NEMA 6-20P
UL CSA
2 HP

Hospital Grade Plugs

Valise®

Description	Cord Diameter	Catalog Number	
Valise plug, white nylon.	.300"-.660" (7.6-16.8)	HBL8666V	HBL8464V

Note: HP ratings listed above are based on 208 to 240V AC only.



15A 250V
NEMA 6-15R
UL CSA
1.5 HP



20A 250V
NEMA 6-20R
UL CSA
2 HP

Hospital Grade Connector Bodies

Valise®

Description	Cord Diameter	Catalog Number	
White nylon.	.300"-.660" (7.6-16.8)	—	HBL8469V