




**15A 250V
NEMA 6-15P
UL CSA
1.5 HP**



**20A 250V
NEMA 6-20P
UL CSA
2 HP**

Plugs


Description	Cord Diameter	Catalog Number	
Insulgrip® Plug, black and white nylon.	.230"-.720" (5.8-18.3)	HBL5666C	HBL5466C
Insulgrip plug, black and white, spring termination	.230"-.720" (5.8-18.3)	HBL5666CST	HBL5466CST
Insulgrip® Plug, corrosion resistant, yellow nylon.	.230"-.720" (5.8-18.3)	HBL56CM66C	HBL54CM66C
Insulgrip plug, corrosion resistant, spring termination, yellow	.230"-.720" (5.8-18.3)	HBL56CM66CST	HBL54CM66CST
8-Position Insulgrip® Angle Plug, black and white nylon.	.325"-.655" (8.3-16.6)	HBL5666CA	HBL5466CA
Valise® Plug, yellow nylon.	.220"-.660" (5.6-16.8)	HBL5666VY	HBL5464VY

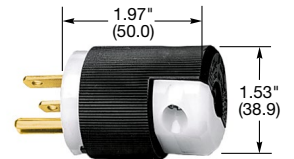

HBL5666C



HBL5666CST

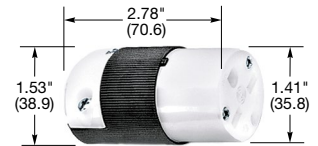

HBL5669C

Connector Bodies

Description	Cord Diameter	Catalog Number	
Insulgrip® Connector Body, black and white nylon, multiple drive screws.	.230"-.720" (5.8-18.3)	HBL5669C	HBL5469C
Insulgrip Connector Body, Black and White, Spring Termination	.230"-.720" (5.8-18.3)	HBL5669CST	HBL5469CST
Valise® Connector Body, yellow nylon.	.220"-.660" (5.6-16.8)	HBL5669VY	HBL5469VY


Note: See page A-48 for accessories.



**15A 250V
NEMA 6-15R
UL CSA**



**20A 250V
NEMA 6-20R
UL Listed**

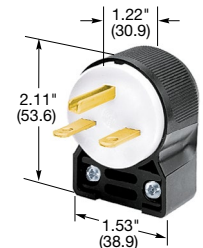

HBL5669C

Insulgrip® Flanged Inlets

Description	Catalog Number	
Nylon casing, back wired.	HBL5678C	HBL5478C


Note: Flanged inlets are not HP rated.
See page A-48 for accessories.




**15A 250V
NEMA 6-15P
UL CSA**



**20A 250V
NEMA 6-20P
UL CSA**

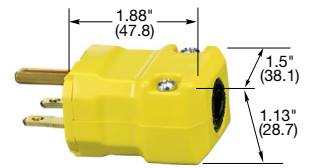

HBL5666VY

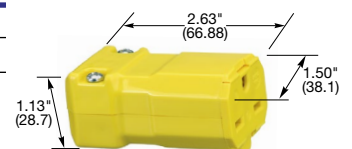

HBL5669VY

Flanged Receptacles

Description	Catalog Number	
Nylon casing, multiple drive screws.	HBL5679C	HBL5479C
Stainless steel flange, brown phenolic housing (mounting screws packaged separately).	HBL5656	-


Note: Connector bodies are not HP rated.
See pages A-47 and A-48 for accessories.



**15A 250V
NEMA 6-15R
UL CSA**



**20A 250V
NEMA 6-20R
UL Listed**

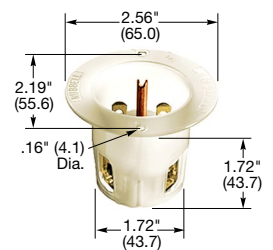

HBL5678C

For quick visual identification of circuits or configurations.

Colored Cord Clamps*

Description	Color	Catalog Number
For use with 15A and 20A, 2 pole/3 wire, insulgrip plugs and connectors with cord diameter range of .230"-.720" (5.8-18.3) only.	Blue	HBLCORDCLAMPBL
	Green	HBLCORDCLAMPGN
	Orange	HBLCORDCLAMPOR
	Purple	HBLCORDCLAMPPP
	Red	HBLCORDCLAMPR
	Yellow	HBLCORDCLAMPY

Note: *Clamp only. Contains no screws. Order in increments of 10. Not UL Listed or CSA Certified.



Dimensions in Inches (mm)