

Straight Blade Devices



20A, 125/250V, 3 Pole, 3 Wire Non-Grounding, Receptacles and Plugs

IP20
SUITABILITY




20A 125V/250V
NEMA 10-20R
UL Listed
2(1) HP



20A 125V/250V
NEMA 10-20P
UL Listed
2(1) HP

Description	Cord Diameter	Catalog Number
Receptacle, black phenolic.	-	HBL6810
Plug, Insulgrip®, nylon.	.385"-.780" (9.8-19.8)	HBL9977C

Note: Horsepower ratings listed above are AC only.
Horsepower ratings not in parentheses are phase to phase (208 to 240V AC).
Those in parentheses are phase to neutral (120V AC).
See pages A-47 and A-48 for accessories.

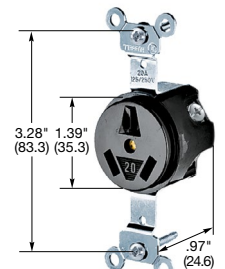

HBL6810



20A, 125/250V, 3 Pole, 4 Wire Grounding, Receptacles and Plugs

IP20
SUITABILITY




20A 125V/250V
NEMA 14-20R
UL CSA
2(1) HP




20A 125V/250V
NEMA 14-20P
UL CSA
2(1) HP

Description	Cord Diameter	Catalog Number
Receptacle, black nylon body, back and side wired.	-	HBL8410
Plug, nylon, angle 4-position.	.390"-.775" (9.9-19.7)	HBL8411C

See pages A-47 and A-48 for accessories.

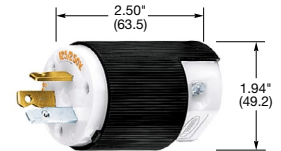

HBL9977C

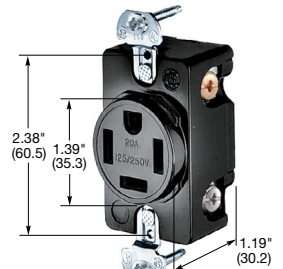

HBL8410



20A, 3Ø 250V AC, 3 Pole, 4 Wire Grounding, Receptacles and Plugs

IP20
SUITABILITY




20A 3Ø 250V AC
NEMA 15-20R
UL CSA
3 HP



20A 3Ø 250V AC
NEMA 15-20P
UL CSA
3 HP

Description	Cord Diameter	Catalog Number
Receptacle, black nylon body, back and side wired.	-	HBL8420
Plug, nylon, angle 4-position.	.390"-.775" (9.9-19.7)	HBL8421C

Note: Horsepower ratings listed above are AC only.
Horsepower ratings not in parentheses are phase to phase (208 to 240V AC).
Horsepower ratings in parentheses are phase to neutral (120V AC).
See pages A-47 and A-48 for accessories.

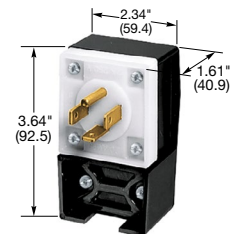

HBL8411C



20A, 3ØY 120/208V AC, 4 Pole, 4 Wire Non-Grounding, Receptacles and Plugs

IP20
SUITABILITY




20A 3ØY 120/208V AC
NEMA 18-20R
UL Listed
2 HP




20A 3ØY 120/208V AC
NEMA 18-20P
UL Listed
2 HP

Description	Cord Diameter	Catalog Number
Receptacle, black nylon body.	-	HBL7250
Plug, nylon, angle, 4-position.	.390"-.775" (9.9-19.7)	HBL7251C

Note: Horsepower ratings are phase to phase (208 to 240V AC).
Weatherproof boots for plugs not available.
See pages A-47 and A-48 for accessories.

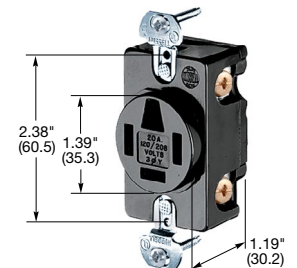

HBL7250

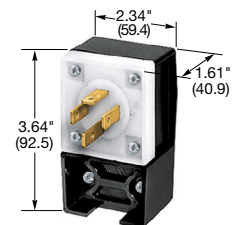

HBL7251C

Dimensions in Inches (mm)