

## 30A, 125/250V, 3 Pole, 4 Wire Grounding, Receptacles and Plugs

**IP20**  
SUITABILITY




**30A 125/250V  
NEMA 14-30R  
2(2) HP**



**30A 125/250V  
NEMA 14-30P  
2(2) HP**

Description	Cord Diameter	Catalog Number
Receptacle, black RTP.	-	<b>HBL9430A</b>
Plug, nylon.	.625"-1.310" (15.9-33.3)	- <b>HBL9431C</b>
Plug, nylon, angle, 4-position.	.625"-1.310" (15.9-33.3)	- <b>HBL9432C</b>

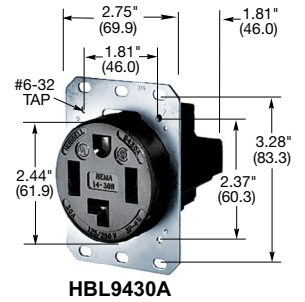

## 30A, 3Ø 250V AC, 3 Pole, 4 Wire Grounding, Receptacles and Plugs

**IP20**  
SUITABILITY





**30A 3Ø 250V AC  
NEMA 15-30R  
3 HP**



**30A 3Ø 250V AC  
NEMA 15-30P  
3 HP**

Description	Cord Diameter	Catalog Number
Receptacle, black RTP.	-	<b>HBL8430A</b>
Plug, nylon.	.625"-1.310" (15.9-33.3)	- <b>HBL8431C</b>
Plug, nylon, angle, 4-position.	.625"-1.310" (15.9-33.3)	- <b>HBL8432C</b>
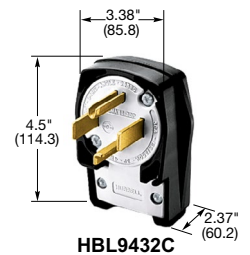
## 30A, 3ØY 120/208V AC, 4 Pole, 4 Wire Non-Grounding, Receptacles and Plugs

**IP20**  
SUITABILITY




**30A 3ØY  
120/208V AC  
NEMA 18-30R  
UL Listed  
3 HP**



**30A 3ØY  
120/208V AC  
NEMA 18-30P  
UL Listed  
3 HP**

Description	Cord Diameter	Catalog Number
Receptacle, black RTP.	-	<b>HBL8330A</b>
Plug, nylon.	.625"-1.310" (15.9-33.3)	- <b>HBL8331C</b>

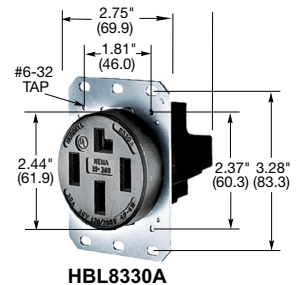

Note: RTP is an abbreviation for reinforced thermoplastic polyester.  
See pages A-49 and A-50 for accessories.

Dimensions in Inches (mm)