

50A, 125/250V, 3 Pole, 4 Wire Grounding, Receptacles and Plugs

IP20
SUITABILITY




**50A 125/250V
NEMA 14-50R**
UL CSA
3(2) HP



**50A 125/250V
NEMA 14-50P**
UL CSA
3(2) HP

Description	Cord Diameter	Catalog Number
Receptacle, black RTP.	-	HBL9450A
Plug, nylon.	.625"-1.310" (15.9-33.3)	HBL9451C
Plug, nylon, angle, 4-position.	.625"-1.310" (15.9-33.3)	HBL9452C

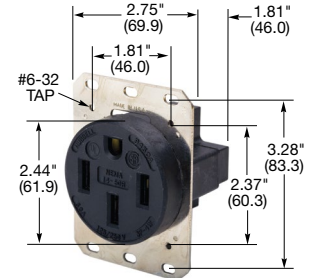

HBL9450A

50A, 3Ø 250V AC, 3 Pole, 4 Wire Grounding, Receptacles and Plugs

IP20
SUITABILITY



**50A 3Ø 250V AC
NEMA 15-50R**
UL CSA
7.5 HP




**50A 3Ø 250V AC
NEMA 15-50P**
UL CSA
7.5 HP

Description	Cord Diameter	Catalog Number
Receptacle, black RTP.	-	HBL8450A
Plug, nylon.	.625"-1.310" (15.9-33.3)	HBL8451C
Plug, nylon, angle, 4-position.	.625"-1.310" (15.9-33.3)	HBL8452C



HBL9451C



50A, 3ØY 120/208V AC, 4 Pole, 4 Wire Non-Grounding, Receptacles and Plugs

IP20
SUITABILITY




**50A 3ØY
120/208V AC
NEMA 18-50R**
UL Listed
7.5 HP




**50A 3ØY
120/208V AC
NEMA 18-50P**
UL Listed
7.5 HP

Description	Cord Diameter	Catalog Number
Receptacle, black RTP.	-	HBL8350A
Plug, nylon, angle, 4-position.	.625"-1.310" (15.9-33.3)	HBL8352C

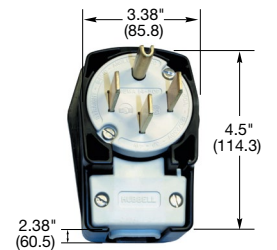

HBL9452C

Note: RTP is an abbreviation for reinforced thermoplastic polyester.
See page A-50 for accessories.

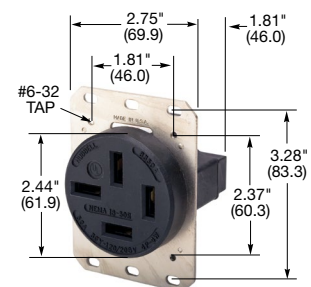

HBL8350A

Dimensions in Inches (mm)