

Features and Benefits


USB Charger Receptacles

More Ways to Charge Faster with Hubbell's line of USB Chargers, available in Type-C, Combination Type A&C or the legacy Type A, all with a USB high power output of 5 Amp 5 Volt DC. Hubbell's USB Charger Duplex Receptacle provides both USB and electrical power in a standard single gang opening. Designed to provide maximum charging for portable electronics, the USB ports are capable of charging two tablets simultaneously.

Hubbell's new weather resistant USB charger receptacle offers a safe and reliable solution, conveniently expanding way to charge portable electronics. Now, being outdoors no longer means worrying about finding a charging source. Weather resistant receptacles comply with Section 406.9 of the National Electrical Code when used with covers.

Common Features

- LED ON to indicate USB and line voltage power available
- USB stainless steel ports rated for minimum 10,000 insertions and removals
- Complies with battery charging specification BC1.2
- Designed for commercial, industrial and home use
- Compatible with USB 1.1/2.0/3.0 devices, including Apple® products

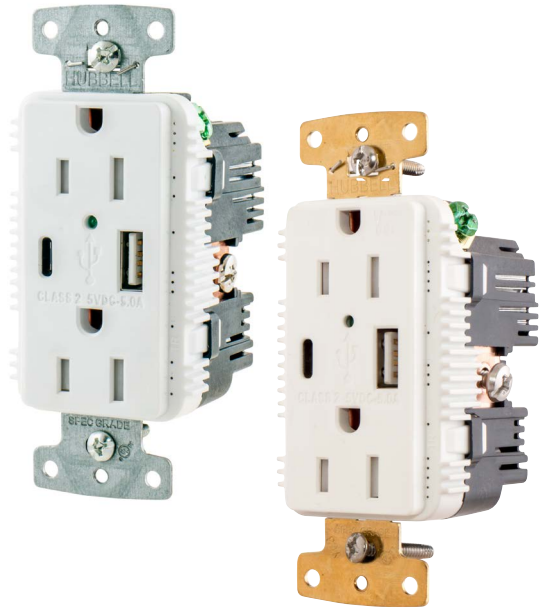

USB Chargers

- Two Type-C port configurations
- One Type A and one Type-C port
- Two Type A port configurations
- High power 5 Amp, 5 Volt DC USB output
- Tamper-Resistant decorator duplex receptacle



Weather Resistant Type A&C USB Charger

- One Type A and one Type-C port configurations
- Meets Section 406.9 of NEC® with cover
- 5 Amp, 5 Volt USB output
- Power indicating green LED light

Weather Resistant USB Charger Duplex Receptacles



Description	Color	15A 125V AC	20A 125V
Type A&C USB Charger receptacle, one Type A and one Type-C port configurations, high power 5 Amp, 5 Volt USB output, Tamper-Resistant USB ports rated 10,000 cycles; Commercial Grade.	Ivory Light Almond White	USB15AC5IWR USB15AC5LAWR USB15AC5WWR	USB20AC5IWR USB20AC5LAWR USB20AC5WWR

Note: Outdoor circuits should be GFCI protected per national and local electric codes. Also available in black, brown and gray. See page Tech-10 for Weather and Tamper-Resistant descriptions.



USB15AC5WWR

Standard USB Charger Tamper-Resistant Duplex Receptacles



Description	Color	15A 125V AC
Type-C USB Charger Receptacle, two Type-C port configurations, high power 5 Amp, 5 Volt USB output.	Ivory Light Almond White	USB15C5I USB15C5LA USB15C5W
Type A&C USB Charger Receptacle, one Type A and one Type-C port configuration, high power 5 Amp, 5 Volt USB output.	Ivory Light Almond White	USB15AC5I USB15AC5LA USB15AC5W
Type A USB Charger Receptacle, two Type A port configurations, high power 5 Amp, 5 Volt USB output.	Ivory Light Almond White	USB15A5I USB15A5LA USB15A5W

Note: Also available in black, brown and gray.



USB15AC5W

Apple® is a registered trademark of Apple Inc.
NEC® is a registered trademark of the The National Electrical Code.