



## 20 Amp, 125, 250 Volts and 277 Volts AC 2 Pole, 3 Wire, Grounding

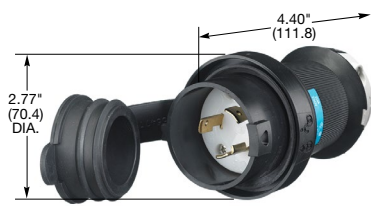

HBL2321SW



HBL2321S

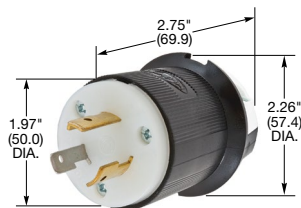


HBL2311



HBL2311ST



HBL2325SW

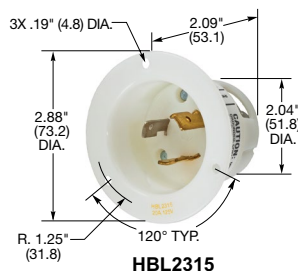

HBL2315

### Plugs

#### Watertight Safety-Shroud®

Description	Cord Dia.	Catalog Number	IP66 SUITABILITY	UL Type 4x, 12
Black Valox® housing, white Valox® clamps.	.360"-.930" (9-24)	<b>HBL2311SW</b>	<b>HBL2321SW</b>	<b>HBL2331SW</b>

#### Safety-Shroud®

Description	Cord Dia.	Catalog Number	IP20 SUITABILITY
Black and white nylon body, white Valox® shroud. Can be used with the Insulgrip Connector Bodies.	.360"-.930" (9-24)	<b>HBL2311S</b>	<b>HBL2321S</b> <b>HBL2331S</b>

#### Insulgrip®

Description	Cord Dia.	Catalog Number	IP20 SUITABILITY
Black and white nylon.	.360"-.930" (9-24)	<b>HBL2311</b>	<b>HBL2321</b> <b>HBL2331</b>
Black and white nylon, spring termination	.360"-.930" (9-24)	<b>HBL2311ST</b>	<b>HBL2321ST</b> <b>HBL2331ST</b>
Corrosion resistant, yellow nylon.	.360"-.930" (9-24)	<b>HBL23CM11</b>	<b>HBL23CM21</b> -
All black nylon.	.360"-.930" (9-24)	<b>HBL2311BK</b>	<b>HBL2321BK</b> -
All black nylon, spring termination	.360"-.930" (9-24)	<b>HBL2311STBK</b>	<b>HBL2321STBK</b> -
Cord clamps with removable inserts. All black nylon.	.360"-.930" (9-24)	<b>HBL2311EBK</b>	<b>HBL2321EBK</b> -

Note: See page B-52 for accessories.

#### Valise®

Description	Cord Dia.	Catalog Number	IP20 SUITABILITY	UL	CSA
Yellow nylon.	.325"-.720" (8.26-18.3)	<b>HBL2311VY</b>	<b>HBL2321VY</b>	<b>HBL2331VY</b>	
Corrosion resistant, yellow nylon.	.325"-.720" (8.26-18.3)	<b>HBL23CM11V</b>	-	-	
Black nylon.	.325"-.720" (8.26-18.3)	<b>HBL2311VBK</b>	<b>HBL2321VBK</b>	<b>HBL2331VBK</b>	

Note: See page B-53 for accessories.

### Flanged Inlets

#### Watertight Safety-Shroud®

Description	Catalog Number	IP66 SUITABILITY	UL Type 4x, 12
Gray Valox® housing and flange.	<b>HBL2315SW</b>	<b>HBL2325SW</b>	<b>HBL2335SW</b>
Gray Valox® housing and flange, reverse service (Not shown).	-	<b>HBL2325SWR</b>	-

Note: See page B-56 for accessories.

#### Insulgrip®

Description	Catalog Number	IP20 SUITABILITY
Nylon casing, back wired.	<b>HBL2315</b>	<b>HBL2325</b> <b>HBL2335</b>
Nylon casing, spring termination	<b>HBL2315ST</b>	<b>HBL2325ST</b> <b>HBL2335ST</b>

Note: See page B-52 for accessories.

See pages B-69 and B-70 for technical information on Twist-Lock and Watertight Safety-Shroud devices.  
See page B-74 for technical information on Valise® plugs and connectors.



HBL2315ST

<b>20A 125V NEMA L5-20P 1 HP</b>	<b>20A 250V NEMA L6-20P 2 HP</b>	<b>20A 277V AC NEMA L7-20P 2 HP</b>



**HBLMITL** - For use with Watertight Safety-Shroud receptacles, see page B-41.

Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.