



20 Amp, 347, 480, 600 and 125/250 Volts AC
2 Pole, 3 Wire, Grounding and 3 Pole, 3 Wire, Non-Grounding

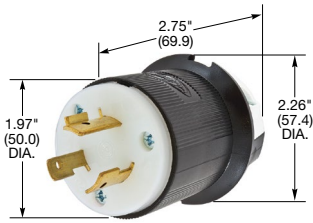

HBL2341




HBL2341ST

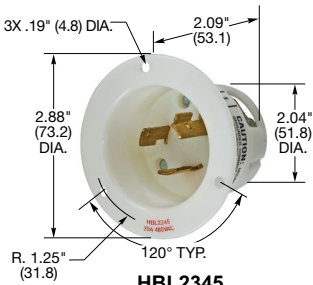


HBL2345



HBL2343

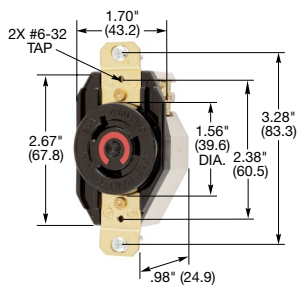

HBL2340

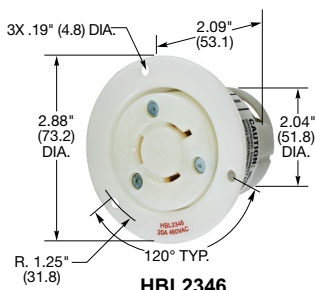

HBL2346

Dimensions in Inches (mm)

IP20
SUITABILITY



Plugs

Description	Cord Dia.	Catalog Number			
Black and white nylon.	.360\"-".930\" (9-24)	HBL3721	HBL2341	HBL2351	-
Black and white nylon, spring termination		-	HBL2341ST	-	-
Black and white nylon (Not shown).	.300\"-".1,050\" (7.6-26.7)	-	-	-	HBL2361

Note: See page B-52 for accessories.

Flanged Inlets

Description	Catalog Number			
Nylon casing, back wired.	HBL3725	HBL2345	HBL2355	HBL2365
Nylon casing, spring termination.	-	HBL2345ST	-	-

Note: See page B-52 for accessories.

IP20
SUITABILITY



Connector Bodies

Description	Cord Dia.	Catalog Number			
Black and white nylon.	.360\"-".930\" (9-24)	HBL3723	HBL2343	HBL2353	-
Black and white nylon, spring termination	.360\"-".930\" (9-24)	-	HBL2343ST	-	-
Black and white nylon (Not shown).	.300\"-".1,050\" (7.6-26.7)	-	-	-	HBL2363

Note: See page B-52 for accessories.

Single Flush Receptacles

Description	Catalog Number			
Black nylon face, back and side wired.	HBL3720	HBL2340	HBL2350	HBL2360
Watertight Safety-Shroud®, gray Valox® housing and flange, back and side wired, (Not shown).	-	HBL2340SW	-	-
Isolated ground, orange nylon face, back and side wired.	-	IG2340	-	-

Note: See page B-52 for accessories.

Flanged Receptacles

Description	Catalog Number			
Nylon casing, back wired.	HBL3726	HBL2346	HBL2356	HBL2366

Note: See page B-52 for accessories.

See page B-69 for technical information.

See page B-39 for switched enclosure.

See page B-42 for Add-A-Shroud® kit. For use with connector bodies.

Only receptacles and plugs up to 480V AC are HP rated.

HP ratings are AC only.

Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.