



**20 Amp, 3ØY 120/208, 277/480 and 347/600 Volts AC
4 Pole, 5 Wire, Grounding**

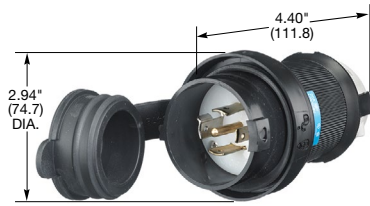


HBL2511SW




HBL2511S

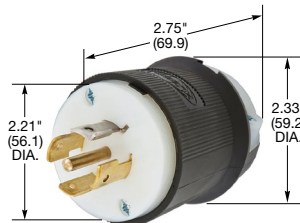

HBL2511

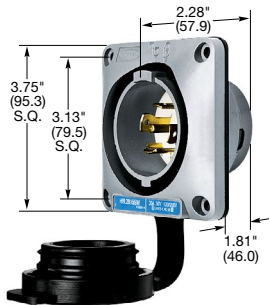

HBL2515SW

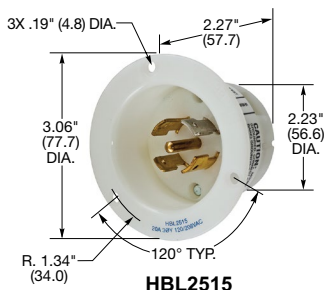

HBL2515

Dimensions in Inches (mm)

Plugs



**20A 3ØY 120/208V AC
NEMA L21-20P
2 HP**



**20A 3ØY 277/480V AC
NEMA L22-20P
5 HP**



**20A 3ØY 347/600V AC
NEMA L23-20P**

Watertight Safety-Shroud®

IP66 SUITABILITY

UL Type 4x, 12

| Description | Cord Dia. | Catalog Number | | |
|--|---------------------|------------------|---|---|
| Black Valox® housing, white Valox® clamps. | .350"-1.150" (9-29) | HBL2511SW | - | - |

Safety-Shroud®

IP20 SUITABILITY

| Description | Cord Dia. | Catalog Number | | |
|---|---------------------|-----------------|---|---|
| Black and white nylon body, white Valox® shroud. Can be used with the Insulgrip Connector Bodies. | .350"-1.150" (9-29) | HBL2511S | - | - |

Note: See page B-40 for accessories.

Insulgrip®

IP20 SUITABILITY

| Description | Cord Dia. | Catalog Number | | | |
|--|---------------------|--------------------|------------------|----------------|---|
| Black and white nylon. | .350"-1.150" (9-29) | HBL2511 | HBL2521 | HBL2531 | |
| Black and white nylon, spring termination. | .350"-1.150" (9-29) | HBL2511ST | HBL2521ST | | - |
| All black nylon. | .350"-1.150" (9-29) | HBL2511BK | - | | - |
| All black nylon, spring termination | .350"-1.150" (9-29) | HBL2511STBK | - | | - |
| Corrosion resistant, yellow nylon. | .350"-1.150" (9-29) | HBL25CM11 | - | | - |
| Black and white for flat cable. | .350"-1.150" (9-29) | HBL2511FC | - | | - |

Note: See page B-52 for accessories.

Flanged Inlets

Watertight Safety-Shroud®

IP66 SUITABILITY

UL Type 4x, 12

| Description | Catalog Number | | |
|---------------------------------|------------------|---|---|
| Gray Valox® housing and flange. | HBL2515SW | - | - |

Note: See page B-52 for accessories.

Insulgrip®

IP20 SUITABILITY

| Description | Catalog Number | | | |
|-----------------------------------|------------------|------------------|----------------|---|
| Nylon casing, back wired. | HBL2515 | HBL2525 | HBL2535 | |
| Nylon casing, spring termination. | HBL2515ST | HBL2525ST | | - |

Note: See page B-52 for accessories.

See pages B-69 and B-70 for technical information on Twist-Lock and Watertight Safety-Shroud devices.

Twist-Lock® 3-Phase Circuit Tester



| Description | Rating | Catalog Number | | |
|-------------------------|--|-------------------|---|---|
| 3-Phase Circuit Tester. | 3Ø 120/208V AC Min. Voltage: 90V AC | HBL3PT2511 | - | - |

Note: Testers in other NEMA configurations can be developed upon request. See page B-53 for additional circuit testers.



HBL3PT2511

Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.

HBLMITL - For use with Watertight Safety-Shroud receptacles, see page B-41.

