


30 Amp, 125, 250 Volts and 277 Volts AC 2 Pole, 3 Wire, Grounding

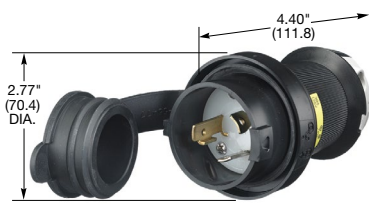


30A 125V NEMA L5-30P 2 HP	30A 250V NEMA L6-30P 2 HP	30A 277V AC NEMA L7-30P 3 HP
---------------------------------	---------------------------------	------------------------------------



HBL2611SW




HBL2621S

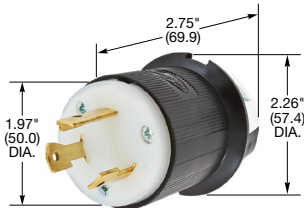


HBL2621



HBL2611ST

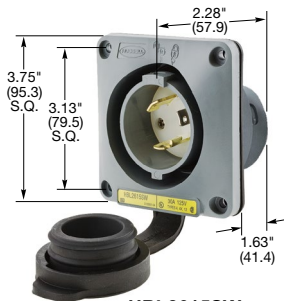

HBL2615SW

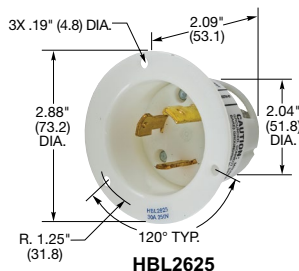

HBL2625

Plugs

Watertight Safety-Shroud®

Description	Cord Dia.	IP66 SUITABILITY	UL Type 4x, 12
Black Valox® housing, white Valox® clamps.	.325"-.930" (9-24)	HBL2611SW	HBL2621SW -

Safety-Shroud®

Description	Cord Dia.	IP20 SUITABILITY
Black and white nylon body, white Valox® shroud. Can be used with the Insulgrip Connector Bodies.	.360"-.930" (9-24)	HBL2611S HBL2621S -

Note: See page B-40 for accessories.

Insulgrip®

Description	Cord Dia.	IP20 SUITABILITY
Black and white nylon.	.360"-.930" (9-24)	HBL2611 HBL2621 HBL2631
Black and white nylon, spring termination		HBL2611ST HBL2621ST -
Heat stabilized, gray nylon, 220° F (104° C).	.360"-.930" (9-24)	HBL2611F HBL2621F -
Corrosion resistant, yellow nylon.	.360"-.930" (9-24)	HBL26CM11 HBL26CM21 -
All black nylon.	.360"-.930" (9-24)	HBL2611BK HBL2621BK -
All black nylon, spring termination	.360"-.930" (9-24)	HBL2611STBK HBL2621STBK -
Cord clamps with removable inserts. All black nylon.	.360"-.930" (9-24)	- HBL2621EBK -

Note: See page B-52 for accessories.

Valise®

Description	Cord Dia.	IP20 SUITABILITY
Yellow nylon.	.590"-.930" (15.0-23.6)	HBL2611VY HBL2621VY -
Corrosion resistant, yellow nylon.	.590"-.930" (15.0-23.6)	HBL26CM11V - -
Black nylon.	.590"-.930" (15.0-23.6)	HBL2611VBK HBL2621VBK -

Note: See page B-53 for accessories.

Flanged Inlets

Watertight Safety-Shroud®

Description	IP66 SUITABILITY	UL Type 4x, 12
Gray Valox® housing and flange.	HBL2615SW	HBL2625SW -
Reverse service, gray Valox® housing and flange (use with HBL2613SR), (Not shown).	HBL2615SWR	- -

Note: See page B-54 for accessories.

Insulgrip®

Description	IP20 SUITABILITY
Nylon casing, back wired.	HBL2615 HBL2625 HBL2635
Nylon casing, spring termination	HBL2615ST HBL2625ST -
Heat stabilized, gray nylon, 220° F (104° C).	HBL2615F HBL2625F -
Nylon casing, weather protective, die cast aluminum, back wired, self closing lift cover.	HBL2615M3 - -

Note: See page B-52 for accessories.

See pages B-69 and B-70 for technical information on Twist-Lock and Watertight Safety-Shroud devices.
See page B-74 for technical information on Valise plugs and connectors.

Dimensions in Inches (mm)

Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.