 


Twist-Lock® Devices




**30 Amp, 3ØY 120/208, 277/480 and 347/600 Volts AC
4 Pole, 5 Wire, Grounding**



30A 3ØY 120/208V AC NEMA L21-30R 3 HP	30A 3ØY 240/415V AC NEMA L26-30R	30A 3ØY 277/480V AC NEMA L22-30R 10 HP	30A 3ØY 347/600V AC NEMA L23-30R
--	--	---	--

Connector Bodies

Watertight Safety-Shroud®		IP66 SUITABILITY		UL Type 4x, 12	
Description	Cord Dia.	Catalog Number			
Black Valox® housing, white Valox® clamps.	.350"-1.150" (9-29)	HBL2813SW	HBL2803	HBL2823SW	-

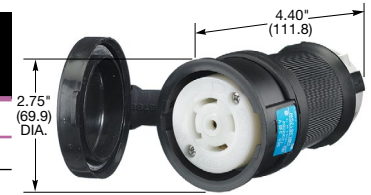

HBL2813SW

Insulgrip®		IP20 SUITABILITY			
Description	Cord Dia.	Catalog Number			
Black and white nylon.	.350"-1.150" (9-29)	HBL2813	-	HBL2823	HBL2833
Black and white nylon, spring termination	.350"-1.150" (9-29)	HBL2813ST	-	HBL2823ST	-
Corrosion resistant, yellow nylon.	.350"-1.150" (9-29)	HBL28CM13	-	-	-
Black and white for flat cable.	.350"-1.150" (9-29)	HBL2813FC	-	-	-
All black nylon.	.350"-1.150" (9-29)	HBL2813BK	-	-	-



HBL2813ST



HBL2813

Note: See page B-52 for accessories.

Receptacles


Watertight Safety-Shroud®		IP66 SUITABILITY		UL Type 4x, 12	
Description	Catalog Number				
Gray Valox® housing and flange, back wired.	HBL2810SW - HBL2820SW HBL2830SW				



HBL2810SW

Note: See page B-54 for accessories.

Safety-Shroud® Twist-Lock®		IP20 SUITABILITY			
Description	Catalog Number				
Gray Valox® angle housing, one gang, back wired.	HBL2810AR - - -				
Gray Valox® surface mounting, one gang, back wired.	HBL2810SR - - -				
Gray Valox® semi-flush, two gang, back wired.	HBL2810SR2 - - -				

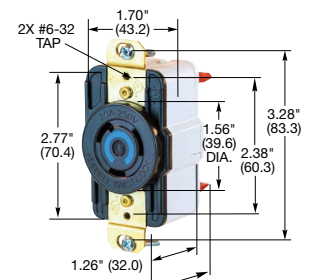


HBL2820ST

Single Flush Receptacles		IP20 SUITABILITY			
Description	Catalog Number				
Black nylon face, back and side wired.	HBL2810	HBL2800	HBL2820	HBL2830	
Black and white nylon, spring termination	HBL2810ST	-	HBL2820ST	-	
Isolated ground, orange nylon face, back and side wired.	IG2810	-	-	-	
Ring terminal connection.	HBL2810RT	-	-	-	

Note: See page B-52 for accessories.

Insulgrip® Flanged Receptacles

Description	Catalog Number			
Nylon casing, back wired.	HBL2816	-	HBL2826	HBL2836
Nylon casing, back wire, spring termination	HBL2816ST	-	HBL2826ST	-
Black nylon casing, back wire, spring termination	HBL2816STBK	-	-	-

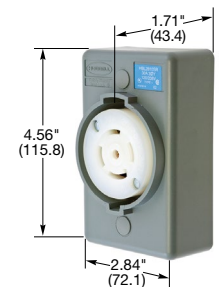

HBL2810SR

Note: See page B-52 for accessories.

Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.

Dimensions in Inches (mm)