


Twist-Lock® Devices

**Non-NEMA 20 Amp, 250, 125/250 Volts and 3ØY 120/208 Volts AC
2 Pole, 3 Wire, Grounding and
3 Pole, 3 Wire, Non-Grounding**




HBL9965C

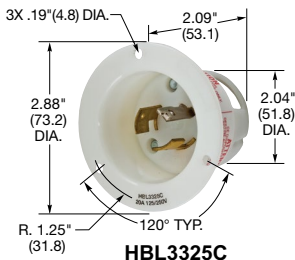

HBL3325C




HBL7411C

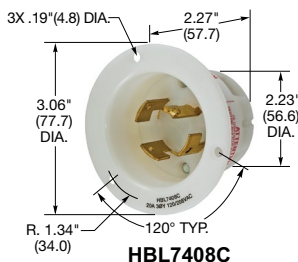


HBL7408C

For Replacement Use Only

 IP20
SUITABILITY



20A 250V
Non-NEMA
Not UL Listed

 

20A 125/250V
Non-NEMA
Not UL Listed

Plugs

Description	Cord Dia.	Catalog Number	
Black and white nylon.	.360"-.930" (9-24)	HBL9965GCB	HBL9965C
Corrosion resistant, yellow nylon.	.360"-.930" (9-24)	-	HBL99CM65C

Note: See page B-52 for accessories.


Flanged Inlets

Description	Catalog Number
Nylon casing, back wired.	- HBL3325C


Note: See page B-52 for accessories.

For Replacement Use Only

 IP20
SUITABILITY



20A 3Ø 250V AC
Non-NEMA
Not UL Listed

 

20A 3Ø Y
120/208V AC
Non-NEMA
Not UL Listed

Plugs

Description	Cord Dia.	Catalog Number	
Black and white nylon.	.350"-1.150" (9-29)	HBL7411GCB	HBL7411C

Note: See page B-52 for accessories.

Flanged Inlets

Description	Catalog Number
Nylon casing, back wired.	- HBL7408C

Note: See page B-52 for accessories.

The devices shown on this page are not listed by Underwriters Laboratories Inc. and are for replacement use only in existing installations.

Dimensions in Inches (mm)

CAUTION: To avoid electrical shock, review premises carefully and do not use if slot or blade configuration (design) is already in a circuit having a rating differing from the rating of this device.