

# Twist-Lock® Devices

## Accessories for 15 Amp 2 and 3 Wire Devices

- Tinted lid is aesthetically pleasing in any location. High-impact, polycarbonate while-in-use cover will not rust or corrode; cover is NEMA 3R rated
- Compact 2-gang design



**HBLPKL520**

- Locking receptacle prevents unintentional disconnection of mating pump plug

### Pool Kit Contains:

- Heavy duty, industrial grade locking receptacle NEMA L5-20, 20A 125V
- Single-pole switch (20A, 120-277V AC)
- Two gang, 2 inch deep die-cast aluminum weatherproof box with (4) 3/4 inch threaded outlets
- Two gang, weatherproof while-in-use cover
- Includes mounting hardware, gasket, wire connector and (3) closure plugs
- Complete assembly instructions

### Pool Pump Kit

Description	Catalog Number
Pool pump receptacle kit.	<b>HBLPKL520</b>



**HBL6023**



**HBL6024**



**HBL7529A**

**IP55\***  
SUITABILITY

### Weatherproof, Seal-Tite®, Triple Seal Boots for 15A Insulgrip® Devices


Description	For 3 Wire Devices	For 3 Wire EdgeConnect™ Devices
"Black elastomer boot for plugs when used in a cord set and connector bodies when used with a flange inlet"	<b>HBL6023</b>	<b>HBL6023ST</b>
Same as above except yellow elastomer.	<b>HBL60CM23</b>	<b>HBL60CM23ST</b>
Black elastomer boot for connector bodies when used in cord sets.	<b>HBL6024</b>	<b>HBL6024ST</b>
Same as above except yellow elastomer.	<b>HBL60CM24</b>	<b>HBL60CM24ST</b>

Note: \*When installed and used properly with plug and connector body combinations.

### PLUGOUT® Lockout Devices

Description	Catalog Number
Lockout device for 15A and 20A straight blade plugs.	<b>HLDM</b>
Lockout device for attachable 20 and 30A plugs, straight body or angle types, with or without weatherproof covers.	<b>HLD</b>

Note: See section BB for additional information on PLUGOUT Lockout devices.

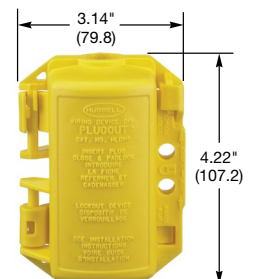

**HLDM**

Dimensions in Inches (mm)