

Twist-Lock® Devices

Accessories for 20 and 30 Amp 3, 4 and 5 Wire Devices

Insulgrip® Plug and Connector Body Latching Kit

The Hubbell latching kit provides both improved safety and security through a double locking feature that makes unintentional disconnection virtually impossible – even under high vibration situations. The plug and connector body lock once when first connected, then again when you push the special position locking slide into place.

Insulgrip® Latching Kit

Description	For 3 Wire Devices	For 4 & 5 Wire Devices
For all 20A and 30A Twist-Lock Insulgrip plugs and connectors.	SK2	SK3



SK2

Valise®

IP55*
SUITABILITY

Weatherproof, Seal-Tite®, Triple Seal Boots

Description	For 3 Wire Devices	For 4 & 5 Wire Devices
Yellow Seal-Tite® elastomer triple seal cover for use with Valise plugs when used in cord set and Valise connector bodies when used with flanged inlet.	HBL60CM31V	–
Yellow Seal-Tite® elastomer triple seal cover for use with Valise connector bodies.	HBL60CM32V	–



HBL60CM31V

Note: *When installed and used properly with plug and connector body combinations.

Insulgrip®


IP55*
SUITABILITY

Weatherproof, Seal-Tite®, Triple Seal Boots

Description	For 3 Wire Devices	For 3 Wire EdgeConnect™ Devices	For 4 & 5 Wire Devices	For 4 & 5 Wire EdgeConnect™ Devices
"Black elastomer boot for plugs when used in a cord set and connector bodies when used in flanged inlets."	HBL6031	HBL6031ST	HBL6035	HBL6035ST
Same as above except yellow.	HBL60CM31	HBL60CM31ST	HBL60CM35	HBL60CM35ST
Black elastomer boot for connector bodies when used in a cord set.	HBL6032	HBL6032ST	HBL6036	HBL6036ST
Same as above except yellow	HBL60CM32	HBL60CM32ST	HBL60CM36	HBL60CM36ST



HBL6032

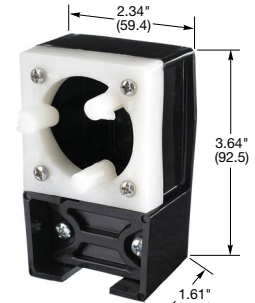

HBL3WAA

Angle Adapter

Description	For 3 Wire Devices	For 4 & 5 Wire Devices
Nylon, angle adapter for Insulgrip plugs and connector bodies, cord grip range .325"-.930" (8.3-24).	HBL3WAA	HBL45WAA

PLUGOUT® Lockout Devices


Description	For 3 Wire Devices	For 4 & 5 Wire Devices
Lockout device for attachable 20 and 30A locking plugs, straight body or angle types, with or without weatherproof covers.	HLD	HLD
Lockout device for 20 and 30A 3 wire angle plugs and watertight Safety-Shroud® Twist-Lock® plugs.	HLD2	HLD2

Note: See section BB for additional information on PLUGOUT Lockout devices.
*When installed and used properly with plug and connector body combinations.

For quick visual identification of circuits or configurations.

Colored Cord Clamps*

Description	Color	For 3 Wire Devices	For 4 & 5 Wire Devices
For use with 20A and 30A Insulgrip® Twist-Lock® Plugs and Connectors. Cord diameter: 3 wire .350"-.930" (9-24), 4 & 5 wire .350" – 1.150" (9-29)	Black	HBLTL2CCBK	HBLTL3CCBK
	Blue	HBLTL2CCBL	HBLTL3CCBL
	Brown	HBLTL2CCBR	HBLTL3CCBR
	Dark Blue	HBLTL2CCDB	HBLTL3CCDB
	Green	HBLTL2CCGR	HBLTL3CCGR
	Orange	HBLTL2CCOR	HBLTL3CCOR
	Red	HBLTL2CCRD	HBLTL3CCRD
	Teal	HBLTL2CCTL	HBLTL3CCTL
	White	HBLTL2CCWH	HBLTL3CCWH
	Yellow	HBLTL2CCYL	HBLTL3CCYL

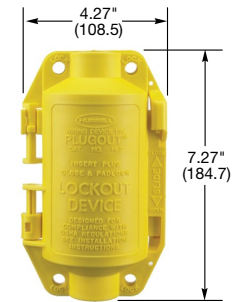

HLD



Note: *Clamp only. Contains no screws. Order in increments of 10. Not UL Listed or CSA Certified.

Dimensions in Inches (mm)