

## SNAPConnect® Specification Grade Style Line® Decorator Series, 15A, 120/277V AC

Description	Toggle Color	Single Pole	Double Pole	Three Way	Four Way
SNAPConnect® Rocker.	Black	<b>SNAP2101BKNA</b>	—	<b>SNAP2103BKNA</b>	—
	Brown	<b>SNAP2101BRNA</b>	—	<b>SNAP2103BRNA</b>	—
	Gray	<b>SNAP2101GYNA</b>	—	<b>SNAP2103GYNA</b>	—
	Ivory	<b>SNAP2101INA</b>	—	<b>SNAP2103INA</b>	—
	Lt. Almond	<b>SNAP2101LANA</b>	—	<b>SNAP2103LANA</b>	—
	Red	<b>SNAP2101RNA</b>	—	<b>SNAP2103RNA</b>	—
	White	<b>SNAP2101WNA</b>	—	<b>SNAP2103WNA</b>	—

### 20A, 120/277V AC

Description	Toggle Color	Single Pole	Double Pole	Three Way	Four Way
SNAPConnect® Rocker.	Black	<b>SNAP2121BKNA</b>	—	<b>SNAP2123BKNA</b>	—
	Brown	<b>SNAP2121BRNA</b>	—	<b>SNAP2123BRNA</b>	—
	Gray	<b>SNAP2121GYNA</b>	—	<b>SNAP2123GYNA</b>	—
	Ivory	<b>SNAP2121INA</b>	—	<b>SNAP2123INA</b>	—
	Lt. Almond	<b>SNAP2121LANA</b>	—	<b>SNAP2123LANA</b>	—
	Red	<b>SNAP2121RNA</b>	—	<b>SNAP2123RNA</b>	—
	White	<b>SNAP2121WNA</b>	—	<b>SNAP2123WNA</b>	—

## Illuminated, Light ON with Load OFF, 15A, 120/277V AC

Description	Toggle Color	Single Pole	Double Pole	Three Way	Four Way
Illuminated, Light ON with Load OFF, Rocker, Blue LED.	Black	<b>SNAP2101ILBKNA</b>	—	<b>SNAP2103ILBKNA</b>	—
	Ivory	<b>SNAP2101ILINA</b>	—	<b>SNAP2103ILINA</b>	—
	Red	<b>SNAP2101ILRNA</b>	—	<b>SNAP2103ILRNA</b>	—
	White	<b>SNAP2101ILWNA</b>	—	<b>SNAP2103ILWNA</b>	—

### 20A, 120/277V AC

Description	Toggle Color	Single Pole	Double Pole	Three Way	Four Way
Illuminated, Light ON with Load OFF, Rocker, Blue LED.	Black	<b>SNAP2121ILBKNA</b>	—	<b>SNAP2123ILBKNA</b>	—
	Ivory	<b>SNAP2121ILINA</b>	—	<b>SNAP2123ILINA</b>	—
	Red	<b>SNAP2121ILRNA</b>	—	<b>SNAP2123ILRNA</b>	—
	White	<b>SNAP2121ILWNA</b>	—	<b>SNAP2123ILWNA</b>	—

## Pilot, Light ON with Load ON, 15A, 120/277V AC

Description	Toggle Color	Single Pole	Double Pole	Three Way	Four Way
Pilot, Light ON with Load ON, Rocker, Red LED.	Black	<b>SNAP2101PLBKNA</b>	—	—	—
	Ivory	<b>SNAP2101PLINA</b>	—	—	—
	Red	<b>SNAP2101PLRNA</b>	—	—	—
	White	<b>SNAP2101PLWNA</b>	—	—	—

### 20A, 120/277V AC

Description	Toggle Color	Single Pole	Double Pole	Three Way	Four Way
Pilot, Light ON with Load ON, Rocker, Red LED.	Black	<b>SNAP2121PLBKNA</b>	—	—	—
	Ivory	<b>SNAP2121PLINA</b>	—	—	—
	Red	<b>SNAP2121PLRNA</b>	—	—	—
	White	<b>SNAP2121PLWNA</b>	—	—	—

## Jumper/Tester


Description	Catalog Number
Jumper/Tester for Single Pole Circuits, Black Toggle, Blue LED Indicator.	<b>SNAPSWJUMP</b>
Jumper/Tester for Three Way Circuits, Black Toggle, Blue LED Indicator.	<b>SNAP3WJUMP</b>

## SNAPConnect® Switch Pigtailed Connector


Description	3 Wire Connector for Single Pole and Single Pole Illuminated	4 Wire Connector for Single Pole with Pilot Light	4 Wire Connector for 3 Way and 3 Way Illuminated
Clear right angle terminal, 6 inch leads, solid wire.	<b>SNAPSP1NA</b>	<b>SNAPSP1NA</b>	<b>SNAP3W1NA</b>
Clear right angle terminal, 6 inch leads, stranded wire.	<b>SNAPSP2NA</b>	<b>SNAPSP2NA</b>	<b>SNAP3W2NA</b>

Note: See page D-15 for accessories and page D-16 for wallplates.  
See page D-22 for technical information.


Many of these products are Assembled in USA, as indicated, and many are Buy American Compliant. Please contact Hubbell with any certification requirements.

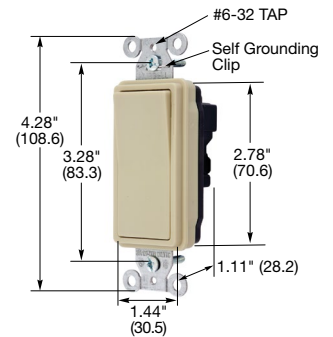


**SNAP2101INA**

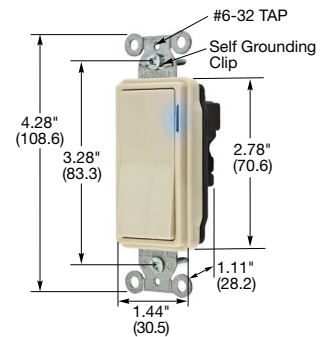

**SNAP2121ILINA**

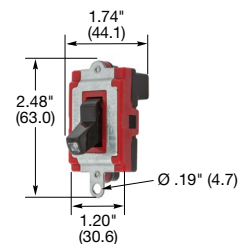

**SNAPSWJUMP**

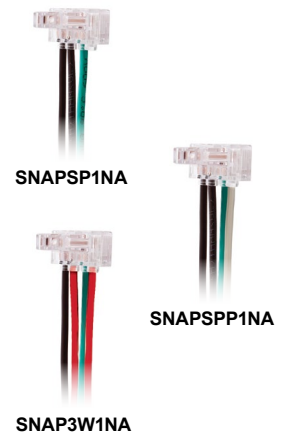

## HP Conversion Chart

	120V	208V	240V	277V AC
15A	.5HP	1.5HP	2HP	2HP
20A	1HP	2HP	2HP	2HP

Dimensions in Inches (mm)