



Switched Disconnects and Enclosures

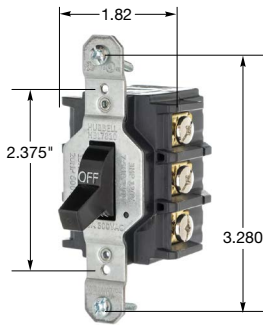


HBL7810




HBL1389

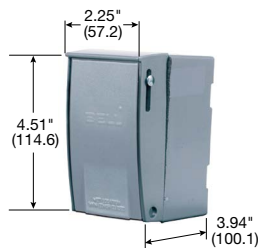


HBL13R13

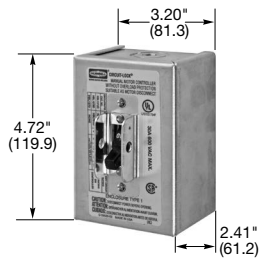


HBL1379

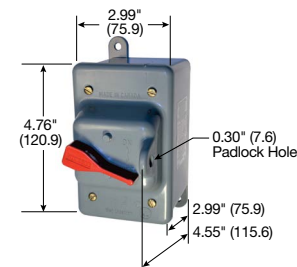

HBL13R23

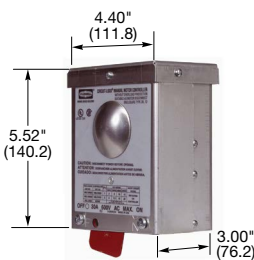

HBL13R89

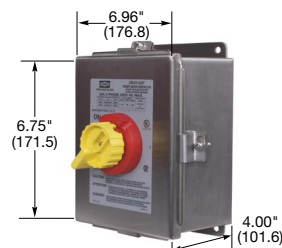

HBL13S33D

30A 600V AC Manual Motor Controllers, Double Pole

Description	Catalog Number
30A, double pole, single throw, AC manual motor controller, black nylon handle, side and back wired.	HBL7832
30A, double pole, single throw, AC manual motor controller, black nylon handle, short toggle.	HBL7832S
HBL7832D in HBL1390 Type 1 enclosure with non-metallic cover, ½ in. and ¾ in. knockouts on top, bottom and back of steel frame.	HBL1392
HBL7832D in HBL1370 metal Type 1 enclosure.	HBL1372
HBL7832D in NEMA 3R non-metallic enclosure.	HBL13R22
HBL7832D in HBL13R90 metal Type 3R enclosure.	HBL13R92
HBL7832D in NEMA 3R flip-lid enclosure.	HBL13R12

Note: See page F-21 for technical information.

30A 600V AC Manual Motor Controllers, Three Pole

Description	Catalog Number
30A, three pole, single throw, AC manual motor controller, black nylon handle, side and back wired.	HBL7810
30A, three pole, single throw, AC manual motor controller, black nylon handle, short toggle.	HBL7810S
HBL7810D in HBL1390 Type 1 enclosure with non-metallic cover, ½ in. and ¾ in. knockouts on top, bottom and back of steel frame.	HBL1389
HBL7810D in HBL1370 metal Type 1 enclosure.	HBL1379
HBL7810D in NEMA 3R non-metallic enclosure.	HBL13R23
HBL7810D in HBL13R90 metal Type 3R enclosure.	HBL13R89
HBL7810D in NEMA 3R flip-lid enclosure.	HBL13R13
30A, 600V, three pole, rotary controller in NEMA 4X stainless steel enclosure.	HBL13S33D
30A, 600V, three pole, rotary controller in NEMA 4X non-metallic enclosure.	HBL13X33D

Note: See page F-21 for technical information.

Motor Rating

Product	120V AC	240V AC	480V AC	600V AC	Phase
30A Double Pole	2HP	5HP	10HP	15HP	1
30A Three Pole	3HP	7½HP	15HP	20HP	3
40A Double Pole	2HP	5HP	10HP	15HP	1
40A Three Pole	3HP	7½HP	15HP	20HP	3
50A Double Pole	2HP	5HP	10HP	15HP	1
50A Three Pole	3HP	7½HP	15HP	25HP	3
60A Double Pole	-	10HP	15HP	20HP	1
60A Three Pole	-	10HP	25HP	30HP	3
85A Double Pole	-	10HP	15HP	20HP	1
85A Three Pole	-	10HP	25HP	40HP	3

Dimensions in Inches (mm)