

## Heavy-Duty Portable Outlet Boxes and Cover Plates

Description	Catalog Number
Box with cord strain relief, with one blank cover plate.	<b>HBLPOB1</b>
White box with cord strain relief, one blank white cover plate.	<b>HBLPOB1L</b>
Box with cord strain relief, with one blank cover plate, black.	<b>HBLPOB1BK</b>
Box with cord strain relief, with two duplex (indoor) cover plates.	<b>HBLPOB1D</b>
White box with cord strain relief, with two white duplex (indoor) cover plates.	<b>HBLPOB1DL</b>
Box with cord strain relief, with two duplex (indoor), yellow cover plates.	<b>HBLPOB1DY</b>
Blank, non-metallic FS cover plate with foam gasket, gray.	<b>HBLP14FS</b>
Blank, non-metallic FS cover plate with foam gasket, white.	<b>HBLP14FSL</b>
Duplex, non-metallic FS cover plate, gray	<b>HBLP8FS</b>
Duplex, non-metallic FS cover plate, white.	<b>HBLP8FSL</b>
Duplex, non-metallic FS cover plate, yellow.	<b>HBLP8FSY</b>
Single receptacle (1.39"), non-metallic FS cover plate, gray.	<b>HBLP7FS</b>
Single receptacle (1.56"), non-metallic FS cover plate, gray.	<b>HBLP720FS</b>
Rectangular opening, non-metallic FS cover plate, gray.	<b>HBLP26FS</b>
Rectangular opening, non-metallic FS cover plate, White.	<b>HBLP26FSL</b>



**HBLPOB1**



**Cover Plates**

## Other Cover Plates and Devices

### which may be used with Heavy-Duty Portable Outlet Boxes

Description	Catalog Number
Duplex cover plate, weatherproof. Single receptacle (1.39") cover plate, weatherproof Single receptacle (1.56") cover plate, weatherproof. Safety-Shroud Twist-Lock® surface receptacles.	<b>HBL5221, HBL52CM2, HBL7423WO, HBL74CM23WO, HBL7425WOA, HBL2310SR, HBL74CM25WOA, HBL2320SR, HBL2330SR, HBL2610SR, HBL2620SR</b>

Note: Standard product gray, CM yellow.

## Deluxe Cord Grips Straight Male Thread

### Nylon Fittings, Stainless Steel Mesh, Liquidtight, for Insulated Cables

Grip Diameter Range Inches (mm)	Thread Size NPT (inches)	Form Size	Catalog Number
.375"-.500" (9.5-12.7)	3/4"	F3	<b>074011335</b>
.500"-.625" (12.7-15.9)	3/4"	F3	<b>074011336</b>
.625"-.750" (15.9-19.0)	3/4"	F3	<b>074011337</b>

## Gray Nylon Cord Connector Straight Male Thread

Grip Diameter Range Inches (mm)	Thread Size NPT (inches)	Form Size	Catalog Number
.375"-.500" (9.5-12.7)	3/4"	F3	<b>SHC1035CR</b>
.500"-.625" (12.7-15.9)	3/4"	F3	<b>SHC1036CR</b>
.625"-.750" (15.9-19.0)	3/4"	F3	<b>SHC1037CR</b>



**Deluxe Cord Grips (purchased separately)**




**Gray Nylon Cord Connector**

## Specifications for Heavy-Duty Portable Outlet Boxes and Cover Plates

UL Listed	UL514C, UL467 and UL50 Enclosures Types 1, 3R.
CSA Certified	94 Enclosures Types 1, 3R and C22.2 No. 0.4 (Impedance).
<b>Box Specifications:</b>	
Moisture Resistance	Wet and damp locations, enclosure Type 3R when used with weatherproof cover plates; Dry, indoors locations, enclosure Type 1 with all other cover plates
Flammability	UL94V-0, 94-5VA classification
Operating Temperature	80°C maximum; -35°C minimum
UV Resistance	All materials are UV stabilized
Impact and Crush Resistance	In accordance with UL514C, UL50, C22.2 No. 18 and C22.2 No. 94
Material	Valox®
Cord Connector Materials	Nylon nut; nylon Gotcha® ring; neoprene grommet
Cord Diameter Range	.38" to .75" diameter
Bonding Strap Material	Brass
Threaded Inserts	Brass
Grounding Screw Material	Brass
Indoor Cover Plate Screws Material	Zinc plated steel
Outdoor Cover Plate Screws Material	Stainless steel
Cover Plate Gasket Material	UL recognized closed-cell foam (aging and oil resistant)

## Dimensions

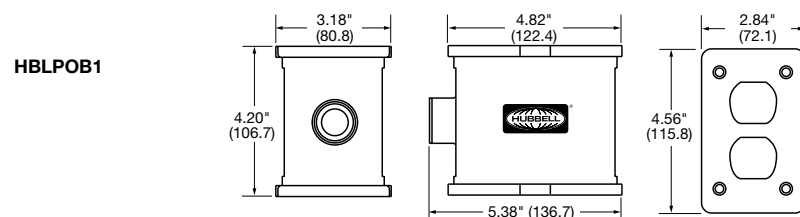

Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.

Dimensions in Inches (mm)