

## Features and Benefits

### Heavy Duty Industrial Weatherproof Reels

- Powder coated, solid U.S. steel construction
- Multi-position roller guide can be mounted in four different positions
- Ratchet lock can be disengaged in field for constant tension application
- UL Type 4X enclosure protects spring motor, junction box, slip ring assembly and cable entrance from hosedown or corrosion
- Optional pivot base allows 340° rotation of reel and increases range of cable to nearly any direction



**HBL501242W**  
with HBL16PB

### Heavy Duty Industrial Weatherproof Reels\*

Description	Amps	Volts AC	Cable Length Feet (m)	Cable Type	Weight Lbs. (kg)	Catalog Number
14" yellow weatherproof reel	15	600	50 (15.2)	14/3 SOW-A	55 (24.9)	<b>HBL501431W</b>
16" weatherproof reel yellow housing white housing	20	600	50 (15.2)	12/3 SOW-A	80 (36.3)	<b>HBL501232W</b> <b>HBL501232WM1</b>
16" yellow weatherproof reel	16	600	50 (15.2)	12/4 SOW-A	86 (39.0)	<b>HBL501242W</b>
16" weatherproof reel yellow housing white housing	25	600	50 (15.2)	10/3 SOW-A	86 (39.0)	<b>HBL501032W</b> <b>HBL501032WM1</b>
16" yellow weatherproof reel	20	600	50 (15.2)	10/4 SOW-A	92 (41.7)	<b>HBL501042W</b>

Note: \*All heavy duty industrial cord reels are supplied with wire leads and 3/4" NPT hub feed. Power supply cable not supplied.



**HBL501232WM1**



**HBL501242W**  
with HBL16PB

## Accessories

Description	Weight Lbs. (kg)	Catalog Number
14" pivot base.	5 (2.3)	<b>HBL14PB</b>
16" pivot base.	13 (5.9)	<b>HBL16PB</b>
Replacement stop.	.2 (.09)	<b>HBLWPBS</b>

## Specifications

Listing/Certification	UL 355 and CSA, C22.2 No. 308.
Environment	Type 4X enclosure, CAN/CSA - C22.2 No. 308. Dry, indoor and wet and damp outdoor non-hazardous location.




**HBL14PB**

## Dimensions

Inch (mm)	A	B	C	D	E	F	G	H	I	J
14" Reel	6.50" (165)	8.12" (206)	16.25" (413)	13.75" (349)	3.00" (76)	12.19" (310)	3.00" (76)	3.00" (76)	3.00" (76)	6.50" (165)
16" Reel	6.50" (165)	9.12" (232)	18.25" (464)	15.75" (400)	3.00" (76)	14.19" (360)	6.00" (152)	6.00" (152)	4.94" (125)	6.50" (165)




**HBLWPBS**

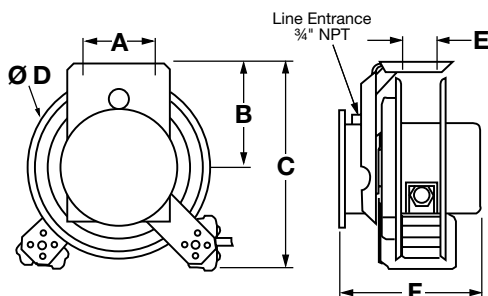

## Pivot Base

### 340° Pivot Base (Optional)

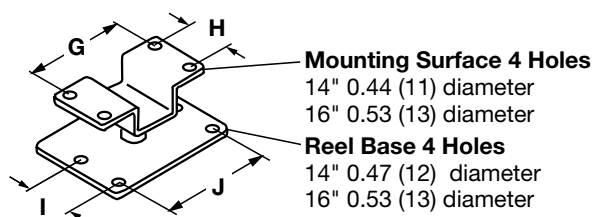

Note: Pivot base for use only with Weatherproof Cable Reel.

Dimensions in Inches (mm)